



Search Results

- Evaluate
- FAQ's
- How to Buy
- Bill of Material
 - Favorite Products List
 - Locate Distributor


Home > Products Overview > Search Results >

Current refinements (click to remove) Search Tips Within Results

Text Search: 'G1.5X2IB6'

Your search criteria matched only one product, shown below

G1.5X2IB6

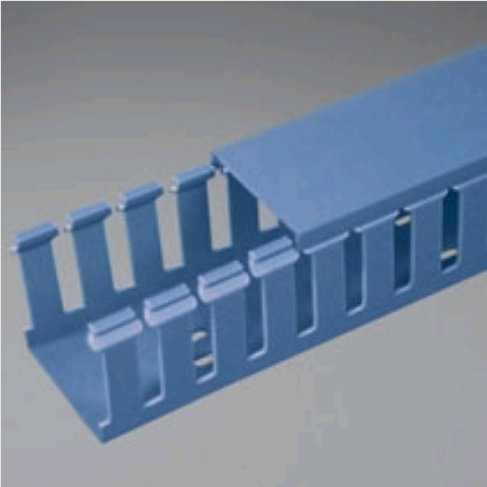

Choose from 6 sizes of *PANDUIT*® Type G Wiring Duct from 1.0 "x 1.0" up to 4.0" x 4.0" in Intrinsic Blue color. Used for general purpose control panel wiring and to route and protect wiring in communication closets. The non -slip cover conceals all wiring and is easy to install. The duct and cover form a flush sidewall providing increased capacity and improved aesthetics.

Specifications

- Made of lead-free PVC
- UL Recognized continuous use temperature: 122 °F (50°C)
- UL94 Flammability Rating of V -0
- Conforms with NFPA 79 -2002 section 14.3.1 requirement for flame retardant material
- Provided with mounting holes

Features and Benefits

- Wide finger/slot design provides greater sidewall rigidity and can be used with a wide range of wire bundle sizes
- *PANDUIT*® exclusive rounded edges protects hands and wiring/cabling from abrasion
- Non-slip cover stays in place during shipment, vibration and when in vertical orientation, eliminating rework
- Flush cover design holds 10 -12% more wires than traditional duct designs
- Double scoreline allows quick modification for larger cabling bundles saving installation time leading to a lower installed cost
- Specially formulated lead -free material eliminates health concerns associated with PVC that contains lead
- Restricted slot design retains wire in slot for fast, easy wire installation or removal

Base and cover sold separately.

Part Number	G1.5X2IB6
RoHS Compliancy Status	Compliant
Part Description	Wide finger, slotted wiring duct.
Material	Lead– free PVC
Color	Intrinsic Blue
CSA Certified	Yes
Length (ft.)	6
CE Compliant	Yes
Duct Size W x H (In.)	1.75 x 2.12
Duct Size W x H (mm)	44.5 x 53.8
Mounting Method	Standard Mounting Holes
Pricing Description	Wide Finger With Flush Cover
Slot Width (In.)	.31
Slot Width (mm)	7.9
Cover Part Number	C1.5IB6
Min. Order UOM	FT
Min. Order Qty.	6
BOM Qty. (# of Pkgs.)	0
Add to Favorite Product List	

Please [register](#) to utilize the 'Bill of Materials', 'Submit Quotes' and 'Favorite Product List' features.