


MICRO Relays

RoHS

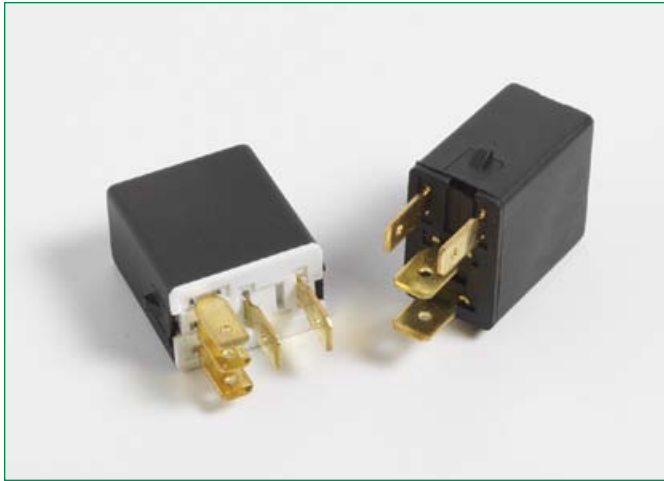

Remote control switches for automotive applications available for 12V and 24V rated circuits.

Relais für Anwendungen im Automobilbereich, erhältlich für 12V und 24V Bordnetze.

Specifications

Normally open relay :

Color Case: Black

Color Base: 12V Black / 24V White

Change over relay:

Color Case: Black

Color Base: 12V Black / 24V White

Packaging:

Series	Pack Size
020406xxTXN	10
020406xxZ	200






HOMOLOGATION IN ACCORDANCE WITH:



REGULATION N.10 ECE-ONU/02






EUROPEAN DIRECTIVE DIR.95/54 CE

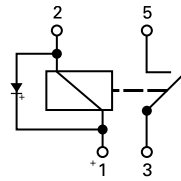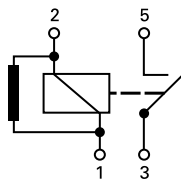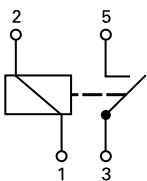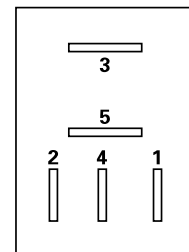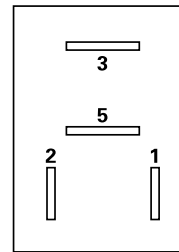

Normally Open (A)

Normally Open
with Resistor (B)

Normally Open
with Diode (C)
Terminal 1 is positive.

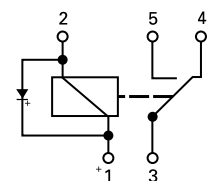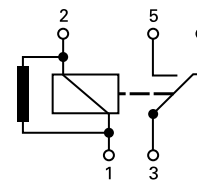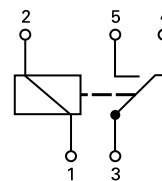

Change Over (A)

Change Over
with Resistor (B)

Change Over
with Diode (C)
Terminal 1 is positive.

Normally open relay

Part Number Artikel-Nr.	Volt	Ampere	Feature Merkmal	Diagram Schema
02040601_	12V	25A	—	A
02040605_	12V	25A	Resistor	B
02040609_	12V	25A	Diode	C
02040602_	24V	10A	—	A
02040606_	24V	10A	Resistor	B
02040610_	24V	10A	Diode	C

Change over relay

Part Number Artikel-Nr.	Volt	Ampere	Feature Merkmal	Diagram Schema
02040603_	12V	20/10A	—	A
02040607_	12V	20/10A	Resistor	B
02040611_	12V	20/10A	Diode	C
02040604_	24V	15/10A	—	A
02040608_	24V	15/10A	Resistor	B
02040612_	24V	15/10A	Diode	C