


### CL4C07UXXX

(M12 Cordset, 4 Position, 16 AWG Unshielded, Female Straight to Free End)

#### FEMALE FACE VIEW

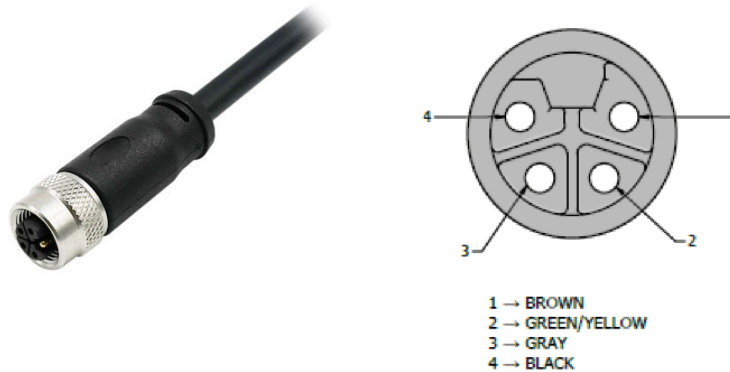

- Mueller's CL4C07UXXX is an M12 L coded 4-pin single ended, unshielded instrumentation cable with a straight female connector on one end and free at the other.
- Keyway – L Coding
- Utilizes a 4-conductor 16 AWG HD-PE-insulated, unshielded cable.
- Ratings:
  - Current: 16 A
  - Voltage: 63V AC/DC
- Material:
  - Coupling Nuts – Nickel Plated Brass
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant