 



Female Disconnects – Nylon Fully Insulated Interlock Barrel




Product Number [†]	UPC (054007-)	Wire Range (AWG)	Mates with Male Tab Width(W') x Thickness	L	Barrel Length	Barrel I.D.	Maximum Insulation Diameter	Terminals per:	
								Carton	Case
MNI18-187DFIX	09994	22-18	0.187 x 0.020	0.81	0.25	0.080	0.145	100	500
MNI18-187DFIK	69576	22-18	0.187 x 0.020	0.81	0.25	0.080	0.145	—	1000
MNI18-250DFIX	09995	22-18	0.250 x 0.032	0.91	0.25	0.076	0.145	100	500
MNI18-250DFIK	69577	22-18	0.250 x 0.032	0.91	0.25	0.076	0.145	—	1000
MNI14-187DFIX	09992	16-14	0.187 x 0.020	0.81	0.25	0.080	0.145	100	500
MNI14-187DFIK	69574	16-14	0.187 x 0.020	0.81	0.25	0.080	0.145	—	1000
MNI14-250DFIX	09993	16-14	0.250 x 0.032	0.91	0.25	0.076	0.145	100	500
MNI14-250DFIK	69575	16-14	0.250 x 0.032	0.91	0.25	0.076	0.145	—	1000
MNI10-250DFIX	09991	12-10	0.250 x 0.032	0.99	0.25	0.128	0.250	50	500
MNI10-250DFIK	69573	12-10	0.250 x 0.032	0.99	0.25	0.128	0.250	—	500




MNI18-187DFI
22-18
MNU18-187DMI

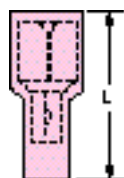


MNI18-250DFI
22-18
MN18-250DMI

 

MNI14-187DFI
16-14
MNU14-187DMI

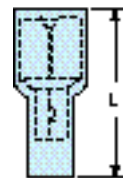

MNI14-250DFI
16-14
MNU14-250DMI

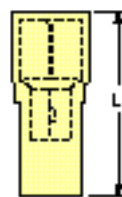

MNI10-250DFI
12-10
MNU10-250DMI

Wire Range
Suggested Mate