 

 
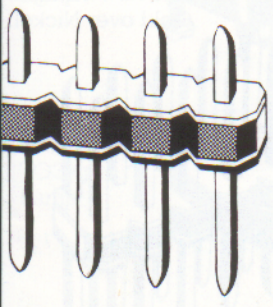


SQUARE PIN
UNSHROUDED
HEADERS

 

SERIES W81136
Single Row Straight





SERIES W82172
Double Row Straight


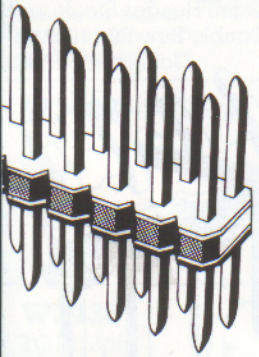


SERIES W81936
Single Row 90°

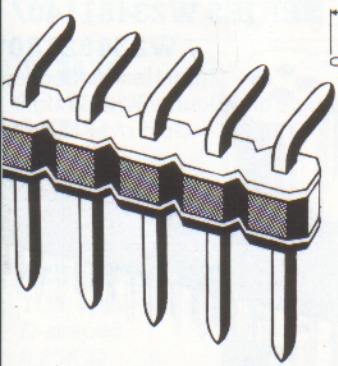

SERIES W82972
Double Row 90°

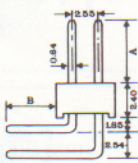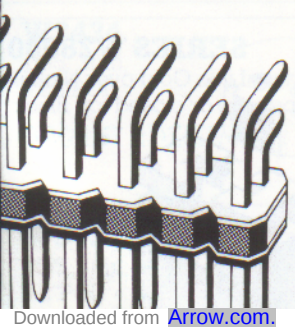

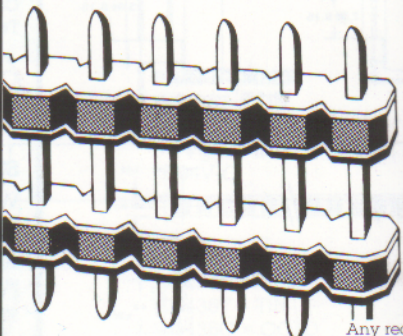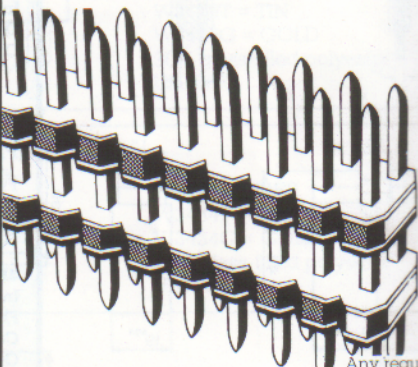DIMENSIONS		PART NUMBERS		DIMENSIONS		PART NUMBERS	
A	B	SIL 180°	DIL 180°	A	B	SIL 180°	DIL 180°
3.00	4.600	W81136T3840 W82172G0340	W82172T3840 W82172G0340	4.800	5.110	W81936T3834 W81936G0334	W82972T3834 W82972G0334
3.500	3.500	W81136T3841 W82172G0341	W82172T3841 W82172G0341	5.700	2.500	W81936T3803 W81936G0303	W82972T3803 W82972G0303
5.700	2.5600	W81136T3800 W81136G0300	W82172T3800 W82172G0300	5.720	5.110	W81936T3804 W81936G0304	
5.700	3.060	W81136T3806 W81136G0306	W82172T3806 W82172G0306	5.800	3.400	W81936T3822 W81936G0322	W82972T3822 W82972G0322
5.700	5.800	W81136T3830 W81136G0330	W82172T3830 W82172G0330	6.700	3.200	W81936T3821 W81936G0321	W82972T3821 W82972G0321
5.700	7.560	W81136T3802 W81136G0302	W82172T3802 W82172G0302	7.000	2.900	W81936T3820 W81936G0320	W82972T3820 W82972G0320
5.700	10.060	W81136T3809 W81136G0309	W82172T3809 W82172G0309	7.000	3.000	W81936T3825* W81936G0325*	W82972T3825* W82972G0325*
5.700	12.760	W81136T3810 W81136G0310	W82172T3810 W82172G0310	7.400	2.540	W81936T3831 W81936G0331	W82972T3831 W82972G0331
5.800	2.540	W81136T3811 W81136G0311	W82172T3811 W82172G0311	8.000	2.800	W81936T3819 W81936G0319	W82972T3819 W82972G0319
5.800	2.960	W81136T3801 W81136G0301	W82172T3801 W82172G0301	9.700	5.800	W81936T3836 W81936G0336	W82972T3836 W82972G0336
5.800	3.460	W81136T3805 W81136G0305	W82172T3805 W82172G0305	12.500	2.540	W81936T3833 W81936G0333	W82972T3833 W82972G0333
6.000	4.960	W81136T3808 W81136G0308	W82172T3808 W82172G0308	13.000	2.540	W81936T3832 W81936G0332	W82972T3832 W82972G0332
6.000	19.000	W81136T3839 W81136G0339	W82172T3839 W82172G0339	SERIES WSD1136 Single Row Straight Dual Plastic  Any required is supplied to cut. Approximate time 21 days.			
6.700	3.260	W81136T3815 W81136G0315	W82172T3815 W82172G0315				
7.000	2.960	W81136T3814 W81136G0314	W82172T3814 W82172G0314				
7.000	3.000	W81136T3825* W81136G0325*	W82172T3825* W82172G0325*				
7.000	5.110	W81136T3828 W81136G0328	W82172T3828 W82172G0328				
7.000	10.060	W81136T3818 W81136G0318	W82172T3818 W82172G0318	SERIES WSD2172 Double Row Straight Dual Plastic  Any required is supplied to cut. Approximate time 21 days.			
7.500	2.540	W81136T3823 W81136G0323	W82172T3823 W82172G0323				
8.500	2.460	W81136T3807 W81136G0307	W82172T3807 W82172G0307				
8.500	3.000	W81136T3826 W81136G0326	W82172T3826 W82172G0326				
9.000	2.540	W81136T3824 W81136G0324	W82172T3824 W82172G0324				
11.000	3.060	W81136T3837 W81136G0337	W82172T3837 W82172G0337				
12.000	4.460	W81136T3817 W81136G0317	W82172T3817 W82172G0317				
12.700	3.060	W81136T3816 W81136G0316	W82172T3816 W82172G0316				
12.700	5.110	W81136T3829 W81136G0329	W82172T3829 W82172G0329				
12.750	5.730	W81136T3812 W81136G0312	W82172T3812 W82172G0312				
12.000	3.000	W81136T3827 W81136G0327	W82172T3827 W82172G0327				