


KGG-MC 1,5/ 3 - Cable housing



1834356
<https://www.phoenixcontact.com/us/products/1834356>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

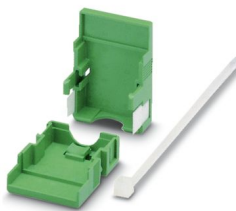

Cable housing, color: green, product range: KGG-MC 1,5, width: 14.5 mm

Commercial data

Item number	1834356
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	AA08
Product key	AAHZDB
Catalog page	Page 242 (C-1-2013)
GTIN	4017918051877
Weight per piece (including packing)	3.95 g
Weight per piece (excluding packing)	3.125 g
Customs tariff number	39269097
Country of origin	PL

KGG-MC 1,5/ 3 - Cable housing

1834356

<https://www.phoenixcontact.com/us/products/1834356>



Technical data


Product properties

Product type	Cable housing
Product family	KGG-MC 1,5
Number of positions	3
Pitch	3.81 mm

Material specifications

Flammability rating according to UL 94	HB
--	----

Dimensions

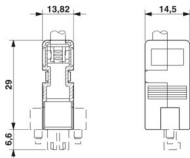Dimensional drawing	
Width	14.5 mm
Height	35.6 mm
Pitch	3.81 mm

KGG-MC 1,5/ 3 - Cable housing


1834356

<https://www.phoenixcontact.com/us/products/1834356>



Drawings

Dimensional drawing

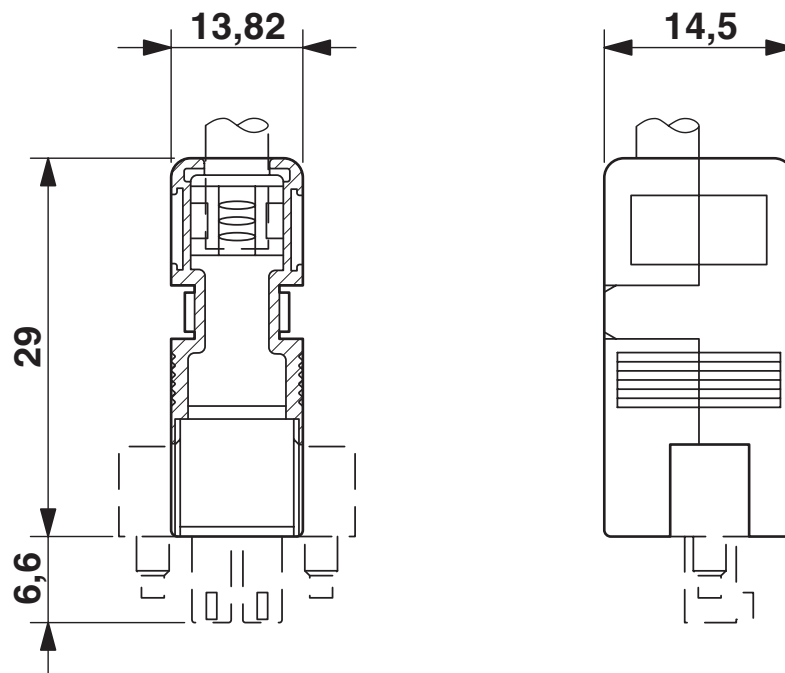

KGG-MC 1,5/ 3 - Cable housing



1834356

<https://www.phoenixcontact.com/us/products/1834356>

Classifications

ECLASS

ECLASS-11.0	27460402
ECLASS-12.0	27460402
ECLASS-13.0	27460402

ETIM

ETIM 9.0	EC002943
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

KGG-MC 1,5/ 3 - Cable housing

1834356

<https://www.phoenixcontact.com/us/products/1834356>



Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

KGG-MC 1,5/ 3 - Cable housing

1834356

<https://www.phoenixcontact.com/us/products/1834356>



Accessories

SBS10:UNBEDRUCKT - Marker card

1007248

<https://www.phoenixcontact.com/us/products/1007248>



Marker card, Card, white, unlabeled, can be labeled with: Marker pen, perforated, mounting type: snapped, snap into flat marker groove, for terminal block width: 10 mm, lettering field size: 6 x 10.1 mm, Number of individual labels: 250

CUC-DST-ABK-CP6,5 - Bend protection sleeve

1419790

<https://www.phoenixcontact.com/us/products/1419790>



Bend protection sleeve, degree of protection: IP20, color: black

KGG-MC 1,5/ 3 - Cable housing




1834356

<https://www.phoenixcontact.com/us/products/1834356>

MC 1,5/ 3-ST-3,81 - PCB connector

1803581

<https://www.phoenixcontact.com/us/products/1803581>

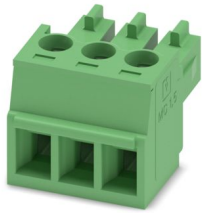


PCB connector, nominal cross section: 1.5 mm², color: green, nominal current: 8 A, rated voltage (III/2): 160 V, contact surface: Tin, contact connection type: Socket, number of potentials: 3, number of rows: 1, number of positions: 3, number of connections: 3, product range: MC 1,5/...-ST, pitch: 3.81 mm, connection method: Screw connection with tension sleeve, screw head form: L Slotted, conductor/PCB connection direction: 0 °, plug-in system: COMBICON MC 1,5, locking: without, mounting: without, type of packaging: packed in cardboard

MC 1,5/ 3-STF-3,81 - PCB connector

1827716
 
<https://www.phoenixcontact.com/us/products/1827716>



PCB connector, nominal cross section: 1.5 mm², color: green, nominal current: 8 A, rated voltage (III/2): 160 V, contact surface: Tin, contact connection type: Socket, number of potentials: 3, number of rows: 1, number of positions: 3, number of connections: 3, product range: MC 1,5/...-STF, pitch: 3.81 mm, connection method: Screw connection with tension sleeve, screw head form: L Slotted, conductor/PCB connection direction: 0 °, plug-in system: COMBICON MC 1,5, locking: Screw locking mechanism, mounting: Screw flange, type of packaging: packed in cardboard

KGG-MC 1,5/ 3 - Cable housing

1834356

<https://www.phoenixcontact.com/us/products/1834356>



IMC 1,5/ 3-ST-3,81 - PCB connectors

1857896

<https://www.phoenixcontact.com/us/products/1857896>



PCB connector, nominal cross section: 1.5 mm², color: green, nominal current: 8 A, rated voltage (III/2): 160 V, contact surface: Tin, contact connection type: Pin, number of potentials: 3, number of rows: 1, number of positions: 3, number of connections: 3, product range: IMC 1,5/..-ST, pitch: 3.81 mm, connection method: Screw connection with tension sleeve, screw head form: L Slotted, conductor/PCB connection direction: 0 °, plug-in system: COMBICON MC 1,5, locking: without, mounting: without, type of packaging: packed in cardboard

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com