
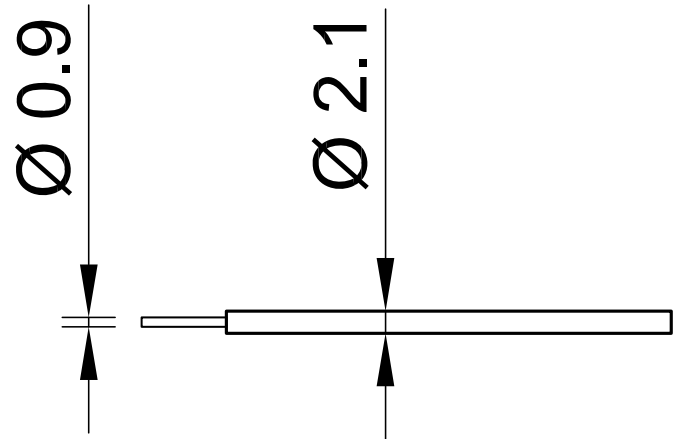


FLEXI-E 0,50

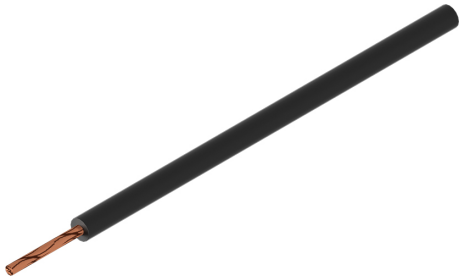

Item number 60.7004-*

Highly flexible basic insulated stranded wire 0,50 mm².

Technical data	
Rated Values	AC 500 V, 10 A
Standard color(s) *	21 22 23 24 25 29
Lead insulation	PVC
Temperature range	-10 °C ... +70 °C
Strand design (n x Ø mm)	129 x 0,07
Lead weight	8.3 kg/km
Conductor diameter	0.9 mm
Cable diameter	2.1 mm
Insulation thickness	0.6 mm
Approvals	CE, UKCA, EAC