

CATEGORIES

For more information or to request assistance, please contact sales@precidip.com

« Back to search results **YOUR SELECTED PRODUCT**

Screw-machined Contacts

01806


Socket contacts

For other versions than the listed available standard types, please contact PRECI-DIP

SPECIFICATIONS:

Socket contact without solder tail / SMD socket contact

- Press-in mount into dia 1.04 mm hole
- Materials: body brass, contact clip BeCu
- Electrical contact resistance max. 20 milliohms
- Mechanical life min. 500 cycles

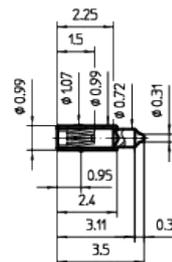

Metric

AVAILABLE STANDARD TYPES

Ordering Part Number	RoHS	Plating Body	Plating Clip	Insertion	Extraction	Dia.Gauge	Max Current
01806-77-5410	RoHS	Flash Au	Flash Au	0.20 N	0.15 N	0.30 mm	3.0 A

CAD CATALOG

- Literature
- Catalog
- CAD catalog

ABOUT PRECI-DIP

- Career
- Contact
- Events

OTHER INFO

- Feedback
- Legal disclaimer
- Cross references

NEWSLETTER

Stay informed!

This website is using cookies for statistics, site optimization and retargeting purposes. You consent to our cookies if you continue to use this website. [Read more here.](#)

powered by arrow