


Specification Sheet

Part Number: 157-00343

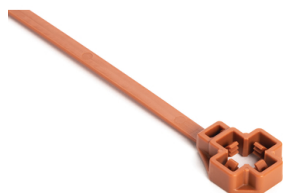

Low-profile head allows mounts to stack, providing more mounting versatility from a single stud.

Four-pawl, three-tooth design delivers outstanding stud retention to keep bundles secure.

PA46 material option allows use in high-heat applications.

Low Profile M10 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 3500/pkg

Article Number 157-00343

Type T80ROSLPSB10U

Color Brown (BN)

Quantity Per pack

Product Description One-piece mounting ties offer a complete solution by both bundling cable and at the same time providing a mounting solution. HellermannTyton's one-piece mounting ties offer the ideal combination of high specification materials and superior design to suit the mounting and bundling needs of complex applications.

Short Description Low Profile M10 Stud Mount Tie, 7.5" Tie, 80lb Tensile Strength, PA46, Brown, 3500/pkg

Global Part Name T80ROSLPSB10U-PA46-BN

Minimum Tensile Strength (Imperial) 80

Minimum Tensile Strength (Metric) 355

Length L (Imperial) 8.5

Length L (Metric) 215.9

Fixation Method Stud Mount

Identification Plate Position none

Releasable Closure No

Tie Closure plastic pawl

Width W (Imperial) 0.82

Width W (Metric) 20.8

Bundle Diameter Min (Imperial) 0.14

Bundle Diameter Min (Metric) 3.5

Bundle Diameter Max (Imperial) 1.97

Bundle Diameter Max (Metric) 50.0

Cable Ties 157-00343

Height H (Imperial)	0.28
Height H (Metric)	7.0
Mounting Hole Diameter D (Imperial)	0.39 x 0.06 "
Mounting Hole Diameter D (Metric)	M10 x 1.5
Stud Diameter (Metric)	10.0 mm
Stud Diameter (Imperial)	0.39
Material	Polyamide 4.6 (PA46)
Material Shortcut	PA46
Flammability	UL 94 V-2
Halogen Free	Yes
UV Resistant (Yes/No)	No
Use Conditions	For Indoor Use Only
Operating Temperature	-40°F to +266°F (-40°C to +130°C)
Reach Compliant (Article 33)	Yes
ROHS Compliant	Yes

Package Quantity (Imperial)	3500
Package Quantity (Metric)	3500
Customs Number	3926909988

7930 N. Faulkner Road, Milwaukee, WI 53224
Phone: (800) 537-1512 | Email: corp@htamericas.com

© 2026 HellermannTyton. All Rights Reserved.

[Contact Us](#) [RoHS/WEEE Compliance](#) [Privacy Policy](#) [Cookie Policy](#) [Terms and Conditions](#)