




PRODUCT NUMBER: 898-43-024-90-310000

www.mill-max.com
DATA SHEET

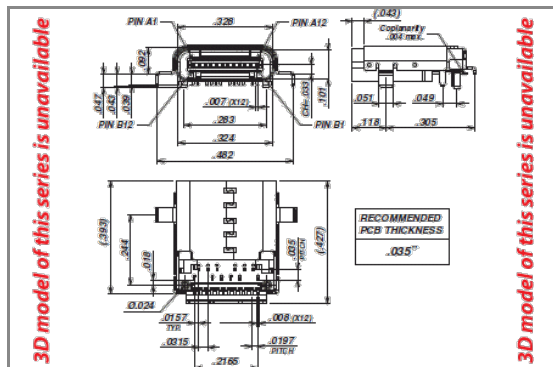

898-43-024-90-310000- SPECIFICATIONS

General Info	
Description:	Type C USB 3.1; Mid-Mount Hybrid
Type:	USB
Category:	Connector
Mounting Style:	Mid-Mount Hybrid
# Pins:	24
Packaging ¹ :	Tape & Reel
Qty Reel:	900
Rows:	Single USB
Product Lifecycle:	Active

Environmental Specs	
Temperature Range:	-40/+85° C
RoHS ² :	Yes

Materials

Shell Plating: 200 μ " Tin (matte finish) over 100 μ " Nickel

Inner Plating: 30 μ " Gold over 50 μ " Nickel

NOTES:

1. 13" (330 mm) Reel
2. Mill-Max products labeled with the RoHS symbol are compliant with all three ROHS Directives. All of our products previously described as RoHS (2002/95/EC) and RoHS-2 (2011/65/EC) are also compliant with RoHS-3 (2015/863/EU).

ADDITIONAL NOTES AND SPECIFICATIONS

In the interest of improved design, quality and performance , Mill-Max reserves the right to make changes in its specifications without prior notice. Specifications and tolerances are provided wherever possible. The tolerance on dimensions of critical to function features is typically held tighter than the stated standard tolerances, such as press-fits, holes and lengths affecting the coplanarity of SMT products. Due to the wide variety of interconnects Mill-Max offers, the specific tolerances vary from product to product. If you need information regarding the tolerance of a particular part, please contact Technical Services.

RELATED LINKS AND DOCUMENTS

Product Discontinuation Notice: (<https://www.mill-max.com/sites/default/files/external/assets/2020-10/898-43-024-90-310000-pdn-20-1022a.pdf>)

Environmental Compliance: (<https://www.mill-max.com/rohs>)