

LPDDR4

K4F8E3S4HD-MGCL



Overview

Specifications

Related resources

Related insights

Versatile LPDRAM for mobile solutions

Samsung's groundbreaking LPDDR4 transfers data faster with less energy, multiplying design options for ultra-thin devices, AI, VR and wearables.

Specifications

Capacity	8 Gb	Org.	x32
Speed	4266 Mbps	Voltage	1.8 / 1.1 / 1.1 V
Temp.	-25 ~ 85 °C	Package	200FBGA
Product Status	Mass Production		

SEE ALL


Related insights



How Samsung Memory Is Fueling the Evolution of Automotive

Samsung is providing powerful automotive memory solutions that are empowering the development of more sophisticated autonomous driving, in-vehicle infotainment and connectivity.

LEARN MORE >

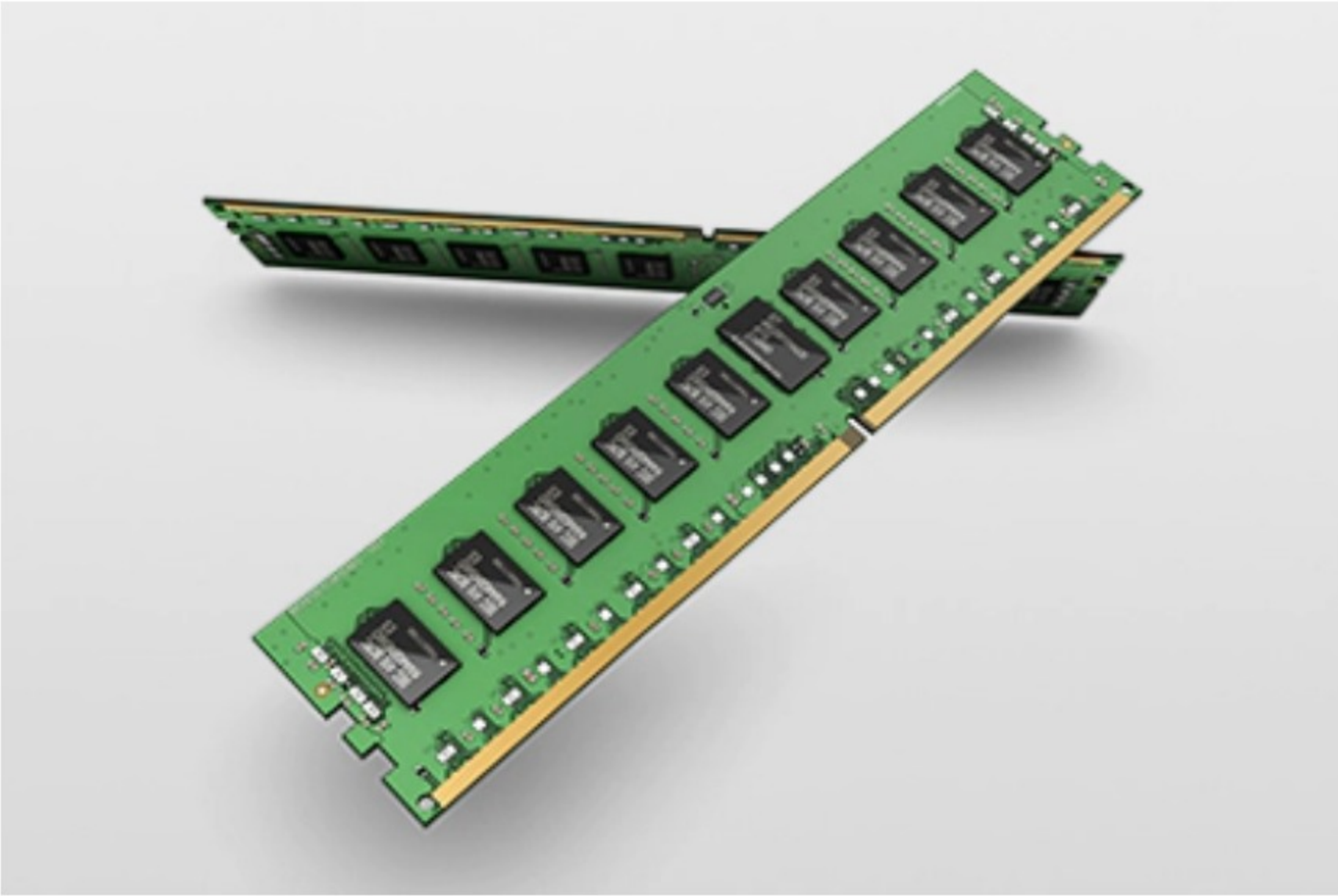

Samsung Announces Industry's First EUV DRAM with Shipment of First Million Modules

Samsung's new EUV-based DRAM modules have completed global customer evaluations.

LEARN MORE >



All product specifications reflect internal test results and are subject to variations by user's system configuration. All product images shown are for illustration purposes only and may not be an exact representation of the product. Samsung reserves the right to change product images and specifications at any time without notice.