



Products | Custom Design | Media | Optic Types | Where To Buy | Contact Us



sales@carclo-optics.com



+44 1753 575 011

LinkedIn



26.5mm Narrow Spot Plain TIR (10048)





Part no.	10048
Drawing no.	60367
Family	26.5mm
Type	TIR
Diameter	26.5
Beam	Narrow Spot
Finish	Plain




LEDs & Performances

Select LED to view available holders

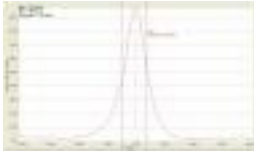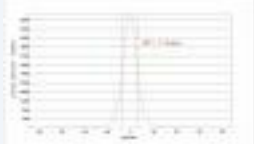Manu.	Performance Data	Images	IES/STP
 Avago Jade White	Eff: 88.8 FWHM: 8 Cd/Im: 20.1		View
 Cree XLamp CSP XD16 Cool White	Eff: 86 FWHM: 7 Cd/Im: 37.2	 	View
	Eff: 83.5 FWHM: 17		View

[Cree XLamp MH-B White](#)

Cd/lm: 6.4

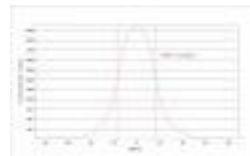

[Cree XLamp MK-R White](#)

FWHM: 18
Cd/lm: 6.8



[View](#)



[Cree XLamp MX-6 White](#)

Eff: 89.1
FWHM: 11
Cd/lm: 16.7

 


[View](#)



[Cree XLamp XB-D White](#)

Eff: 85.1
FWHM: 7
Cd/lm: 48.9



[View](#)



[Cree XLamp XHP-50 Gen 2 White](#)

Eff: 82.5
FWHM: 20
Cd/lm: 5.7





[View](#)



[Cree XLamp XHP-50 White](#)

Eff: 84
FWHM: 17
Cd/lm: 5.54

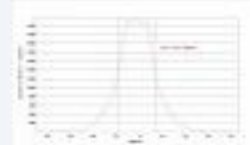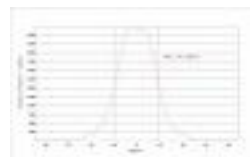


[View](#)



[Cree XLamp XHP35 HI White](#)

Eff: 83.3
FWHM: 10
Cd/lm: 21.3

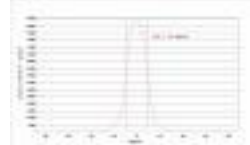


[View](#)



[Cree XLamp XHP35 White](#)

Eff: 82
FWHM: 14
Cd/lm: 10.7

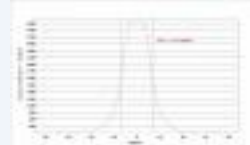


[View](#)



[Cree XLamp XM-L White](#)

Eff: 85.9
FWHM: 12
Cd/lm: 16.8

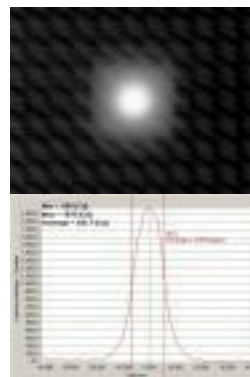


[View](#)



[Cree XLamp XM-L2 White](#)

Eff: 88.5
FWHM: 12
Cd/lm: 19.6

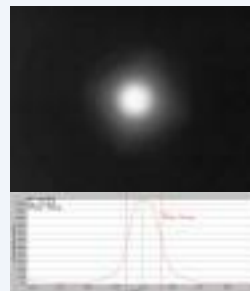

[View](#)



[Cree XLamp XP-C White](#)

Eff: 87.3
FWHM: 4
Cd/lm: 150.8




[View](#)



[Cree XLamp XP-E White](#)

Eff: 86.9
FWHM: 6
Cd/lm: 46.4

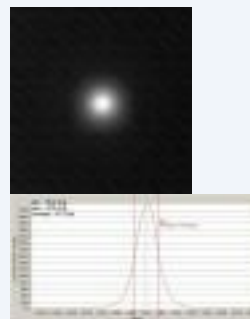


[View](#)




[Cree XLamp XP-E2 White](#)

Eff: 89.2
FWHM: 5
Cd/lm: 68.8

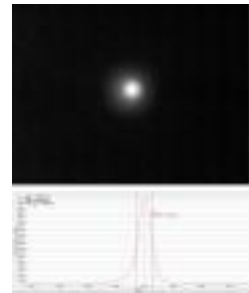

[Cree XLamp XP-G White](#)

Eff: 85.8
FWHM: 9
Cd/lm: 31.2

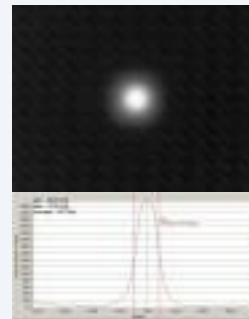


[View](#)



[Cree XLamp XP-G2 White](#)

FWHM: 8
Cd/lm: 37.3

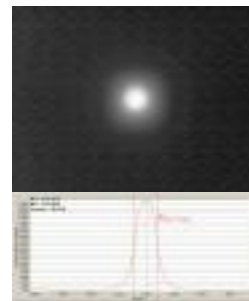


[View](#)



[Cree XLamp XP-G3 White](#)

Eff: 83
FWHM: 10
Cd/lm: 20.7


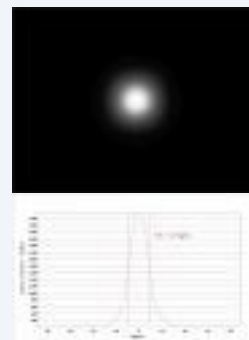


[View](#)



[Cree XLamp XP-L HI White](#)

Eff: 83.4
FWHM: 8
Cd/lm: 27.6

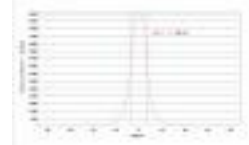
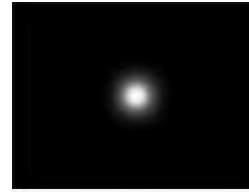


[View](#)



[Cree XLamp XP-L White](#)

Eff: 83.3
FWHM: 12
Cd/lm: 14.3

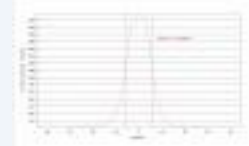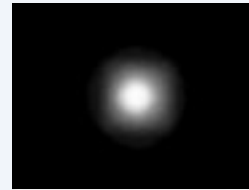


[View](#)



[Cree XLamp XP-L2 White](#)

Eff: 84.5
FWHM: 14
Cd/lm: 12.8

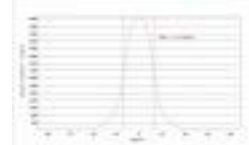



[View](#)

Eff: 86



[Cree XLamp XQ-A Blue](#)

FWHM: 3
Cd/lm: 224.3

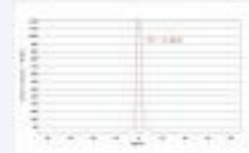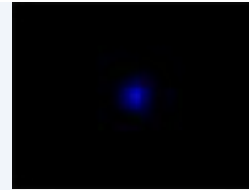


[View](#)



[Cree XLamp XQ-A Green](#)

Eff: 86
FWHM: 3
Cd/lm: 205.1

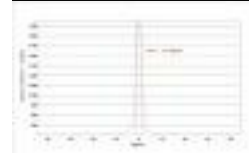


[View](#)




[Cree XLamp XQ-A Red](#)

Eff: 86
FWHM: 3
Cd/lm: 152.5

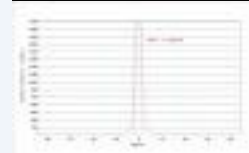

[View](#)


Eff: 83
FWHM: 3

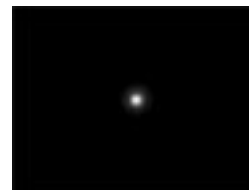

[View](#)





Cd/lm: 206

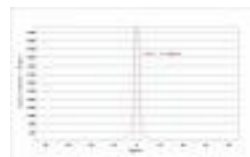

[Cree XLamp XQ-A White](#)



Eff: 85
FWHM: 4
Cd/lm: 89.1

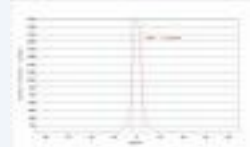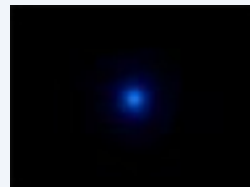


[Cree XLamp XQ-E HI Blue](#)

[View](#)



Eff: 85
FWHM: 4
Cd/lm: 88.9

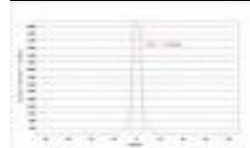


[Cree XLamp XQ-E HI Green](#)

[View](#)



Eff: 85
FWHM: 4
Cd/lm: 94.6

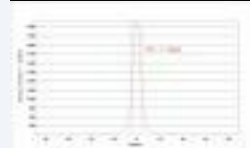



[Cree XLamp XQ-E HI Red](#)

[View](#)



[Cree XLamp XQ-E HI White](#)

Eff: 83
FWHM: 4
Cd/lm: 109

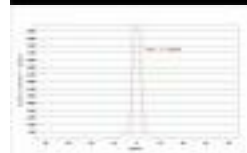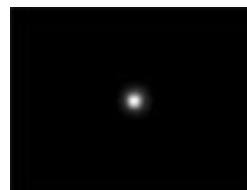

[View](#)



[Cree XLamp XR White](#)

Eff: 88.5
FWHM: 10
Cd/lm: 13.8

[View](#)



[Cree XLamp XR-C White](#)

Eff: 88.5
FWHM: 5
Cd/lm: 52.3

[View](#)



[Cree XLamp XR-E White](#)


Eff: 88.3
FWHM: 6
Cd/lm: 42.2

[View](#)



[Cree XLamp XT-E HE White](#)

Eff: 85.5
FWHM: 9
Cd/lm: 26.1

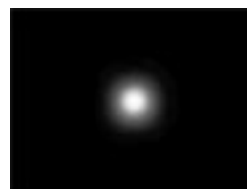


[View](#)



[Cree XLamp XTE White](#)

Eff: 88.9
FWHM: 8
Cd/lm: 34.3

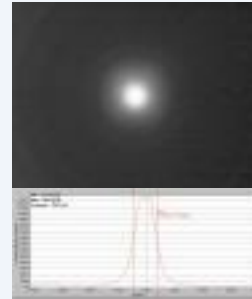


[View](#)



[Everlight Shuen White](#)

Eff: 87.8
FWHM: 8
Cd/lm: 29.9

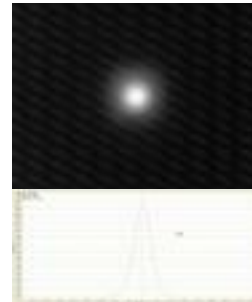


[View](#)



[LEDEngin 3W White](#)

Eff: 85.6
FWHM: 8
Cd/lm: 18.6

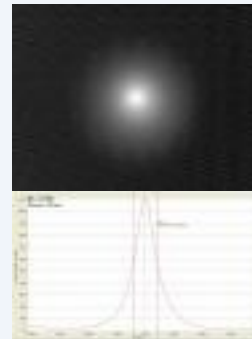


[View](#)



[LEDEngin 5W White](#)

Eff: 84.9
FWHM: 8
Cd/lm: 20.6

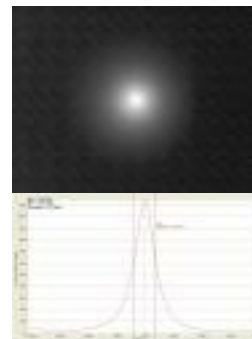


[View](#)



[LG 3535LG White](#)

FWHM: 8
Cd/lm: 35.1

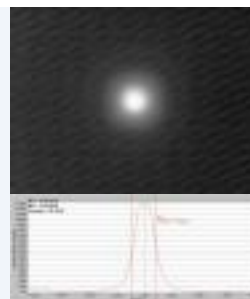

[View](#)



[Lite-On R38386AS - S R38 IR](#)

Eff: 91.5
FWHM: 6
Cd/lm: 50




[View](#)



[LUMILEDS LUXEON 3030 White](#)

Eff: 81
FWHM: 7
Cd/lm: 33.71

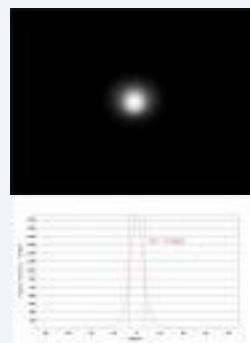

[View](#)



[LUMILEDS LUXEON 3535 HV White](#)

Eff: 83.3
FWHM: 5
Cd/lm: 36.6





[View](#)



[LUMILEDS LUXEON 3535 L White](#)

Eff: 83
FWHM: 6.3
Cd/lm: 32.21

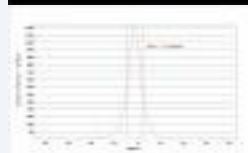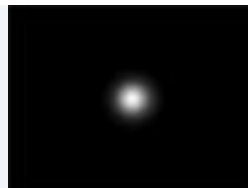


[View](#)



[LUMILEDS LUXEON 3535L Blue](#)

Eff: 85.2
FWHM: 4
Cd/lm: 67.9


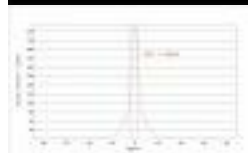


[View](#)



[LUMILEDS LUXEON 3535L Green](#)

Eff: 86
FWHM: 3
Cd/lm: 84.6

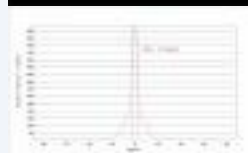
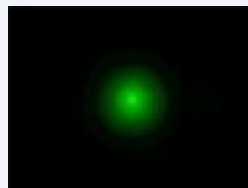


[View](#)



[LUMILEDS LUXEON 3535L Red](#)

Eff: 86
FWHM: 2
Cd/lm: 157.5

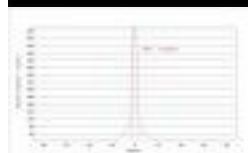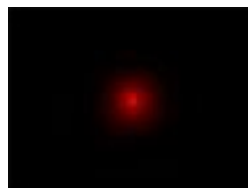


[View](#)



[LUMILEDS LUXEON 5050 White](#)

Eff: 86
FWHM: 16
Cd/lm: 8.9

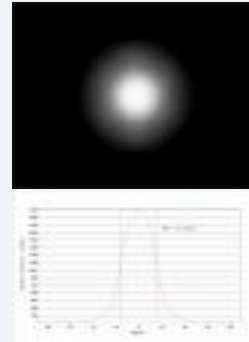


[View](#)



[LUMILEDS LUXEON C Blue](#)

Eff: 81
FWHM: 6
Cd/lm: 53.7

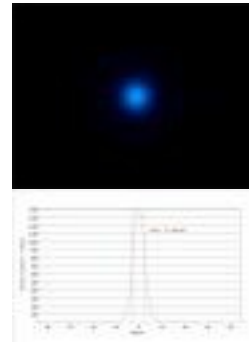

[View](#)



[LUMILEDS LUXEON C High-Power](#)

Eff: 78.9
FWHM: 6
Cd/lm: 42.1




[View](#)



[LUMILEDS LUXEON C Lime](#)

Eff: 82
FWHM: 5
Cd/lm: 54


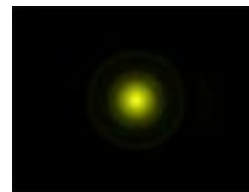


[View](#)



LUMILEDS LUXEON C Red

Eff: 80
FWHM: 5
Cd/lm: 38.9

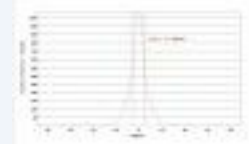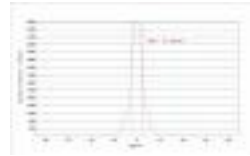


[View](#)



LUMILEDS LUXEON C White

Eff: 83.5
FWHM: 4
Cd/lm: 106.2


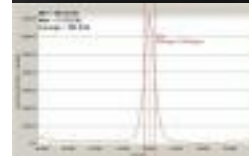


[View](#)



LUMILEDS LUXEON CSP 05 White

Eff: 82
FWHM: 5
Cd/lm: 40.26

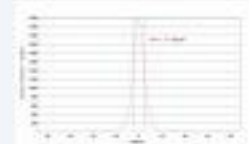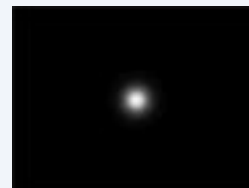



[View](#)

Eff: 82



[LUMILEDS LUXEON CSP 10 White](#)

FWHM: 7
Cd/lm: 24.3

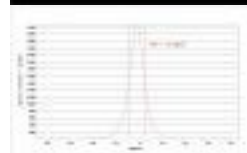
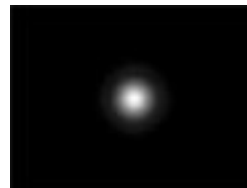


[View](#)



[LUMILEDS LUXEON CZ](#)

Eff: 87
FWHM: 4 x 4
Cd/lm: 114.4

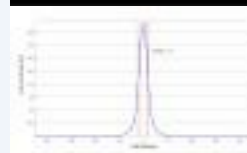
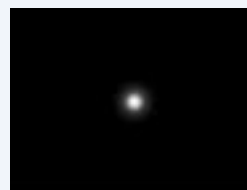


[View](#)



[LUMILEDS LUXEON IR Compact 850nm](#)

Eff: 90.5
FWHM: 5
Cd/lm: 67

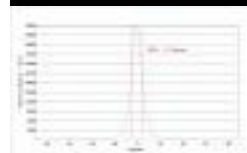
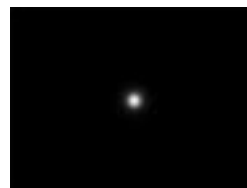


[View](#)



[LUMILEDS LUXEON IR Domed 60 Degree](#)

Eff: 89
FWHM: 7
Cd/lm: 41.7

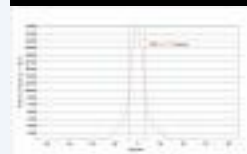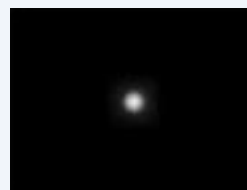

[View](#)



[LUMILEDS LUXEON IR Domed 90 Degree](#)

Eff: 90
FWHM: 7
Cd/lm: 42.5




[View](#)



[LUMILEDS LUXEON M White](#)

Eff: 83
FWHM: 18
Cd/lm: 6.5

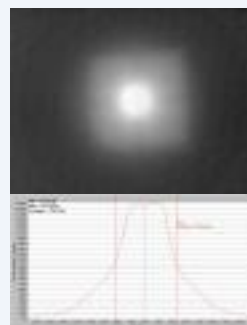


[View](#)



[LUMILEDS LUXEON MX White](#)

Eff: 84
FWHM: 16
Cd/lm: 5.6

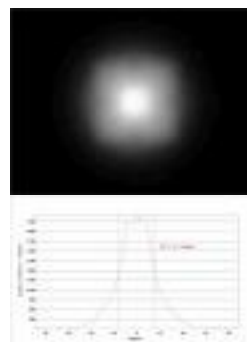





[View](#)



Eff: 84
FWHM: 10



  
[View](#)

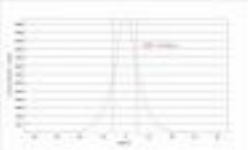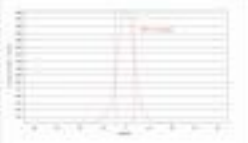LUMILEDS LUXEON MZ White	Cd/lm: 10.4		
 LUMILEDS LUXEON Q White	Eff: 81.4 FWHM: 8 Cd/lm: 24.4	 	View
 LUMILEDS LUXEON R White	Eff: 86.1 FWHM: 9 Cd/lm: 30.6	 	View
 LUMILEDS LUXEON Rebel ES White	Eff: 86.1 FWHM: 9 Cd/lm: 30.6	 	View
 LUMILEDS LUXEON Rebel White	Eff: 85.9 FWHM: 8 Cd/lm: 44.8		



[LUMILEDS LUXEON T White](#)

Eff: 86.1
FWHM: 9
Cd/lm: 30.6

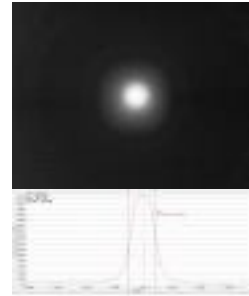


[View](#)



[LUMILEDS LUXEON TX White](#)

Eff: 82.9
FWHM: 8
Cd/lm: 27.3

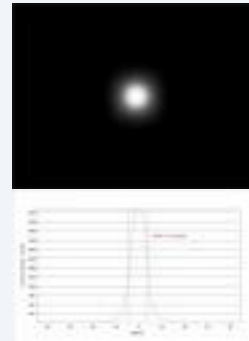


[View](#)



[LUMILEDS LUXEON V White](#)

Eff: 83.5
FWHM: 13
Cd/lm: 11.4

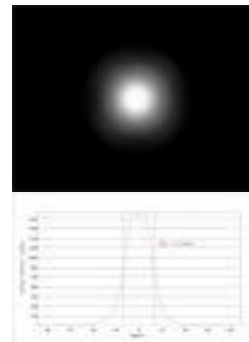

[View](#)




[LUMILEDS LUXEON V2 White](#)

Eff: 86.5
FWHM: 9
Cd/lm: 24.3





[View](#)

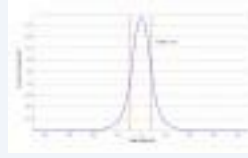

[LUMILEDS LUXEON Z ES White](#)

Eff: 83
FWHM: 6
Cd/lm: 48

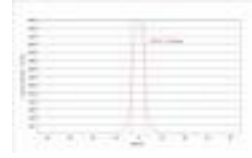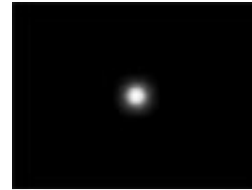


[View](#)



[LUMILEDS LUXEON Z White](#)

Eff: 83
FWHM: 4
Cd/lm: 73.5

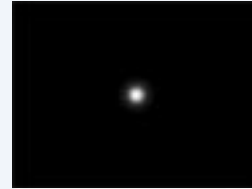

[View](#)



[Nichia 219 White](#)

FWHM: 9
Cd/lm: 30.9




[View](#)

Eff: 84



[Nichia 229A White](#)

FWHM: 14
Cd/lm: 11.1

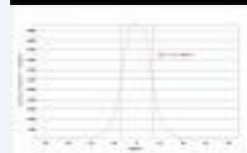


[View](#)



[Nichia 757G White](#)

Eff: 86
FWHM: 8
Cd/lm: 29.6


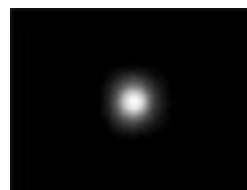


[View](#)



[Nichia NCSW E17A White](#)

Eff: 81
FWHM: 6
Cd/lm: 60.2

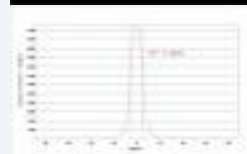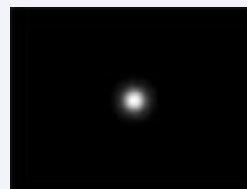


[View](#)




[Nichia NCSW E17A White](#)

Eff: 85.5
FWHM: 6
Cd/lm: 60

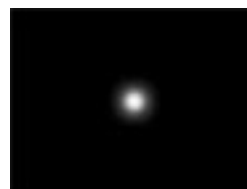

[View](#)

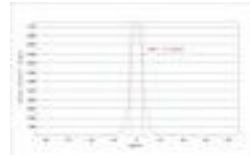

[Nichia NF2W 385AR-V2 White](#)

Eff: 86
FWHM: 9
Cd/lm: 23




[View](#)



[Nichia NFMW 481AR White](#)

Eff: 77.5
FWHM: 15
Cd/lm: 9.1

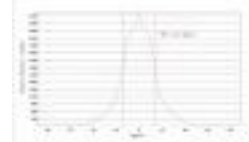


[View](#)



[Nichia NFMW 484AR White](#)

Eff: 86
FWHM: 16
Cd/lm: 7.6

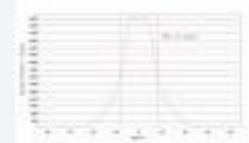

[View](#)



[Nichia NFMW 486AR White](#)

Eff: 86.5
FWHM: 15
Cd/lm: 8.7





[View](#)



[Nichia NFMW 488AR White](#)

Eff: 86
FWHM: 16
Cd/lm: 7.8

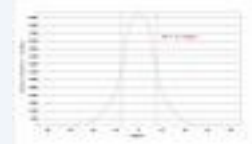
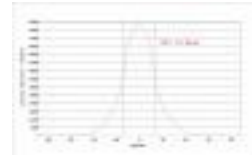


[View](#)



[Nichia NVSL 219B White](#)

Eff: 85
FWHM: 7
Cd/lm: 39.5

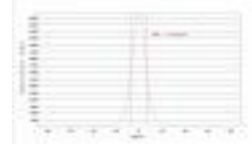
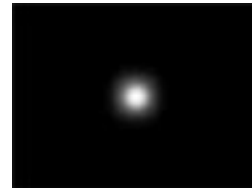


[View](#)



[Nichia NVSW 219C White](#)

Eff: 85
FWHM: 10
Cd/lm: 83.6

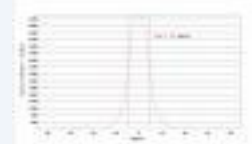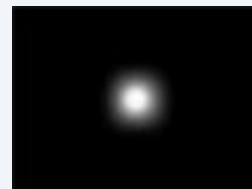

[View](#)

Eff: 84.5



[Nichia NVSW 319A White](#)

FWHM: 12
Cd/lm: 16.3





[View](#)



[Nichia NVSW E21A White](#)

Eff: 82
FWHM: 7
Cd/lm: 36.42

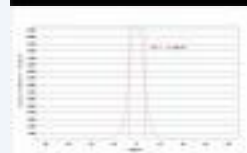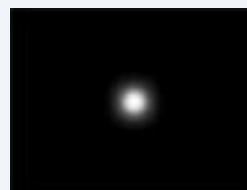


[View](#)



[Nichia Top Emitting NCSL 119-H3 White](#)

Eff: 86.5
FWHM: 6
Cd/lm: 56.6

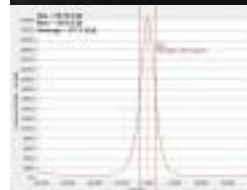

[View](#)




[Nichia Top Emitting NFSW 036 White](#)

Eff: 87.1
FWHM: 4
Cd/lm: 71.1




[View](#)

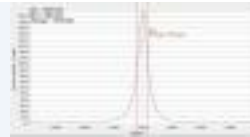

[Nichia Top Emitting NS3W 183T White](#)

Eff: 86.1
FWHM: 11
Cd/lm: 14.4


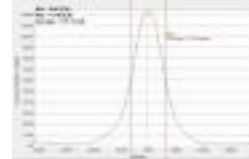


[View](#)



[Osram OS DURIS E 2835 White](#)

Eff: 86
FWHM: 6
Cd/lm: 40.1

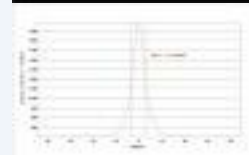
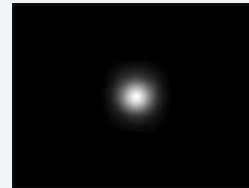


[View](#)



[Osram OS DURIS E2 White](#)

Eff: 83
FWHM: 3
Cd/lm: 59.6

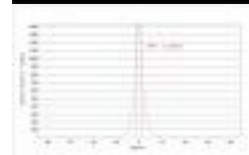
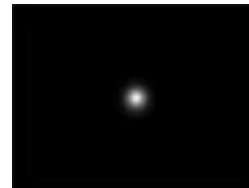


[View](#)



[Osram OS DURIS E3 White](#)

Eff: 86.8
FWHM: 4
Cd/lm: 54.6

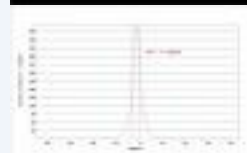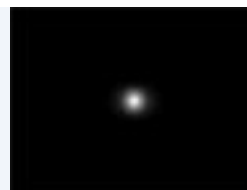


[View](#)



[Osram OS DURIS P10 White](#)

Eff: 84.2
FWHM: 15
Cd/lm: 5.7

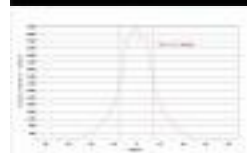


[View](#)



[Osram OS DURIS P8 White](#)

Eff: 83.3
FWHM: 8
Cd/lm: 29.6

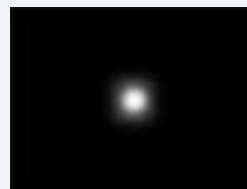


[View](#)



[Osram OS DURIS S10 White](#)

Eff: 85.5
FWHM: 19
Cd/lm: 4.8


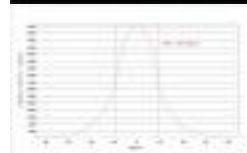


[View](#)



[Osram OS DURIS S2 White](#)

Eff: 87.3
FWHM: 6
Cd/lm: 34.9

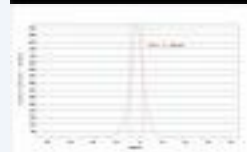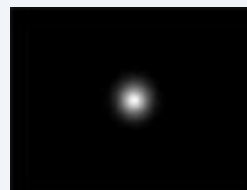


[View](#)



[Osram OS DURIS S5 Deep Blue](#)

Eff: 85
FWHM: 7
Cd/lm: 39.9

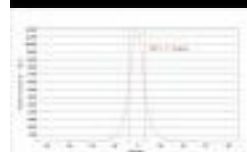


[View](#)



[Osram OS DURIS S5 Green](#)


Eff: 87
FWHM: 7
Cd/lm: 41.6

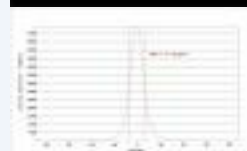

[View](#)




Eff: 88
FWHM: 6

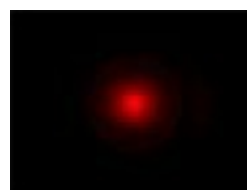

[View](#)

[Osram OS DURIS S5 Red](#)



Cd/lm: 50.4

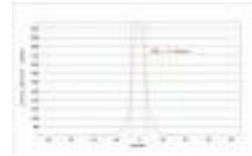

OSRAM
Opto Semiconductors

[Osram OS DURIS S5 White](#)

Eff: 83
FWHM: 7
Cd/lm: 31.43

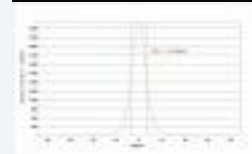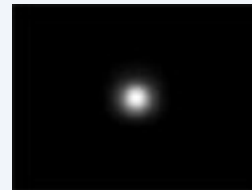


[View](#)

OSRAM
Opto Semiconductors

[Osram OS Osconiq P3737 White](#)

Eff: 84.5
FWHM: 11
Cd/lm: 15.2


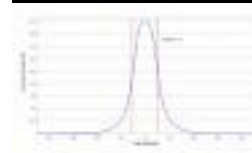


[View](#)

OSRAM
Opto Semiconductors

[Osram OS OSLON Black SFH 4725S IR](#)

Eff: 92.5
FWHM: 6
Cd/lm: 52.9

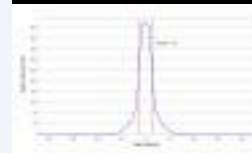
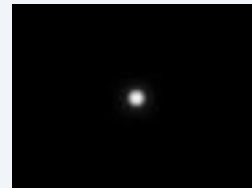


[View](#)



[Osram OS OSLON Pure CSP GW VJLPE1 White](#)

Eff: 87
FWHM: 4
Cd/lm: 134.4

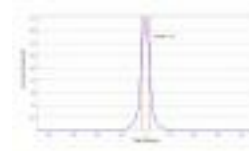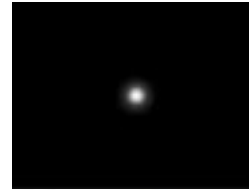

[View](#)



[Osram OS OSLON Square Flat White](#)

Eff: 86.5
FWHM: 6
Cd/lm: 55.4




[View](#)



[Osram OS OSLON Square Gen 3 White](#)


Eff: 83.3
FWHM: 8
Cd/lm: 29.5

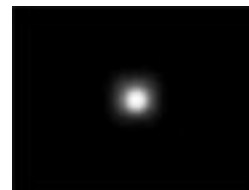

[View](#)




Eff: 83.1
FWHM: 7
Cd/lm: 29.7

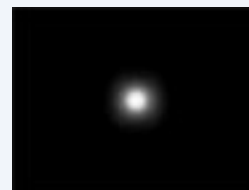


[View](#)

Osram OS OSLON Square White

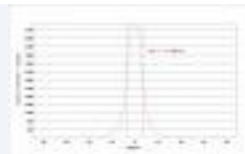

Osram OS OSLON SSL 80 degree White

Eff: 86.5
FWHM: 6
Cd/lm: 58.4

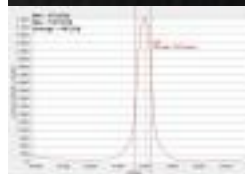


[View](#)



Plessey PLW 7070GA White

Eff: 84
FWHM: 21
Cd/lm: 5

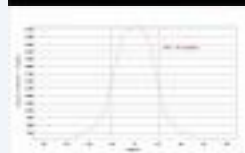

[View](#)



Samsung 3535 LH351A White


Eff: 86.1
FWHM: 8
Cd/lm: 39.6







[View](#)



Eff: 83
FWHM: 9

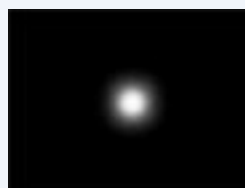

[View](#)

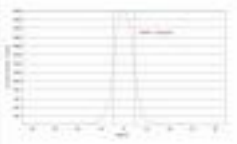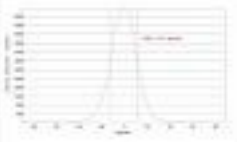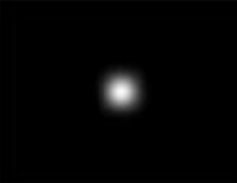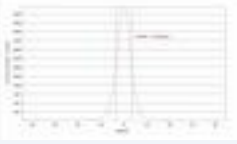Samsung 3535 LH351B White	Cd/lm: 21.5		
 Samsung 3535 LH351D White	Eff: 86 FWHM: 13 Cd/lm: 12.5	 	View
 Samsung 3535 LH351Z White	Eff: 83.3 FWHM: 7 Cd/lm: 32	 	View
 Samsung CSP LH181B White	Eff: 87 FWHM: 8 Cd/lm: 28.9	 	View



[Samsung CSP LH231B White](#)

Eff: 87
FWHM: 10
Cd/lm: 20.5





[View](#)



[Samsung CSP LM101B White](#)

Eff: 87
FWHM: 5
Cd/lm: 66.9

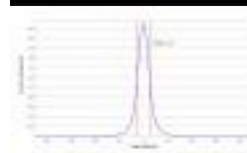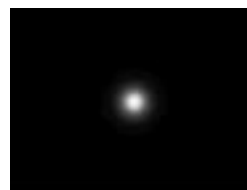

[View](#)



[Samsung WH5 White](#)

Eff: 88.2
FWHM: 8
Cd/lm: 18.9




[View](#)



[Seoul CSP SZ8Y22 White](#)

Eff: 87
FWHM: 9 x 9
Cd/lm: 20.8


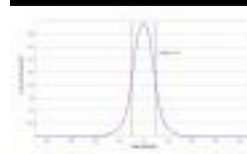


[View](#)



[Seoul CSP SZ8Y22P White](#)

Eff: 87
FWHM: 10
Cd/lm: 19.9

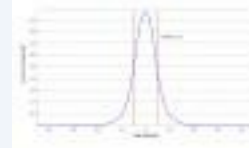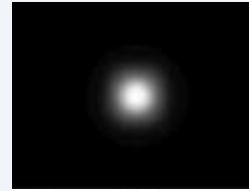


[View](#)



[Seoul CSP SZ8Y50 White](#)

Eff: 86.5
FWHM: 21
Cd/lm: 5.1

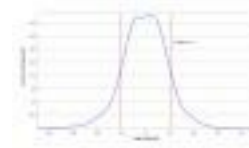

[View](#)



[Seoul MidPower MJT3030 White](#)

Eff: 83
FWHM: 6
Cd/lm: 30.3




[View](#)



[Seoul MidPower MJT4040 White](#)

Eff: 84
FWHM: 9
Cd/lm: 15.3


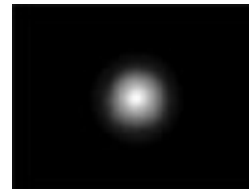


[View](#)



[Seoul MJT 5050 White](#)

Eff: 83.3
FWHM: 13
Cd/lm: 11.7

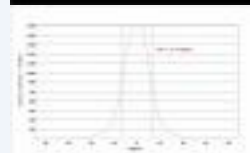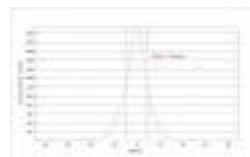

[View](#)



[Seoul P4 White](#)

Eff: 89.1
FWHM: 7
Cd/lm: 27





[View](#)



[Seoul P4 White](#)

Eff: 82.34
FWHM: 8
Cd/lm: 18.6

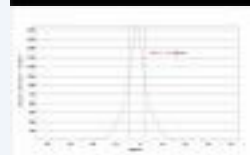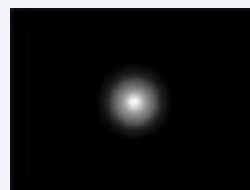



[View](#)

Eff: 86



[Seoul SZ8Y11 White](#)

FWHM: 5 x 5
Cd/lm: 57.7

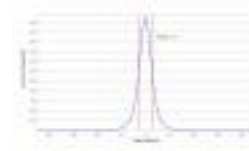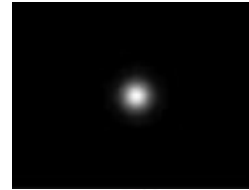


[View](#)



[Seoul SZ8Y15 White](#)

Eff: 86
FWHM: 5
Cd/lm: 80


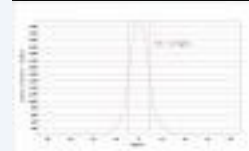


[View](#)



[Seoul SZ8Y19 White](#)

Eff: 84
FWHM: 9
Cd/lm: 21.24

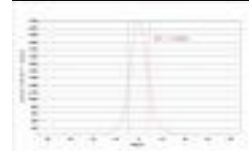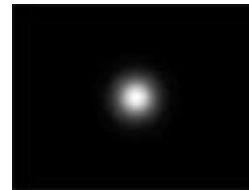


[View](#)



[Seoul Z - Power Z5M White](#)

FWHM: 7
Cd/lm: 35.4

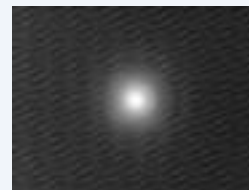


[View](#)



[SSC Z - Power Z1 White](#)

Eff: 87.8
FWHM: 11
Cd/lm: 11.8

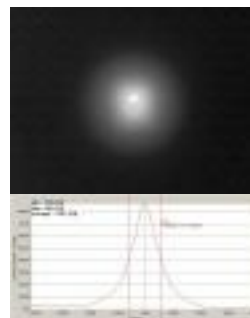


[View](#)



[SSC Z - Power Z5 White](#)

Eff: 88.3
FWHM: 6
Cd/lm: 71.8

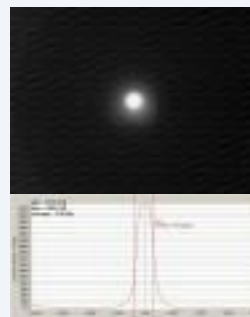


[View](#)



[SSC Z - Power Z5P White](#)

Eff: 87.3
FWHM: 7
Cd/lm: 53.7

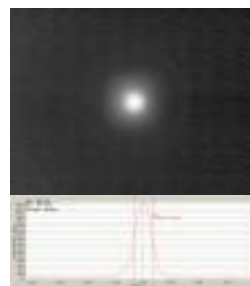


[View](#)



[Toshiba TL 1L2 White](#)

Eff: 83
FWHM: 8
Cd/lm: 25.4


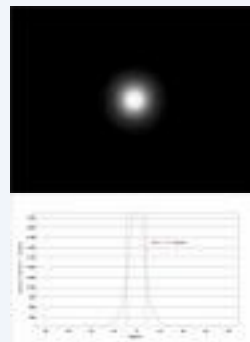


[View](#)



[Toshiba TL 1L4 White](#)

Eff: 83
FWHM: 9
Cd/lm: 24.3

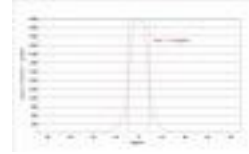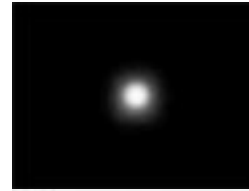

[View](#)