


ITEM NO.	PART NUMBER	DESCRIPTION	QTY.	COMPONENT NOTES
1	30-00934	Wire, 7C BC, 26 AWG, UL20280, 300V, 80C, 5.2 mm, braided shield, FT2, TPU	1	

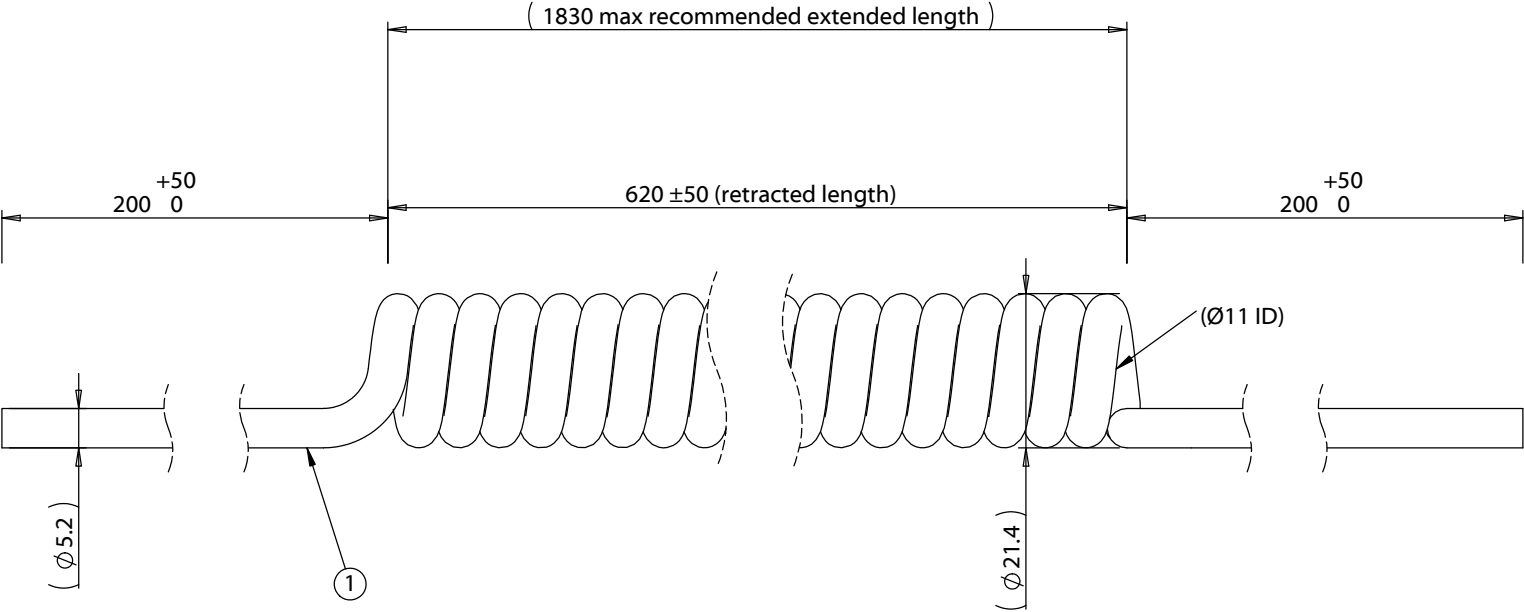

Notes:
Total wire length for resistance calculation: 6500 mm

Revision:	Date:	Description:	Prepared:	Notes: RoHS and REACH compliant Phthalate and halogen free Function test: no open, no short circuit, no intermittent	TENSILITY tel 1.541.323.3228800 877.670.7118 fax 1.541.323.4202web tensility.com		
A	10/17/2018	Initial release	Verified:				
			Dimensions are in millimeters. Tolerances: X: ± 0.5 mm X.X: ± 0.3 mm X.XX: ± 0.05 mm	Description: Coiled cable, 2230 mm, 7C blunt cut to same, 26 AWG, 5.2 mm, TPU, shielded, 30-00934 wire	Size:	Part number:	
					A	31-00103	
					Scale:	1:1	 

5

4

3

2

1