




You are here: [Home](#) ▶ [Piezo Buzzer](#) ▶ [Piezo Indicator](#) ▶ [Panel Mounting](#) ▶ KPEG810SAN

KPEG810SAN

[Print](#)


APPEARANCE DRAWING 外觀尺寸圖

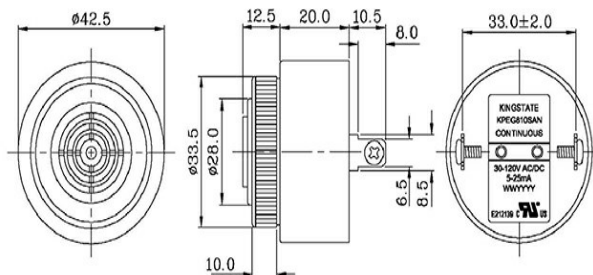

Additional Info

Rated Frequency (Hz):	2800
Rated Voltage (Vp-p / VDC):	Max 120 VAC/VDC
Current Consumption (mA):	Max 25 @120VDC/VAC
Sound Pressure Level (dB):	Min 80dB@60cm/120VDC/VAC
Operating Temperature (°C):	-30 ~ + 85
Storage Temperature (°C):	-40 ~ + 85
Dimension (mm):	Φ42.5X32.5
Tone:	Continuous

 Like [Sign Up](#) to see what your friends like.

Tagged under [Piezo Panel Mounting Indicator 28Khz 120VDC 120VAC](#)

More in this category: [« KPEG750PA](#) [KPEG850SAN »](#)

[back to top](#)

Best view with [Microsoft Internet Explorer 9](#) or above, [Mozilla Firefox](#) or [Google Chrome](#).

版權所有 © 2017 志豐電子 251新北市淡水區中正東路2段69-11號10樓 Tel :+886-2-2809-5651 info@kingstate.com.tw

Copyright © 2017 Kingstate Electronics Corp. 10F, No. 69-11, Sec.2, JhongJheng E. Rd., Damshui Dist, New Taipei City 251, Taiwan