



SIDE VIEW

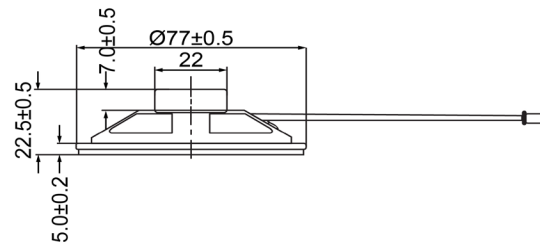

BOTTOM VIEW

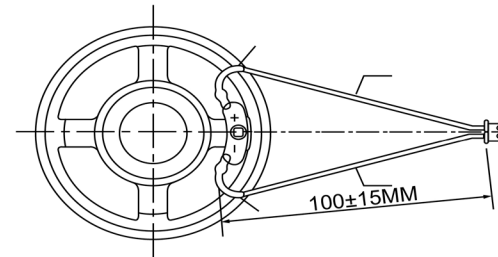

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description	Date	Approved		
Shape	Round		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering	10/21/2013	J.S		
Resonant Frequency	280	(Hz)							
Frequency Range	280 ~ 15,000	(Hz)							
SPL @ 10cm	107	(dBA)							
Impedance	35	(Ohm)							
Cone Material	Paper								
Nominal Power	0.5	(W)							
Max Power	1	(W)							
Mount Type	Flush								
Operating Temperature	-25 ~ +55	°C							
Storage Temperature	-25 ~ +55	°C		Drawn by	Date	Checked by	Date	Approved by	Date
Weight	38	(g)		A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			Dynamic Speaker			SP770235-1			