

Search This Product Catalog

By Keyword

Go


- Manufacturing & Industry
- Product Catalog for Manufacturing & Industry

 - 3M™ Aerosols, Films, Hot Melt, Liquids, & Pastes Solutions
 - 3M™ Bonding Tapes
 - 3M™ Controlled Delivery Products
 - 3M™ Converter Solutions
 - 3M™ Corrosion Protection Products
 - 3M™ Electrical Products
 - 3M™ Industrial Abrasives
 - 3M™ Industrial Tapes
 - 3M™ Occupational Health & Environmental Safety Products
 - 3M™ Packaging Solutions
 - 3M™ Protection Products
 - 3M™ Reclosable Fasteners
 - Dyneon™ Fluoropolymer Products
 - Specialty Fluids

Product Catalog for Manufacturing & Industry>3M™ Electrical Products...3M™ Scotchlok™ Ring Tonques Nylon Insulated Brazed Seam>3M™ Scotchlok™ Ring Tonques Nylon Insulated Brazed Seam, 8 AWG>

3M™ Scotchlok™ Ring Tongue Nylon Insulated Brazed Seam MN8-38RK, Stud Size 3/8

Printer-friendly format

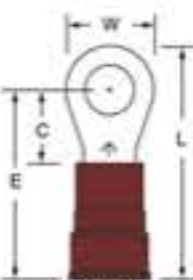

[\[click to enlarge\]](#)

This terminal has a wire range of 8 AWG and a stud size of 3/8. It comes in quantities of 200 per case. A ring is the standard style of tongue. The safest and most reliable; it cannot be removed unless mounting screw is removed.

3M Id : 80-0080-0606-8
GTIN(UPC/EAN) : 0 00 54007 08270 5

Additional Information

A ring is the standard style of tongue. The safest and most reliable; it cannot be removed unless mounting screw is removed.

Learn More . . .

Packaging Data

Email [Ring Tonques - Nylon Insulated Brazed Seam 4 AWG - Product Selection Guide \(PDF 24.8 K\)](#)

Email [Ring Tonques - Nylon Insulated Brazed Seam 8 AWG - Product Selection Guide \(PDF 26.1 K\)](#)

Email [Scotchlok Terminals MN8-10R/S THRU MN4-12R/S - Data Sheet \(PDF 24.3 K\)](#)

Email [Terminal Stud Size Chart - Product Selection Guide \(PDF 14.9 K\)](#)

Please Note:

Adobe® Acrobat® Reader is required to view PDF documents.



Characteristics

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.175 Inch
Barrel Length	0.31 Inch
Barrel Style	Brazed
Brand	Scotchlok
Clearance ©	0.45 Inch
Conductor Sizes	8 AWG
CSA File Number	LR22190
Dimension E	1.08 Inch
Insulation Material	Nylon
Length (L)	1.38 Inch
Maximum Insulation Outer Diameter	0.34 Inch
Packaging	200 per bulk box
RoHS 2011/65/EU Compliant	Yes
Stud Size	3/8 Inch
Terminal Style	Standard
Terminal Type	Ring
Thickness	0.05 Inch
UL File Number	E23438
Width (W)	0.59 Inch