


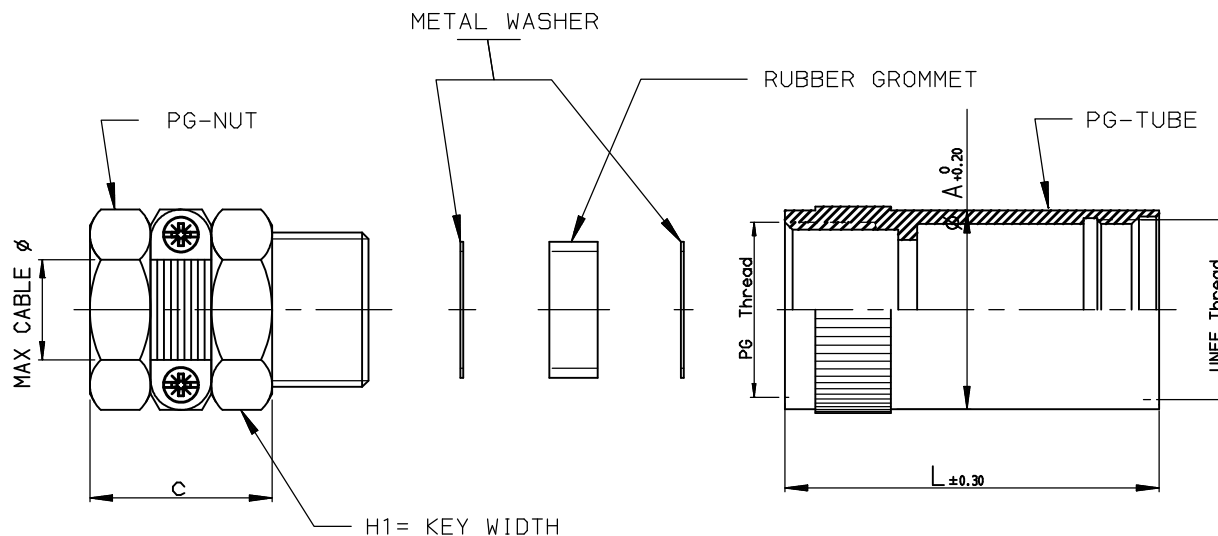

MATERIAL

- PG-TUBE : ALUMINIUM ALLOY, NICKEL PLATED.
- WASHER : ZINC-ELECTROPLATED STEEL.
- SCREWS : STAINLESS STEEL.
- RUBBER GROMMET : NEOPRENE BLACK
- PG-NUT AND PRESSURE BAR : POLYAMIDE - UL94-V0, COULOR BLACK.

NOTES

- ALL PIECES ARE PACKED AS LOOSE PIECES IN PLASTIC BAG

PERFORMANCE CHARACTERISTICS

- DEGREE OF WATER PROTECTION : IP65
- OPERATING TEMPERATURE : -55°C to +125°C
- CORROSION SALT SPRAY : 48 HOURS
- RoHS COMPLIANT

CATALOG NUMBER

UTO--JCPGN

CAT. N°.	UNEF Thread	PG Thread	L	Ø A	C	MAX CABLE Ø	H1
UT010JCPGN	9/16 24-UNEF-2B	PG9	42.1	17.2	14.5	11.2	19.0
UT012JCPGN	11/16 24-UNEF-2B	PG11	42.1	20.8	16.0	13.5	21.0
UT014JCPGN	13/16 20-UNEF-2B	PG13.5	47.1	23.8	17.0	14.5	23.0
UT016JCPGN	15/16 20-UNEF-2B	PG16	50.1	26.9	19.0	16.5	25.0
UT018JCPGN	1-1/16 18-UNEF-2B	PG16	54.2	30.2	19.0	16.5	25.0
UT020JCPGN	1-3/16 18-UNEF-2B	PG21	55.6	33.3	23.5	22.2	32.0
UT022JCPGN	1-5/16 18-UNEF-2B	PG21	62.7	36.2	23.5	22.2	32.0
UT024JCPGN	1-7/16 18-UNEF-2B	PG29	65.0	39.7	30.0	29.5	42.0

B	18/06/12	ADD NOTE : RoHS COMPLIANT		N.--
ISS	DATE	Latest modification by :	ROUILLARD Ch	MOD N°
Designed by: ROUILLARD		date: 04/01/06	Type of drawing: CUSTOMER DRAWING	
Checked by :		SEE DISTRIBUTION LIST	Date : ON DISTRIBUTION LIST	
TITLE : UTO and UTOW Connectors Cable clamp with metal PG tube and plastic strain relief				
SCALE 1	General angular Tolerances --	MATERIAL: See note		N° : --
	General linear Tolerances: --	General machining surface texture: --	Geometric tolerances see NF E 04-552	PROJECT TTR10
	SOURIAU Route Nationale 23 72470 CHAMPAGNE Tel. (33)02.43.54.35.00			This document is the property of SOURIAU It must not be reproduced or communicated without permission in writing from the owners
	FORMAT A3	SOURIAU DRG N° UTOXXJCPGN-C01		
				SHEET 1/1