

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1805800101

Status:

Active

Overview:

LED Array Holders, Dual-Ended Wire Trap

Description:

LED Array Holder for 16.00 by 19.00mm COB, Rectangular Version, Gold (Au) Plating, PBT, One-Piece Design, White

Documents:

3D Model

Application Specification AS-180328-001-001 (PDF)

Drawing (PDF)


Packaging Specification PK-180586-001-001 (PDF)

3D Model (PDF)

Test Summary TS-180155-001-001 (PDF)

Product Specification PS-180580-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

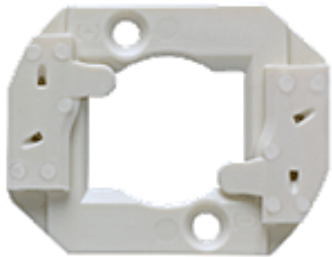

Series image - Reference only

Agency Certification

UL

E345583

General

Product Family

Solid State Lighting

Series

180580

Array Type

Nichia

Beam Angle

N/A

Height

4.10mm

Overview

LED Array Holders, Dual-Ended Wire Trap

Product Name

Wire Trap Holder

Type

LED COB Array Holder

UPC

887191653433

Physical

Base Type

N/A

Color Rendering Index (CRI)

N/A

Correlated Color Temp (CCT)

N/A

Depth

0.90mm

Flammability

94V-0

Lamp Type

N/A

Material - Metal

Copper Alloy

Mounting Style

Screws

Net Weight

8.868/g

Packaging Type

Tray

Electrical

Lamp Wattage - Maximum

N/A

Lumens

N/A

Voltage (Fixture) - Maximum

600V DC

Wiring Style

Poke In Wire Traps

Material Info

Reference - Drawing Numbers

Application Specification

AS-180328-001-001

Packaging Specification

PK-180586-001-001

Product Specification

PS-180580-001-001

Sales Drawing

SD-180580-001

Test Summary

TS-180155-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
ECHA_01_2020 (16
January 2020

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

180580 Series

Use With

19.00mm by 16.00mm COB

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION