

CA Series

Illuminated Power Rocker Switches

Features/Benefits

- 15 AMPS @ 125 V AC
- Illuminated actuator
- Various actuator styles

Typical Applications

- Power outlet strips
- Appliances
- Handling and packaging machines
- RoHS compliant



Specifications

CONTACT RATING: 15 AMPS @ 125 V AC; 10 AMPS @ 250 V AC; 1/4 HP @ 125 V AC or 250 V AC.

ELECTRICAL LIFE: 10,000 make-and-break cycles at full load.

LAMP LIFE: 20,000 hours typ.

INSULATION RESISTANCE: $10^9 \Omega$ min.

DIELECTRIC STRENGTH: 1,000 Vrms min. @ sea level.

Materials

HOUSING: 6/6 nylon (UL 94V-2), black.

ACTUATOR: Polycarbonate (UL 94V-2), red.

CONTACTS: Coin silver, silver plated.

OPERATING TEMPERATURE: -30°C to +65°C

NOTE: Specifications and materials listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

Build-A-Switch

To order, simply select desired option from each category and place in the appropriate box. Available options are shown and described on pages G-103 through G-105. For additional options not shown in catalog, consult Customer Service Center.

Switch Function CA04 SPST, On-Off CA24 DPST, On-Off	Actuator J1 Rocker J7 Curved rocker	Actuator Color 3 Red translucent 5 Yellow translucent 6 Green translucent	Lamp Voltage 7 125 V neon 8 250 V neon	Housing Color 2 Black 1 White	Terminations 07 Quick connect	Actuator Markings NONE No markings D ON-OFF H 0 I P 0 -	Contact Material Q Silver
--	--	---	---	--	---	--	---

Rocker



G

C&K



Third Angle
Projection

Dimensions are shown: Inches (mm)

Specifications and dimensions subject to change

CA Series Illuminated Power Rocker Switches

 
SWITCH FUNCTION



NO. POLES	MODEL NO.	SWITCH FUNCTION		CONNECTED TERMINALS		SCHEMATIC
		POS. 1	POS. 2	POS. 1	POS. 2	
SP	CA04	ON	OFF	1-1A	OPEN	SPST
SPST ACTUATOR SHOWN IN POS. 1 - 'ON' POSITION Part number shown: CA04J137207Q TERMINAL NOS. MARKED ON HOUSING						
DP	CA24	ON	OFF	1-1A, 2-2A	OPEN	DPST
DPST ACTUATOR SHOWN IN POS. 1 - 'ON' POSITION Part number shown: CA24J137207Q TERMINAL NOS. MARKED ON HOUSING						

See CONTACT MATERIAL section, page G-105, for complete contact ratings and agency approvals.
Contacts make on side opposite actuator thrown.

All models with all options.



Third Angle
Projection

Dimensions are shown: Inches (mm)
Specifications and dimensions subject to change


www.ck-components.com




CA Series Illuminated Power Rocker Switches

ACTUATOR

J1 ROCKER

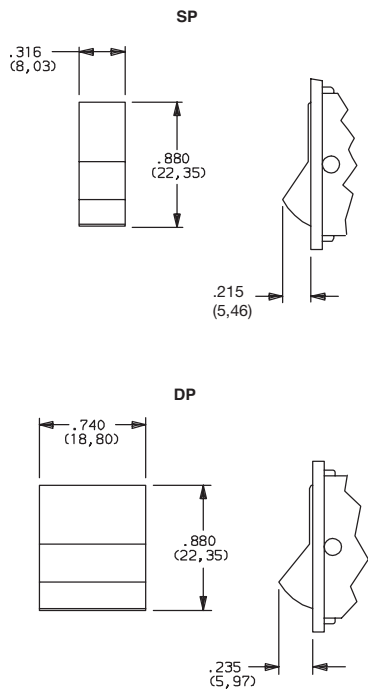

J7 CURVED ROCKER

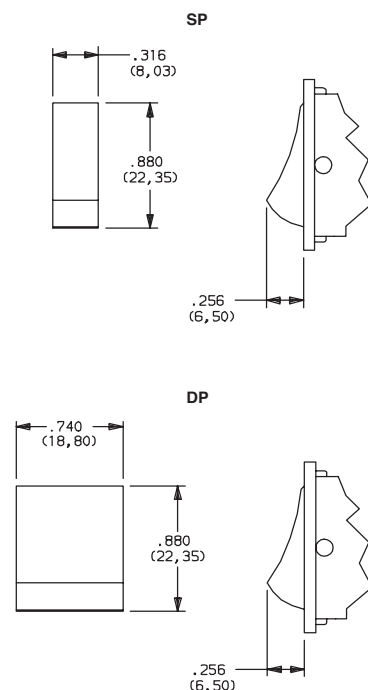

ACTUATOR COLOR

OPTION CODE	ACTUATOR COLOR
3	RED TRANSLUCENT
5	YELLOW
6	GREEN

NOTE: Special colors available, consult Customer Service Center.

NEON LAMP VOLTAGE

- 7 125 V NEON
- 8 250 V NEON

HOUSING COLOR

OPTION CODE	HOUSING COLOR
2	BLACK
1	WHITE

NOTE: Housing frame finish: matte. Special colors available, consult Customer Service Center.



Third Angle
Projection

Dimensions are shown: Inches (mm)


Specifications and dimensions subject to change

www.ck-components.com

CA Series Illuminated Power Rocker Switches

TERMINATIONS

07 QUICK CONNECT

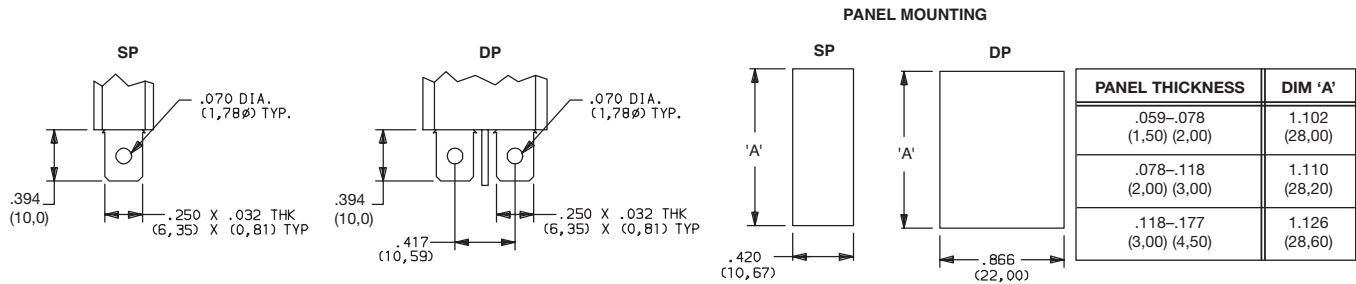


ACTUATOR MARKINGS

NONE NO MARKING



 
D ON-OFF



H O I



P O -

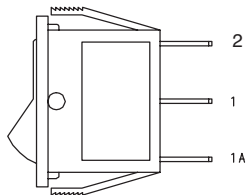

Marking color white, standard for all actuator colors except yellow. Marking color black, standard for yellow actuators. Consult Customer Service Center for other available markings and colors.

NOTE: Orientation of actuator markings and terminals

CONTACT MATERIAL

OPTION CODE	CONTACT AND TERMINAL MATERIAL	RATINGS	
Q	SILVER ¹	POWER	15 AMPS @ 125 V AC; 10 AMPS @ 250 V AC; 1/4 HP @ 125 V AC or 250 V AC (UL/CSA).

* Note: See Technical Data section of this catalog for RoHS compliant and compatible definitions and specifications.

¹ CONTACTS: Coin silver, silver plated.
TERMINALS: Copper, silver plated.

All models  with all options.