

# MHM501-00


In Production

Recommended

RoHS

REACH

## Appearance & Shape

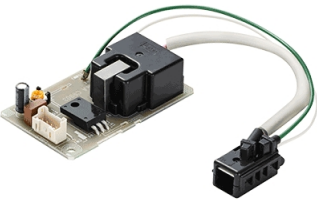

## Packaging Information

Packaging	Specifications	Standard Packing Quantity
-	Carton Box	200


## Features

Heater Built-in (High quality)

### Attention

- 1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.
- 2.This datasheet has only typical specifications because there is no space for detailed specifications. Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.

# MHM501-00



## Specifications

Input Voltage	12.0Vdc
Consumption Electricity	2.4W
Operating Temperature Range	-10°C to 50°C
Operating Humidity Range	20%RH to 80%RH
Max Operating Duty (%)	30(3S≥On time≥0.5S)
Lead Length	110mm

**Attention**  
1.This datasheet is downloaded from the website of Murata Manufacturing Co., Ltd. Therefore, it's specifications are subject to change or our products in it may be discontinued without advance notice. Please check with our sales representatives or product engineers before ordering.  
2.This datasheet has only typical specifications because there is no space for detailed specifications.  
Therefore, please review our product specifications or consult the approval sheet for product specifications before ordering.