

Horizontal Finger Cable Manager *RB-HFM Series*



Features:

- Metal components are constructed in 16-gauge steel.
- Fingers are constructed in black plastic.
- Snap-on, hinged door.
- Includes cutouts at the rear for cable pass-through.
- Fits standard EIA-compliant mounting rails.
- Metal components finished in textured RAL9005 black powder paint.
- Requires mounting hardware.
- Finished in textured RAL9005 black powder paint finish.
- TAA-compliant for GSA Schedule purchases.
- RoHS and REACH compliant.
- Manufactured in North America.

RACK BASICS®



For a double-sided manager, install two (2) managers mounted back-to-back. The rear opening provides a cable pass-thru.


Part of the Rack Basics® line of economy rack solutions.

Gallery



Accessories

- Mounting Hardware
- Hook and Loop Roll

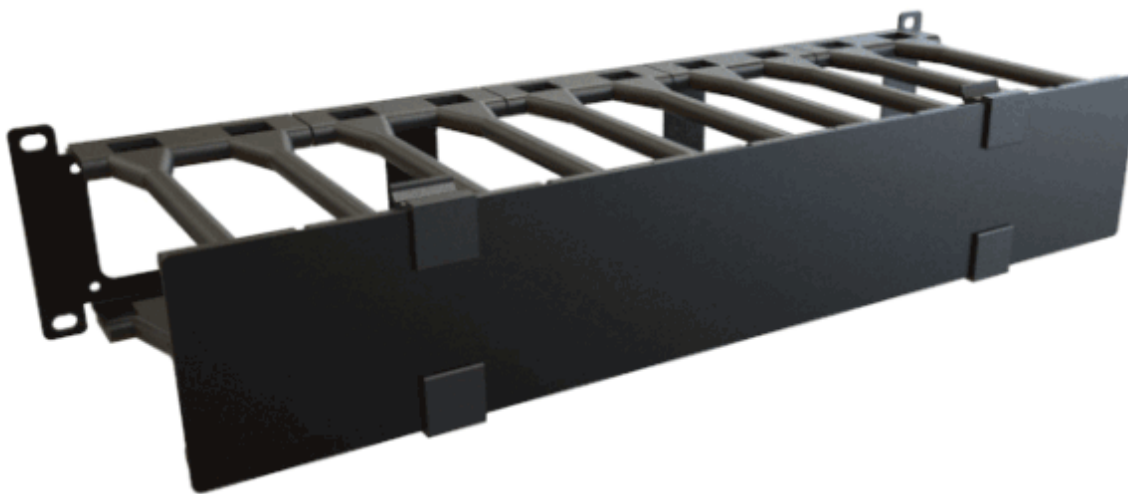

TAA-Compliant Cable Managers

Part No.	Overall Dinmensions			Usable Mounting Dimensions	
	Height	Width	Depth	Rack Units	Height
RB-HFMS1	1.47	19.00	4.37	1U	1.75
RB-HFMS2	3.22	19.00	4.37	2U	3.50
RB-HFMS3	5.22	19.00	4.37	3U	5.25
RB-HFMS4	6.97	19.00	4.37	4U	7.00
RB-HFMD1	1.47	19.00	6.50	1U	1.75
RB-HFMD2	3.22	19.00	6.50	2U	3.50
RB-HFMD3	5.22	19.00	6.50	3U	5.25
RB-HFMD4	6.97	19.00	6.50	4U	7.00

Non-TAA Compliant Managers are available while supplies last.

Part No.	Overall Dinmensions			Usable Mounting Dimensions	
	Height	Width	Depth	Rack Units	Height
RB-HFM1	1.72	19.00	4.37	1U	1.75
RB-HFM2	3.22	19.00	4.37	2U	3.50

COO: China

Data subject to change without notice

© 2023. Hammond Manufacturing Ltd. All rights reserved.