


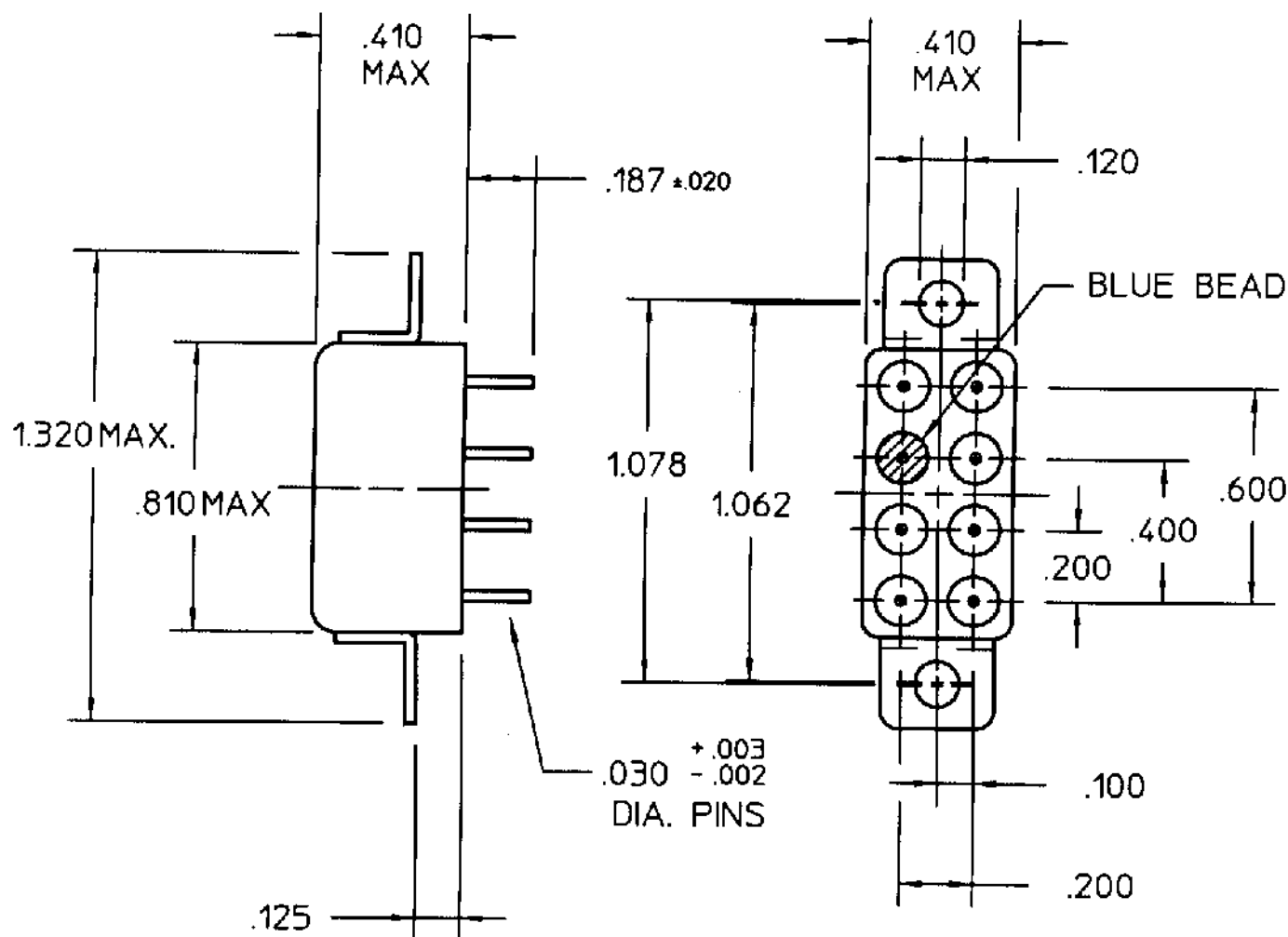

REV. 0


DCO 15864

COIL: @ 25°C
 RESISTANCE 1250 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.0 VDC
 MUST RELEASE 15 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE & RELEASE 4 MS MAX.
 CONTACT BOUNCE 2.0 MS MAX.

CUSTOMER DATA SHEET

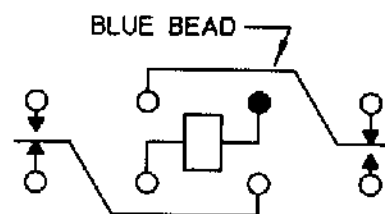

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 2A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 10/14/99 CK 10/14/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C.I.I.
 CUST. NO. STANDARD REV.

"HFW" RELAY

HFW1230D00