


# Angular Feed-Through Spring Clamp

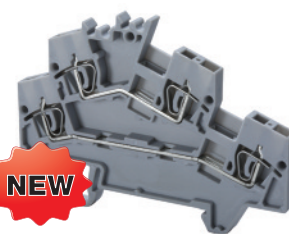

|                     |                           |              |           |                                               |              |          |                                               |                |           |
|---------------------|---------------------------|--------------|-----------|-----------------------------------------------|--------------|----------|-----------------------------------------------|----------------|-----------|
| Terminal Width      | 6 mm                      |              |           | 8 mm                                          |              |          | 5 mm                                          |                |           |
| Height x Length     | 42 x 61.5 mm              |              |           | 42 x 74 mm                                    |              |          | 50 x 79.5 mm                                  |                |           |
| Stripping Length    | 15 mm                     |              |           | 15 mm                                         |              |          | 14 mm                                         |                |           |
| Insulation Material | Polyamide 6.6             |              |           | Polyamide 6.6                                 |              |          | Polyamide 6.6                                 |                |           |
| Type of Connection  | 4 spring clamp connection |              |           | 3 spring clamps & 2 slots for interconnection |              |          | 4 spring clamps & 4 slots for interconnection |                |           |
| Approvals           |                           |              |           |                                               |              |          |                                               |                |           |
| Wire Range          | 22-10 AWG                 | 0.2-4 sq.mm. | 22-10 AWG | 22-8 AWG                                      | 0.2-6 sq.mm. | 22-8 AWG | 22-12 AWG                                     | 0.34-2.5 sq.mm | 22-12 AWG |
| Voltage Rating      | 600 V                     | 800 V        | 600 V     | 600 V                                         | 800 V        | 600 V    | 300 V                                         | 800 V          | 300 V     |
| Current Rating      | 35 A                      | 32 A         | 35 A      | 50 A                                          | 41 A         | 50 A     | 25 A                                          | 24 A           | 25 A      |
| Other Approvals     |                           |              |           |                                               |              |          |                                               |                |           |

|                       | Cat. No.     | Std. Pk. | Cat. No.     | Std. Pk. | Cat. No.      | Std. Pk. |
|-----------------------|--------------|----------|--------------|----------|---------------|----------|
| <b>Terminal Block</b> | <b>AS4/4</b> | 100      | <b>AS6/3</b> | 50       | <b>ADL2.5</b> | 50       |
| <b>End Plate</b>      | EPAS4        | 50       | EPAS6        | 50       | EPADL2.5      | 50       |

|                                                                     |                         |     |           |     |           |     |
|---------------------------------------------------------------------|-------------------------|-----|-----------|-----|-----------|-----|
| <b>DIN Rail</b><br>for ordering information<br>refer to pages 90-91 |                         |     |           |     |           |     |
| <b>End Stop</b><br>for ordering information<br>refer to page 92     | CA103                   | 50  | CA103     | 50  | CA103     | 50  |
|                                                                     | CA702                   | 50  | CA702     | 50  | CA702     | 50  |
|                                                                     | CA802                   | 50  | CA802     | 50  | CA802     | 50  |
| <b>Jumpers Adjacent</b>                                             | DOES NOT ACCEPT JUMPERS |     | CA801/3   | 100 | CA801/1   | 100 |
| <b>Jumpers Alternate</b>                                            |                         |     | CA801/3-3 | 100 | CA801/1-3 | 100 |
| <b>Push in type wire jumper</b>                                     |                         |     | CA901/3   | 100 | CA901/1   | 100 |
| <b>Step Down Jumper</b> see page 98                                 |                         |     | CA901/4   | 100 |           |     |
|                                                                     |                         |     | CA901/6   | 100 |           |     |
| <b>Marking Tags</b>                                                 | MT6                     | 100 | MT8       | 100 | MT5       | 100 |