

## RJ45 RJ45 coupler PCB 1x RJ45+solder

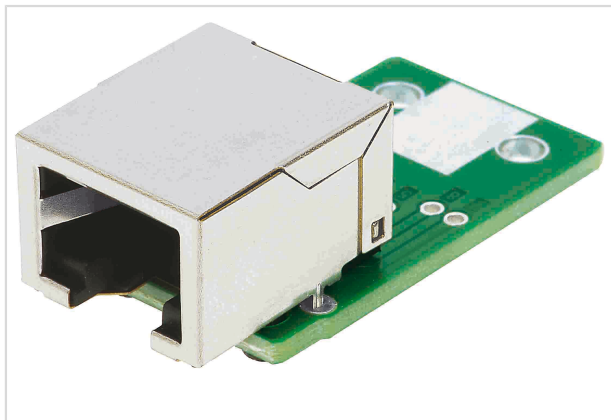


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 545 1134
Specification	RJ45 RJ45 coupler PCB 1x RJ45+solder
HARTING eCatalogue	<a href="https://b2b.harting.com/09455451134">https://b2b.harting.com/09455451134</a>

### Identification

Category	Connectors
Series	HARTING RJ Industrial®
Element	Adapter
Specification	RJ45

### Version

Termination method	Solder termination
Shielding	Fully shielded, 360° shielding contact
Number of contacts	8

### Technical characteristics

Rated current	1.5 A
Rated voltage	125 V
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20

### Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained



**Pushing Performance**  
Since 1945

## Material properties

California Proposition 65 substances	Yes
California Proposition 65 substances	Antimony trioxide
California Proposition 65 substances	Lead
California Proposition 65 substances	Nickel

## Specifications and approvals

Approvals	DNV GL
-----------	--------

## Commercial data

Packaging size	100
Net weight	6.34 g
Country of origin	Germany
European customs tariff number	85366990
eCl@ss	27440205 Contact insert for industrial connectors