



DIMENSIONS mm (inches)

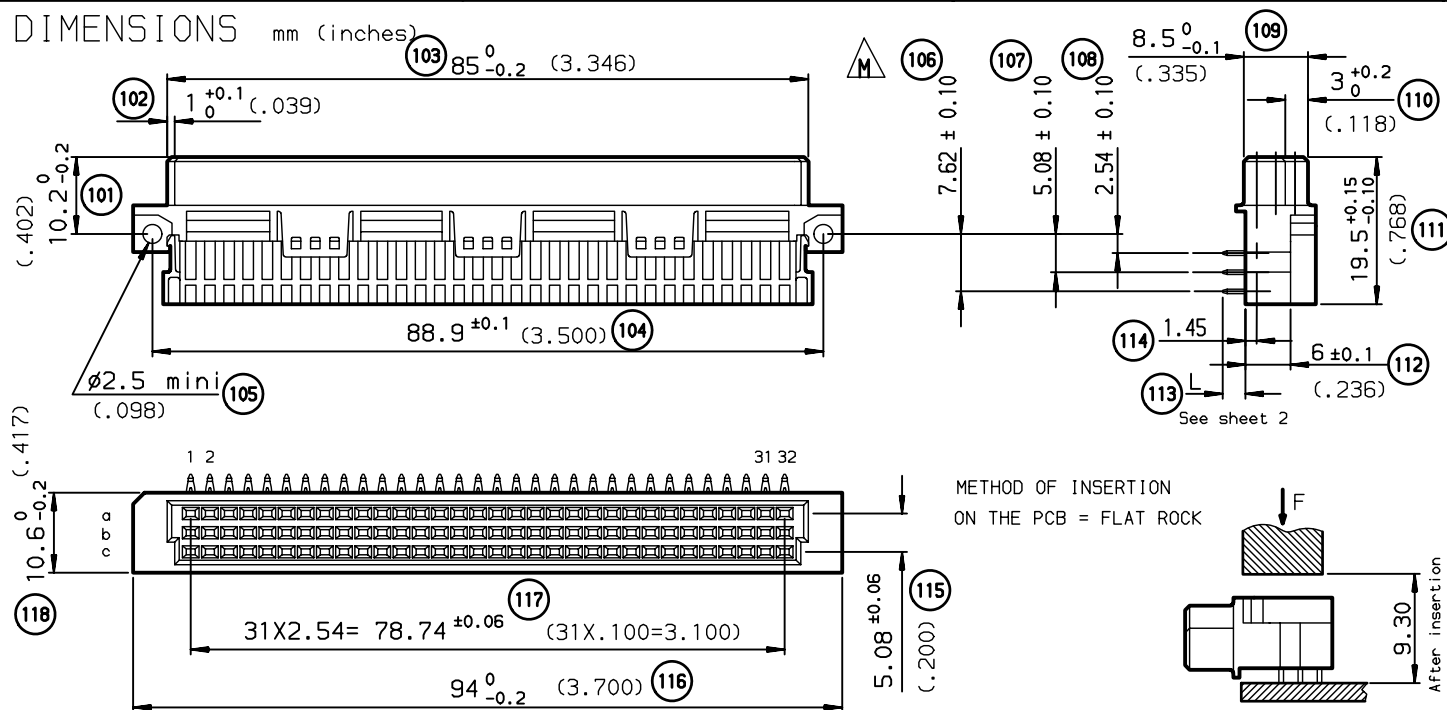

Recommended accessory :

Loaded connectors with less than 64 cts
require fixings with self-winding screws
part number : 4514327

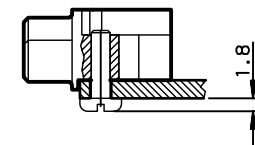

TIN LEAD	LEAD FREE	
8609 396 88 94 755 000 E3	8609 396 88 94 755 E3 LF	Style R receptacle, 96 Position, press fit, class 2
8609 396 88 94 765 000 E3	8609 396 88 94 765 E3 LF	Style R receptacle, 96 Position, press fit, class 1
8609 464 88 94 755 000 E3	8609 464 88 94 755 E3 LF	Style R receptacle, 64 Position, press fit, class 2
8609 464 88 94 765 000 E3	8609 464 88 94 765 E3 LF	Style R receptacle, 64 Position, press fit, class 1

Application specific part-numbers: See sheet 2

GENERAL CHARACTERISTICS AND ROHS INFORMATIONS:


SEE DRAWING C-8609-0000C

rev	ecn no	dr	date
J	-	ROU	2002/08/30
K	LS05-004	JTA	2005/02/25
L	LS06-0097	LGO	2006/07/25
M	LS07-0297	HLE	2007/11/19
-	-	-	-
-	-	-	-
-	-	-	-

www.fciconnect.com			surface ISO 1302		tolerance std ISO 406 ISO 1101		projection 		mm 	
			TOLERANCES UNLESS OTHERWISE SPECIFIED							
Dr	ROUILLARD	1993/05/01	ANGULAR	LINEAR	0.X	±0.1	size A3	Scale 1.5		
Eng	TARON	1993/05/01			0.XX	±0.1				
Chr	LEGARE	1993/05/01			0.XX ±2°	0.XXX		±0.1	ECN LS07-0297	
Appr	LEGARE	1993/05/01	Product family			DIN 8609		Spec ref -		
			title RIGHT ANGLE RECEPTACLE - STYLE R PRESS FIT				dwg no C-8609-0369		Rev.	
									M	
			catalog no		SEE TABLE		CUSTOMER		sheet 1 of 2	

REV F - 2006-04-17

 PCB LAYOUT



SEE DRAWING C-8609-0000C

European Views

Downloaded from Arrow.com.