


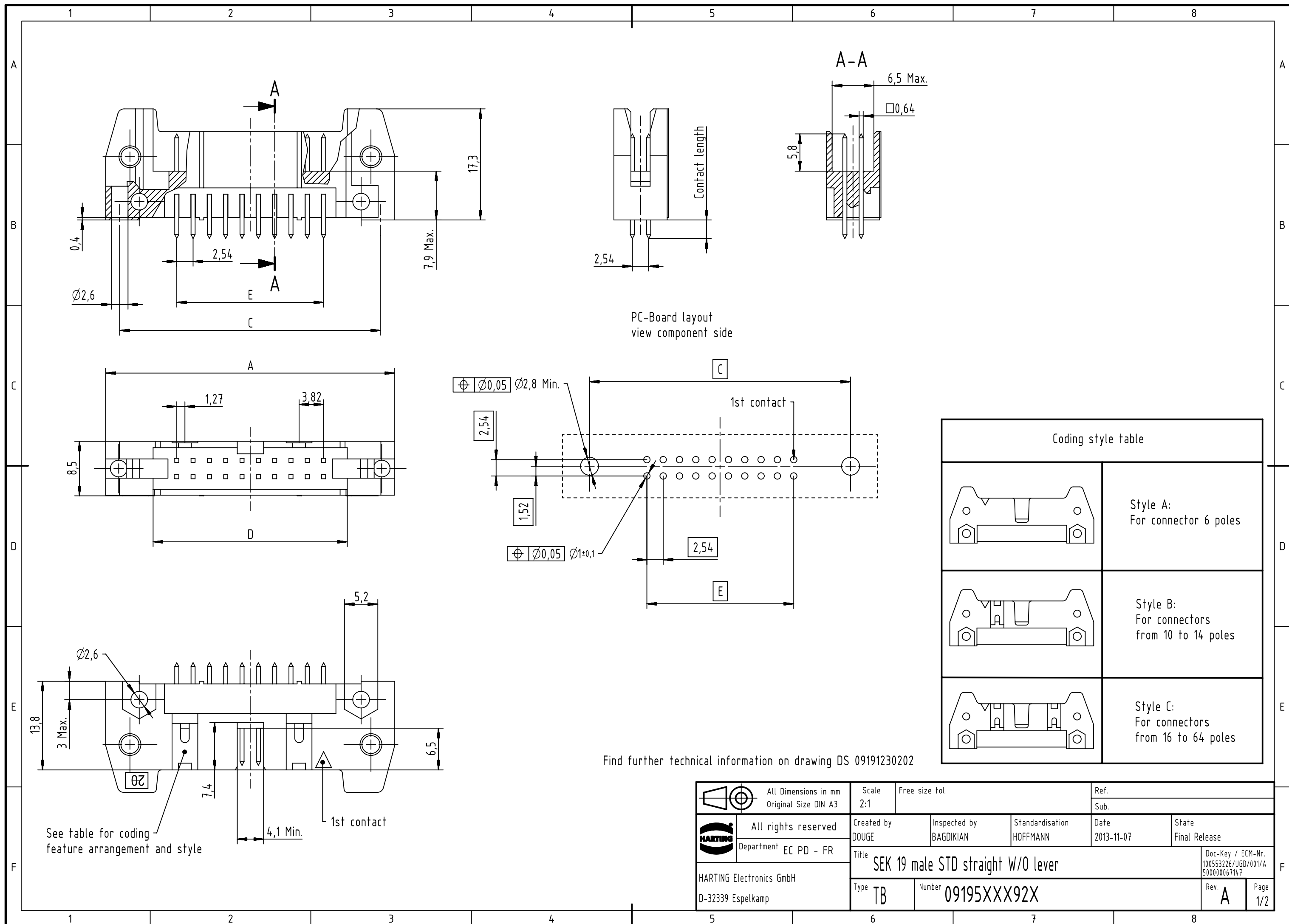

1		2		3		4		5		6		7		8	
A															A
	Performance Level					Dimensions (mm)									
	PL3 : 50 mating Cycles No Gas Test	PL2 : 250 mating Cycles 4 day Gas Test	S4 : 0,76µm Au or equivalent PdNi												
B	Nb of Contacts	Part Number	Part Number	Part Number	Insulator Color	Contact Length ±0,3(mm)	A Max	C	D	E					B
	06	0919 506 7924	0919 506 6924	0919 506 5924	Beige	2,9	27,2	22,86	12,45	2,54 x 2 = 5,08					
	10	0919 510 7924	0919 510 6924	0919 510 5924			32,3	27,94	17,53	2,54 x 4 = 10,16					
	14	0919 514 7924	0919 514 6924	0919 514 5924			37,4	33,02	22,61	2,54 x 6 = 15,24					
	16	0919 516 7924	0919 516 6924	0919 516 5924			39,9	35,56	25,15	2,54 x 7 = 17,78					
	20	0919 520 7924	0919 520 6924	0919 520 5924			45,0	40,64	30,23	2,54 x 9 = 22,86					
	24	0919 524 7924	0919 524 6924	0919 524 5924			50,1	45,72	35,91	2,54 x 11 = 27,94					
	26	0919 526 7924	0919 526 6924	0919 526 5924			52,6	48,26	37,85	2,54 x 12 = 30,48					
	30	0919 530 7924	0919 530 6924	0919 530 5924			58,0	53,34	43,83	2,54 x 14 = 35,56					
	34	0919 534 7924	0919 534 6924	0919 534 5924			62,8	58,42	48,01	2,54 x 16 = 40,64					
	40	0919 540 7924	0919 540 6924	0919 540 5924			70,4	66,04	55,63	2,54 x 19 = 48,26					
	50	0919 550 7924	0919 550 6924	0919 550 5924			83,1	78,74	68,33	2,54 x 24 = 60,96					
	60	0919 560 7924	0919 560 6924	0919 560 5924			95,8	91,44	81,03	2,54 x 29 = 73,66					
	64	0919 564 7924	0919 564 6924	0919 564 5924			100,9	96,52	86,11	2,54 x 31 = 78,74					
C	06	0919 506 7924 001	0919 506 6924 001	0919 506 5924 001			Black	2,9	27,2	22,86	12,45	2,54 x 2 = 5,08			
	10	0919 510 7924 001	0919 510 6924 001	0919 510 5924 001	32,3	27,94			17,53	2,54 x 4 = 10,16					
	14	0919 514 7924 001	0919 514 6924 001	0919 514 5924 001	37,4	33,02			22,61	2,54 x 6 = 15,24					
	16	0919 516 7924 001	0919 516 6924 001	0919 516 5924 001	39,9	35,56			25,15	2,54 x 7 = 17,78					
	20	0919 520 7924 001	0919 520 6924 001	0919 520 5924 001	45,0	40,64			30,23	2,54 x 9 = 22,86					
	24	0919 524 7924 001	0919 524 6924 001	0919 524 5924 001	50,1	45,72			35,91	2,54 x 11 = 27,94					
	26	0919 526 7924 001	0919 526 6924 001	0919 526 5924 001	52,6	48,26			37,85	2,54 x 12 = 30,48					
	30	0919 530 7924 001	0919 530 6924 001	0919 530 5924 001	58,0	53,34			43,83	2,54 x 14 = 35,56					
	34	0919 534 7924 001	0919 534 6924 001	0919 534 5924 001	62,8	58,42			48,01	2,54 x 16 = 40,64					
	40	0919 540 7924 001	0919 540 6924 001	0919 540 5924 001	70,4	66,04			55,63	2,54 x 19 = 48,26					
	50	0919 550 7924 001	0919 550 6924 001	0919 550 5924 001	83,1	78,74			68,33	2,54 x 24 = 60,96					
	60	0919 560 7924 001	0919 560 6924 001	0919 560 5924 001	95,8	91,44			81,03	2,54 x 29 = 73,66					
	64	0919 564 7924 001	0919 564 6924 001	0919 564 5924 001	100,9	96,52			86,11	2,54 x 31 = 78,74					
	D	06	0919 506 7922	0919 506 6922	0919 506 5922	Beige			4,5	27,2	22,86	12,45	2,54 x 2 = 5,08		
10		0919 510 7922	0919 510 6922	0919 510 5922	32,3		27,94	17,53		2,54 x 4 = 10,16					
14		0919 514 7922	0919 514 6922	0919 514 5922	37,4		33,02	22,61		2,54 x 6 = 15,24					
16		0919 516 7922	0919 516 6922	0919 516 5922	39,9		35,56	25,15		2,54 x 7 = 17,78					
20		0919 520 7922	0919 520 6922	0919 520 5922	45,0		40,64	30,23		2,54 x 9 = 22,86					
24		0919 524 7922	0919 524 6922	0919 524 5922	50,1		45,72	35,91		2,54 x 11 = 27,94					
26		0919 526 7922	0919 526 6922	0919 526 5922	52,6		48,26	37,85		2,54 x 12 = 30,48					
30		0919 530 7922	0919 530 6922	0919 530 5922	58,0		53,34	43,83		2,54 x 14 = 35,56					
34		0919 534 7922	0919 534 6922	0919 534 5922	62,8		58,42	48,01		2,54 x 16 = 40,64					
40		0919 540 7922	0919 540 6922	0919 540 5922	70,4		66,04	55,63		2,54 x 19 = 48,26					
50		0919 550 7922	0919 550 6922	0919 550 5922	83,1		78,74	68,33		2,54 x 24 = 60,96					
60		0919 560 7922	0919 560 6922	0919 560 5922	95,8		91,44	81,03		2,54 x 29 = 73,66					
64		0919 564 7922	0919 564 6922	0919 564 5922	100,9		96,52	86,11		2,54 x 31 = 78,74					
E		06	0919 506 7922 001	0919 506 6922 001	0919 506 5922 001		Black	4,5		27,2	22,86	12,45	2,54 x 2 = 5,08		
	10	0919 510 7922 001	0919 510 6922 001	0919 510 5922 001	32,3	27,94			17,53	2,54 x 4 = 10,16					
	14	0919 514 7922 001	0919 514 6922 001	0919 514 5922 001	37,4	33,02			22,61	2,54 x 6 = 15,24					
	16	0919 516 7922 001	0919 516 6922 001	0919 516 5922 001	39,9	35,56			25,15	2,54 x 7 = 17,78					
	20	0919 520 7922 001	0919 520 6922 001	0919 520 5922 001	45,0	40,64			30,23	2,54 x 9 = 22,86					
	24	0919 524 7922 001	0919 524 6922 001	0919 524 5922 001	50,1	45,72			35,91	2,54 x 11 = 27,94					
	26	0919 526 7922 001	0919 526 6922 001	0919 526 5922 001	52,6	48,26			37,85	2,54 x 12 = 30,48					
	30	0919 530 7922 001	0919 530 6922 001	0919 530 5922 001	58,0	53,34			43,83	2,54 x 14 = 35,56					
	34	0919 534 7922 001	0919 534 6922 001	0919 534 5922 001	62,8	58,42			48,01	2,54 x 16 = 40,64					
	40	0919 540 7922 001	0919 540 6922 001	0919 540 5922 001	70,4	66,04			55,63	2,54 x 19 = 48,26					
	50	0919 550 7922 001	0919 550 6922 001	0919 550 5922 001	83,1	78,74			68,33	2,54 x 24 = 60,96					
	60	0919 560 7922 001	0919 560 6922 001	0919 560 5922 001	95,8	91,44			81,03	2,54 x 29 = 73,66					
	64	0919 564 7922 001	0919 564 6922 001	0919 564 5922 001	100,9	96,52			86,11	2,54 x 31 = 78,74					
	F														