
 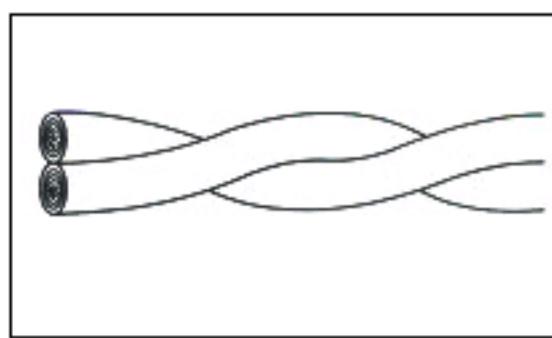




55A0122-22-6/9CS2275 Product Details

[Share](#) | [Print](#) | [Email](#)

55A0122-22-6/9CS2275

TE Internal Number: 403895-000



Spec 44, Spec 55 and Spec RCW Wire and Cable

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Cable Type = Spec 55
- Wire Source = United States
- Cable Style = Primary
- Wire Size (AWG/CM) = 22 AWG
- Voltage Rating = 600 VAC

[View all Features](#)

Quick Links

- Pricing & Availability
- Search for Tooling
- Product Feature Selector
- Contact Us About This Product


[Add to My Part List](#)

[Request Sample](#)

[Find Similar Products](#)

[Buy Product](#)

Documentation & Additional Information

Product Drawings:

- [TWO CONDUCTOR CABLE, UNSHIELDED, UNJACKETED, GENERAL...](#) (PDF, English)

Catalog Pages/Data Sheets:

- None Available

Product Specifications:

- None Available

Application Specifications:

- None Available

Instruction Sheets:

- None Available

CAD Files:

- None Available

Related Products:

- [Tooling](#)

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- Cable Type = Spec 55
- Cable Style = Primary

Electrical Characteristics:

- Voltage Rating (VAC) = 600

Dimensions:

- Conductor Outer Diameter (mm [in]) = 0.79 [0.031]

Body Features:

- Wire Size (AWG/CM) = 22 AWG
- Conductor Type = Silver-Plated Copper
- Wire Color = Blue, White
- Nominal Outside Diameter (mm [in]) = 2.18 [0.086]
- Wire Diameter (mm [in]) = 1.09 [0.043]

Configuration Features:

- Number of Conductors = Twisted Pair

Industry Standards:

- Government/Industry Qualification = Yes
- Government/Industry Part Number = M27500A22SR2U00
- RoHS/ELV Compliance = RoHS compliant, ELV compliant
- Lead Free Solder Processes = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS compliant

Conditions for Usage:

- Temperature Range (°C) = -65 – +200
- Wire Size - Details = 22 AWG 0.38 mm², 0.00059 in², 19 x 34 AWG

Operation/Application:

- Application = General Purpose - Lightweight

Packaging Features:

- Wire Source = United States

Other:

- Brand = Raychem

Corporate Information

[About TE](#)
[Investors](#)
[News Room](#)
[Supplier Portal](#)
[Careers](#)
[Terms & Conditions](#)
[Privacy Policy](#)

Quick Links

[Distributor Inventory](#)
[Product Cross Reference](#)
[Documents & Drawings](#)
[Product Compliance Support Center](#)
[Site Map](#)

Customer Support

[Email or Chat With Us](#)
[Find a Phone Number](#)
[Knowledge Base](#)
[Manage Your Account](#)

Keep Me Informed

