


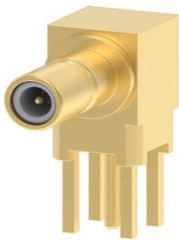

Part Number : [733280030](#)
Product Description : SSMB Jack, Right-Angle, PCB
Receptacle, Through Hole, Brass Body, Gold (Au)
Plated, 3.44mm Leg Length, 50 Ohms
Series Number : 73328
Status : Active
Product Category : RF / Coaxial Connectors



Documents & Resources

Drawings
[733280030 sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Contains Lead per D(2023)3788-DC (14 Jun 2023)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

[EU RoHS Certificate of Compliance](#)

[Additional Product Compliance Information](#)

Part Details

General

Status	Active
Category	RF / Coaxial Connectors
Series	73328
Description	SSMB Jack, Right-Angle, PCB Receptacle, Through Hole, Brass Body, Gold (Au) Plated, 3.44mm Leg Length, 50 Ohms
Application	RF
Product Name	SSMB
Style	PCB
Type	Subminiature
UPC	822348632329

Electrical

Frequency	12 GHz
Impedance	50Ω
Power / Voltage	VOLTAGE: 250 Vrms@Sea Level

Physical

Cable Attachment	N/A
Gender	Jack
Keying to Mating Part	N/A
Net Weight	0.800/g
Orientation	Right Angle
Packaging Type	Bag
Panel Mount	No
Panel Mount Method	N/A
PCB Mounting	Through Hole
PCB Thickness - Recommended	3.31mm

Reverse Polar	No
Wire/Cable Type	N/A

This document was generated on Sep 18, 2025