


C4AC02UXXX

(M12 Cordset, 4 Position, 18 AWG, Male Straight to Female Straight)

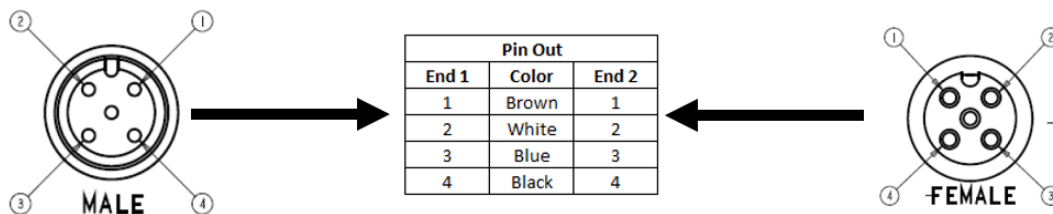

- Mueller's C4AC02UXXX is an M12 4-pin double ended instrumentation cable with a straight male connector on one end and a straight female connector on the other.
- Keyway – A Coding
- Utilizes our 4-conductor 18 AWG TPE-insulated cable.
- Ratings:
 - Current: 4 A
 - Voltage: 250 V AC/DC
 - Temperature Range: -40° C to 105° C
- Material:
 - Coupling Nuts – Aluminum
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant

Mueller Electric Company
2850 Gilchrist Rd. Bld 5A
Akron, OH 44305

www.muellerelectric.com

Toll Free: 800.955.2629
Phone: 330.780.2525
Fax: 330.780.2524