

Part Number : [190670098](#)


Product Description : NylaKrimp Funnel Entry Ring
Tongue Terminal for 2 AWG Wire, Stud Size 5/16" (M8),
Carton

Series Number : 19067

Status : Active

Product Category : Ring and Spade Terminals

Engineering Part Number : G-975-56

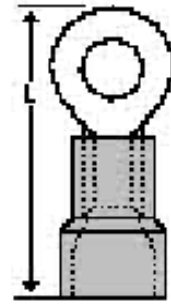

Documents and Resources

Drawings

[190670098_sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-19902-013-001.pdf](#)

[PS-19902-016-001.pdf](#)

Product Environment Compliance

Compliance

| | |
|--------------------|--|
| GADSL/IMDS | Not Relevant |
| China RoHS | Not Relevant |
| EU ELV | Not Relevant |
| Low-Halogen Status | Low-Halogen per IEC 61249-2-21 |
| REACH SVHC | Not Contained per D(2025)7771-DC (04 Feb 2026) |
| EU RoHS | Compliant per EU 2015/863 |

Compliance Statements

- EU RoHS
- REACH SVHC

- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

| | |
|--------------|--|
| Status | Active |
| Category | Ring and Spade Terminals |
| Series | 19067 |
| Description | NylaKrimp Funnel Entry Ring Tongue Terminal for 2 AWG Wire, Stud Size 5/16" (M8), Carton |
| Keyword | Ring Terminal, Ring Terminals |
| Product Name | NylaKrimp |
| Style | Ring |
| Type | Ring Terminal |
| UPC | 800753066793 |

Agency

| | |
|-----|---------|
| CSA | LR18689 |
| UL | E32244 |

Physical

| | |
|---------------------------|-----------------|
| Barrel Type | Closed - Brazed |
| Flammability | 94V-2 |
| Insulation | Nylon (PA) |
| Material - Plating Mating | Tin |
| Net Weight | 15.424/g |

| | |
|-----------------------------|----------------------|
| Packaging Type | Carton |
| Plating min - Mating | 2.540µm |
| Plating min - Termination | 2.540µm |
| Stud Size | 5/16" (M8) |
| Termination Interface Style | Crimp or Compression |
| Wire Insulation Diameter | 15.24mm max. |
| Wire Size (AWG) | 2 |

Application Tooling

Global

| Description | Part Number |
|---|------------------|
| Putt Pump Hydraulic Head Crimper, Die Set Required, For Insulated and Non-Insulated Terminals and Splices | <u>192860117</u> |
| Die Set (Large) for the HHLS Hydraulic Crimper | <u>192890010</u> |
| PremiumGrade Hand Crimp Tool for 8-2 AWG Terminals | <u>640013900</u> |
| Hand Crimp Tool for 2 AWG Insulated Ring Terminals | <u>640017970</u> |
| Putt Pump Dieless Head Crimper, For Insulated and Non-Insulated Terminals and Splices | <u>638162000</u> |

This document was generated on May 20, 2026