


CONFIGURATION	PART NUMBER	LENGTH
MINI, 5 PIN, 16AWG MALE RECEPTACLE	MN51PW02Mxxx	AS REQUESTED

DIMENSIONS

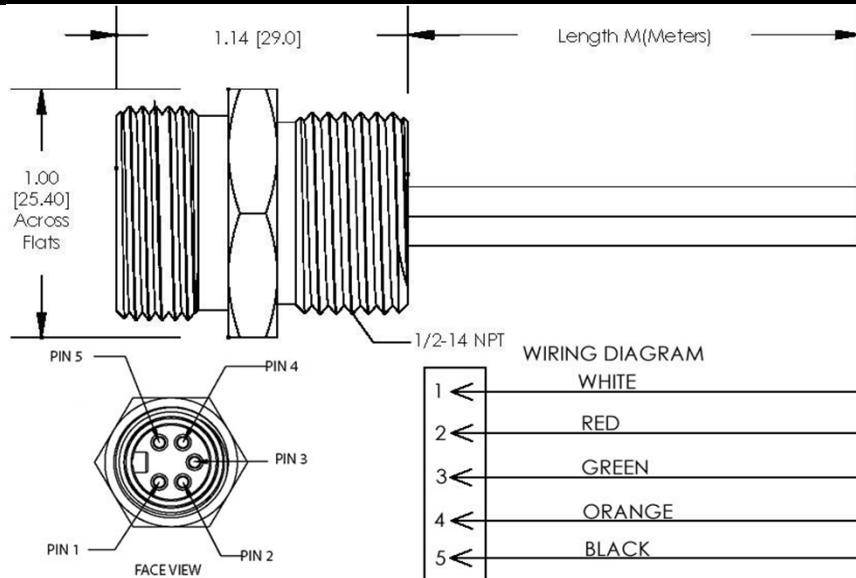

TECHNICAL DATA

APPROVALS:	UL, c(UL)
TEMPERATURE RANGE:	-20C to +105C
PROTECTION:	IP 67, NEMA 6P
VOLTAGE RATING:	600VAC
AMPERAGE:	8A
HOUSING:	MACHINED ALUMINUM, ANODIZED
CONTACTS:	COPPER ALLOY
CONTACT PLATING:	GOLD OVER NICKEL PLATING
CONNECTOR FACE:	PVC
CHARACTERISTICS:	16 AWG, 600 V, MTW OR UL 1015
NOTES:	<p>Custom Options: Additional wire styles, colors and sizes are available. Contact your Sales Representative.</p> <p>Housing Options: Stainless Steel.</p>