


| | |
|---|----------------------------|
| Mallory Mallory Sonalert Products, Inc. | Part #: JT028-RG-CS |
| Sales Outline Drawing | Revision: D |

Specifications:

| | | | | | |
|------------------------|-------------------------|-----------------|--|--|--|
| Stack Number: | 1 | 2 | | | |
| LED Color: | RED | GREEN | | | |
| Connection Wires: | Red and Brown | Green and Brown | | | |
| LED Current Draw: | <50 mA | <40 mA | | | |
| Rated Voltage: | 24 VAC/DC | | | | |
| Operating Voltage: | 20-28 VAC/DC | | | | |
| Total Max Current: | <90mA | | | | |
| Operating Temperature: | -25° ~ +60°C | | | | |
| Lens Color: | Opaque White | | | | |
| Material: | ABS FR15U | | | | |
| Mounting Method: | Stainless Steel Pole | | | | |
| Weight Typical (g): | 580 | | | | |
| NEMA 12: | Approved | | | | |
| Options: | Please contact factory. | | | | |

Dimensions: Inches (mm) **cUL Recognized** **ROHS Compliant**

PATENT NUMBER(S) D898600 10309594

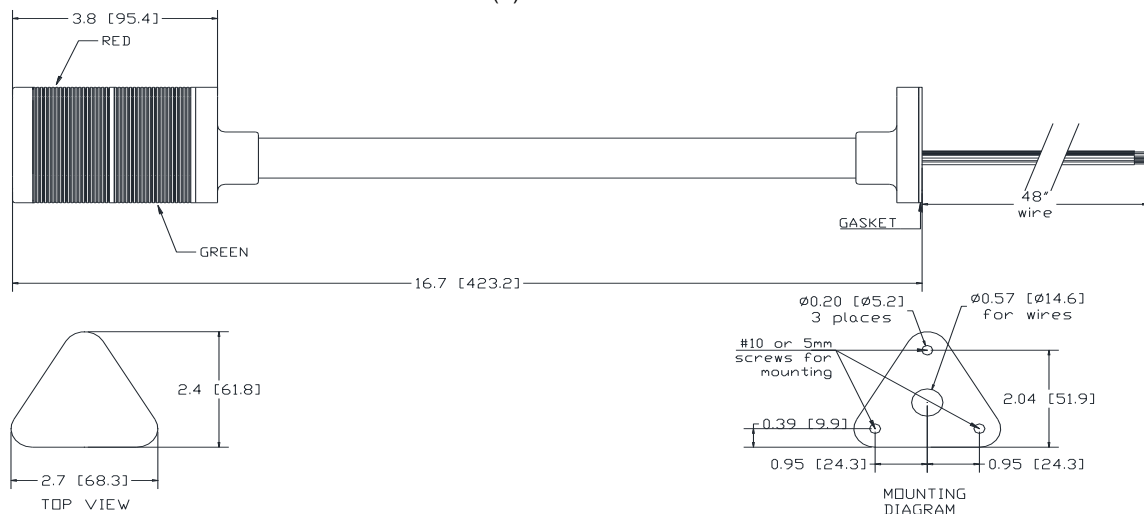

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.