


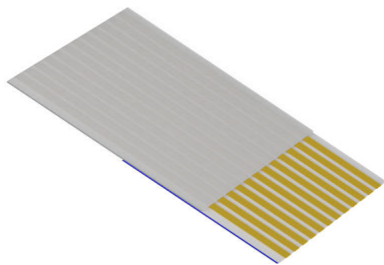

**Part Number :** [150200138](#)  
**Product Description :** 0.50mm Pitch Premo-Flex FFC  
Jumper, Opposite Side Contacts (Type D), 305.00mm  
Cable Length, Gold (Au) Plating, 12 Circuits  
**Series Number :** 15020  
**Status :** Active  
**Product Category :** Flat-Flexible Cable (FFC)



## Documents & Resources

### Drawings

- [150200138 sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

### Specifications

- [PS-15020-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Reviewed per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2025)4165-DC (25 June 2025)
EU RoHS	Not Reviewed per EU 2015/863

### Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

### Industry Documents

- IPC 1752A Class C

- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

---

**Part Details**

**General**

Status	Active
Category	Flat-Flexible Cable (FFC)
Series	15020
Description	0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 305.00mm Cable Length, Gold (Au) Plating, 12 Circuits
Comments	Contacts on opposite sides, Type D
Product Name	Premo-Flex FFC Jumper
UPC	884982176003

**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

**Physical**

Cable Length	305.00mm
Circuits (Loaded)	12
Contact Layout Type	D (opposite side)
Design Feature	Flexible
Material - Plating Mating	Gold
Net Weight	1.550/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C

Termination Style	FFC Connector
Wire/Cable Type	Flat Flex Cable
Wire Size (AWG)	N/A

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 12 Circuits, Phosphor Bronze, Gold Plating	<a href="#"><u>5019511230</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, V-Flip Series, Vertical, 4.05mm Height, 12 Circuits, Copper Alloy, 125°C Operating Temperature, Gold Plating	<a href="#"><u>5019511250</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FBH1 Series, Right-Angle, Dual Contact, 1.00mm Height, 12 Circuits, Gold over Nickel Plating	<a href="#"><u>5034801200</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, FD19 Series, Right-Angle, Bottom Contact, 1.90mm Height, 12 Circuits, Gold over Nickel Plating	<a href="#"><u>5051101292</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Vertical, 3.90mm Height, 12 Circuits, Gold Plating	<a href="#"><u>525591252</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 12 Circuits, Gold Plating	<a href="#"><u>527451297</u></a>
Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Bottom Contact, 2.00mm Height, 12 Circuits, Gold Plating	<a href="#"><u>527461271</u></a>

0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Right-Angle, Non-ZIF, Dual Contact Style, 1.20mm Mated Height, 12 Circuits, Gold (Au) Plating	<u>512811298</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, Gold (Au) Plating	<u>545481272</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.20mm Height, Right-Angle, Surface Mount, ZIF, Top Contact Style, 12 Circuits, Gold (Au) Plating	<u>545501272</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Standard Footprint, Gold Plating, Black, 12 Circuits	<u>781191220</u>
0.50mm Pitch Easy-On FFC/FPC Connector, Surface Mount, Vertical, Non-ZIF, Reverse Footprint, Gold Plating, Black, 12 Circuits	<u>781271220</u>
0.50mm Pitch Easy-On FFC/FPC Connector, 1.30mm Height, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, 12 Circuits, Gold (Au) Contact Plating	<u>512961294</u>

---

This document was generated on Sep 22, 2025