

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:


68506-0414

Status:

Active

Description:

6.35mm Tab Micro Relay Socket, Female, 4 Circuits

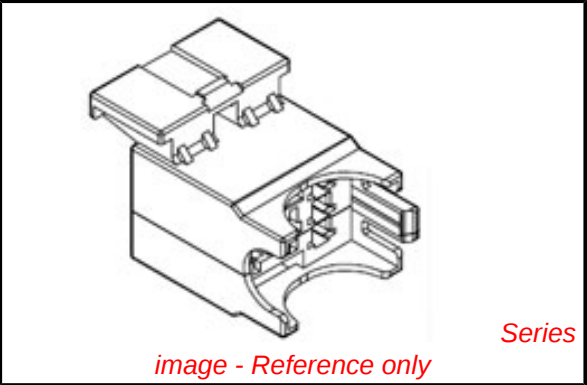

Documents:

3D Model

Drawing (PDF)

Product Specification PS-68506-001 (PDF)

Packaging Specification PK-68506-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Other Sockets
Series	68506
Component Type	Socket
Product Name	N/A
Physical	
Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black, Blue
Durability (mating cycles max)	Contact Molex
Entry Angle	Vertical
Keying to Mating Part	N/A
Material - Resin	Polyester
PCB Locator	No
PCB Retention	N/A
Packaging Type	Bag
Pitch - Mating Interface	6.00mm, 8.00mm
Pitch - Termination Interface	6.00mm, 8.00mm
Temperature Range - Operating	-40°C to +120°C
Electrical	
Current - Maximum per Contact	3A
Voltage - Maximum	N/A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-68506-001
Product Specification	PS-68506-001
Sales Drawing	SD-68506-002

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

68506Series

Use With

35427 6.00mm

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION