


19" Front Panel, 1 U, 3 mm, Al, Anodized, Untreated Edges

CATALOG NUMBER

30219-098

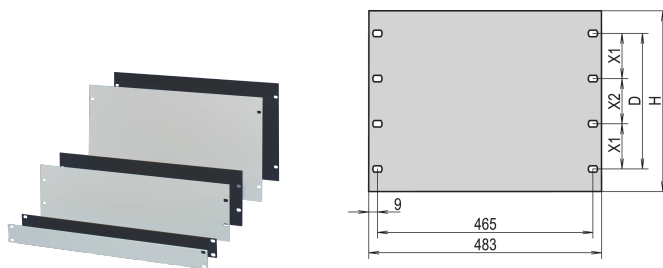

Front panels made of Aluminum.

CERTIFICATIONS



FEATURES

Aluminum, 4 or 3 mm thick, with Anodized or Painted finish

PRODUCT ATTRIBUTES

Rack Height: 1U

Accessory Type: Front panel

Mounting: Screw-on Front

Finish: Anodized

Front Finish: Anodized

Package Quantity: 1

Rear Finish: Anodized

Treated Edges: No

EMC Shielding: No

Material: Aluminum

Product Type: Front Panel


Rack Width: 95HP

Type: 19" Front Panel

ADDITIONAL PRODUCT DETAILS

Please order 19" assembly kit separately.

DIAGRAMS

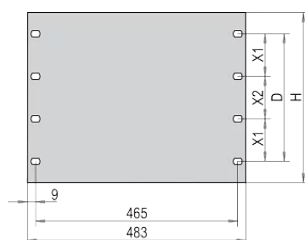

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE