



(/)



RF CONNECTORS, CABLES, AND COMPONENTS (/RF)

ALL RF COMPONENTS, 50 OHM, 75 OHM, ORIGINAL SOLUTIONS (/RF/COMPONENTS) 75 OHM (/RF/COMPONENTS/75-OHM)

HDBNC™ (/RF/COMPONENTS/75-OHM/HDBNC) HDBNC-TH (/PRODUCTS/HDBNC-TH) **HDBNC-NUT-001-N**

HDBNC-NUT-001-N

Back To Top ↑

HDBNC-NUT-001-N

75 Ohm High-Density BNC Jack, Through-hole

Product Specs

Product Specs

Features

- Optimized for 12G-SDI Broadcast Video solutions
- 4X the panel density of traditional BNCs
- Bayonet latch
- 20% reduction in weight of traditional BNCs
- Dual sourced by Amphenol®

3D Models

Looking for a 3D model? Select your format and download your model.
This site uses cookies and other website monitoring technologies to assist with website functions and with our promotional and marketing efforts. By clicking "Accept", you consent to the terms in our recently updated Privacy Notice (http://suddendocs.samtec.com/articles/privacy-notice.pdf) and Policy Manual (http://suddendocs.samtec.com/articles/samtec-policy-manual.pdf#page=4).

Accept

Accept

Decline

Decline

Free Samples



Downloads

Contact



Live Chat

We are sorry for the inconvenience, but we do not recognize the part number you specified as an available Standard Part. Please try again or contact e3dmodels@samtec.com



(2)

(<tel:+18007268329>) (<mailto:eCustomerService@samtec.com>)

Specs Kit

Get All This Information By Email

Submit

Secured form. No spam.

✓ **Ships Immediately: 750 pieces** | Large Volume Lead Time: 2 weeks

Buckets

Price

❗ Please **Login** (</login?returnUrl=https%3A%2F%2Fwww.samtec.com%2Fproducts%2Fhdbnc-nut-001-n>) to see customer specific pricing. Or you may directly **contact support**. (</support>)

You don't have an account? **Create one** (<https://www.samtec.com//account/login/createaccount.aspx>)



Add to Cart (<https://www.samtec.com//my-samtec/order.aspx?partnumbersource=kinetic.techspecs.partconfigurator&partnumber=hdbnc-nut-001-n>)

Get a Free Sample

This site uses cookies and other website monitoring technologies to assist with website functions and with our promotional and marketing efforts. By clicking Accept, you consent to the terms in our recently updated [Privacy Notice](http://www.samtec.com/articles/privacy-notice.pdf) (<http://www.samtec.com/articles/privacy-notice.pdf>) and [Policy Manual](http://www.samtec.com/articles/samtec-policy-manual.pdf) (<http://www.samtec.com/articles/samtec-policy-manual.pdf>).
(<http://www.samtec.com/articles/privacy-notice.pdf>) and (<http://www.samtec.com/articles/samtec-policy-manual.pdf>)

Accept

Accept

Decline

Decline

[Free Samples](#)




[Downloads](#)

[Contact](#)



[Live Chat](#)

(tel:+18007268329) (mailto:eCustomerService@samtec.com)

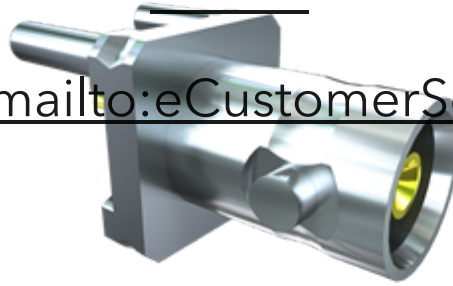

DISCLAIMER: Product images may not represent actual part.

Catalog Pages

Language

English

Download

PDF Catalog Page
(http://suddendocs.samtec.com/catalog_english/hdbnc.pdf)

Prints

Prints

Footprints

This site uses cookies and other website monitoring technologies to assist with website functions and with our promotional and marketing efforts. By clicking Accept, you consent to the use of these technologies. For more information, please see our [Privacy Policy](http://suddendocs.samtec.com/articles/privacy-policy.pdf) and [Privacy Notice](http://suddendocs.samtec.com/articles/privacy-policy.pdf) (<http://suddendocs.samtec.com/articles/privacy-policy.pdf>) and [Policy Manual](http://suddendocs.samtec.com/articles/samtec-policy-manual.pdf#page=4) (<http://suddendocs.samtec.com/articles/samtec-policy-manual.pdf#page=4>).

Related Series and Mates

Free Samples

Accept

Accept

Decline

Decline



Downloads

Contact




Live Chat

HDBNC-BH

(L)

75 Ohm High-Density BNC Bulkhead Jack, Through-hole

(tel:+18007268329) (mailto:eCustomerService@samtec.com)

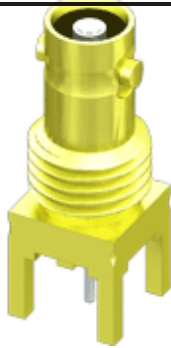

(/products/hdbnc-bh)

This site uses cookies and other website monitoring technologies to assist with website functions and with our promotional and marketing efforts. By clicking Accept, you consent to the use of these technologies. For more information, please see our [Privacy Notice](#) (<http://suddendocs.samtec.com/articles/privacy-notice.pdf>) and [Policy Manual](#) (<http://suddendocs.samtec.com/articles/samtec-policy-manual.pdf#page=4>).


Accept

Accept

Decline

Decline

Free Samples**Downloads****Contact****Live Chat**

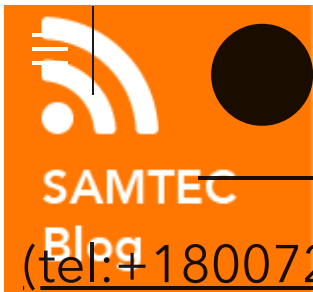

(tel: +18007268329) (mailto:eCustomerService@samtec.com)
(http://blog.samtec.com/)

A DEEP DIVE INTO SEVERE ENVIRONMENT TESTING (PART II)

(HTTPS://BLOG.SAMTEC.COM/POST/A-DEEP-DIVE-INTO-SEVERE-ENVIRONMENT-TESTING-PART-II/)

In the first part of this series on Severe Environment Testing (SET) we covered Electrostatic Discharge (ESD) and Dielectric Withstanding Voltage (DWV) at an altitude of 70,000 ft. Continuing on the path of "how" we tested, we will be looking at the other tests that were introduc...

[Read More (https://blog.samtec.com/post/a-deep-dive-into-severe-environment-testing-part-ii/)]

YOUR LOCAL FSE LOCATION: (CHANGE)



© 2019 Samtec. All rights reserved.

[View Full Site](#)

SPEAK WITH A REPRESENTATIVE

1-800-726-8329

1-800-SAMTEC-9

1-812-944-6733

WEBSITE OR PRODUCT SUPPORT

eCustomerService@samtec.com (mailto:eCustomerService@samtec.com)

[Live Chat](#)

This site uses cookies and other website monitoring technologies to assist with website functions and with our

[Privacy Policy](#) (https://www.samtec.com/privacy-policy) and [Terms of Use](#) (https://www.samtec.com/terms-of-use).

[Notice of Privacy Practices](#) (https://www.samtec.com/articles/privacy-notice.pdf) and [Policy Manual](#) (https://www.samtec.com/articles/policy-manual.pdf).

[Free Sample Program](#) (https://www.samtec.com/offerings/samples.aspx#page=4).

[Risk Mitigation](#) (/about/legal#risk)

[Locations](#) (/about/global)

Accept

Accept

Decline

Decline



[Downloads](#)

[Contact](#)



[Live Chat](#)

[Careers \(/about#careers\)](#)
[Quality \(/support/compliance\)](#)
[Sitemap \(/support/sitemap\)](#)
[Legal/Compliance/Privacy \(/about/legal\)](#)



CONTACT US (/about#contactus)
(tel: +18007268329) (mailto: ECustomerService@samtec.com)

[Application Engineering \(/about#contactus\)](#)
[Customer Support \(/about#contactus\)](#)
[Live Chat](#)

LANGUAGES

[English \(/www.samtec.com/\)](#)
[简体中文 \(/www.samtec.com/zh/\)](#)
[日本語 \(/www.samtec.com/jp/\)](#)



© 2019 Samtec. All rights reserved.

[Terms \(/about/legal#samtecterms\)](#) [Privacy \(/about/legal#policies\)](#) [Technical Support / Support \(/support\)](#)

[View Mobile Site](#)

This site uses cookies and other website monitoring technologies to assist with website functions and with our promotional and marketing efforts. By clicking Accept, you consent to the use of these technologies in accordance with our [Privacy Notice](#) (<http://suddendocs.samtec.com/articles/privacy-notice.pdf>) and [Policy Manual](#) (<http://suddendocs.samtec.com/articles/samtec-policy-manual.pdf#page=4>).

[Free Samples](#)

Accept



[Downloads](#)

Decline

[Contact](#)



Live Chat