


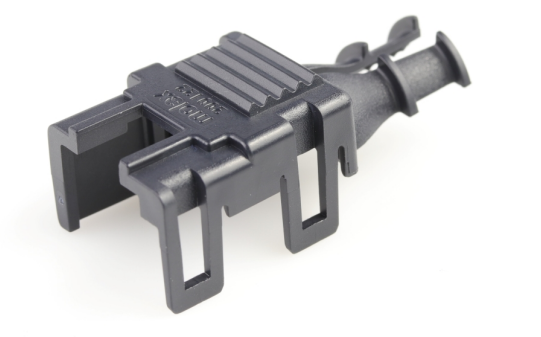

Part Number : [2001220004](#)
Product Description : Mega-Fit Receptacle Backshell, Dual Row, Low-Halogen, 4 Circuits
Series Number : 200122
Status : Active
Product Category : Connector Accessories
Engineering Number : F4068.02-P27



Documents & Resources

Drawings
[2001220004_sd.pdf](#)

3D Models and Design Files
[2001220004_stp.zip](#)

Specifications
[AS-76823-100-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements
- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Connector Accessories
Series	200122
Description	Mega-Fit Receptacle Backshell, Dual Row, Low-Halogen, 4 Circuits
Component Type	Backshell
Product Name	Mega-Fit
UPC	889056290951

Physical

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Black
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	2.030/g
Number of Rows	2
Packaging Type	Bag
Temperature Range - Operating	-40° to +105°C

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Use with Part(s)

Description	Part Number
-------------	-------------

Mega-Fit Dual Row Receptacle Housings	<u>171692</u>
--	---------------

This document was generated on Mar 14, 2025