



 Keyword, Part Number or Cross-Ref

 [Bill of Materials](#)

- / Copper Systems
- / Patch Cords & Accessories
- / Patch Cords
- / [STP28X4.5MBU](#)

STP28X4.5MBU Share

Copper Patch Cord

Category 6A Performance, 28AWG, F/UTP Patch Cord, CM/LSZH, Blue, 4.5m.

 Find A Distributor

Qty

Add to Bom

[Specifications](#) [Packaging Detail](#) [Resources](#)

[Related Products](#)

Top of Page 

Specifications





Conductor Gauge (AWG)

28

Conductor Gauge (kcmil)	NA
Performance Level	Category 6A
Connector 2 Type	RJ45 8(8)
Connector 1 Type	RJ45 8(8)
Overall Length (In.)	NA
Overall Length (ft.)	14.76
Overall Length (m)	4.5
Overall Length (mm)	NA
Nominal Diameter (mm)	NA
Wiring Scheme	T568B
Maximum Operating Temperature (°C)	75
Maximum Operating Temperature (°F)	167
Minimum Operating Temperature (°C)	-10
Minimum Operating Temperature (°F)	14
Maximum Storage Temperature (°C)	70
Maximum Storage Temperature (°F)	158
Minimum Storage Temperature (°C)	-40
Minimum Storage Temperature (°F)	-40
Color	Blue
Sub Brand	PanNet
Flammability Rating	CM, LSZH-1 (60332-1)
Standards Met	IEEE 802.3af, 802.3at, 802.3bt type 3 and type 4, UL 1863.
Product Type	Copper Patch Cord
Cable Color	Blue
Length (ft.)	14.76
Termination End 1	Modular Plug
Termination End 2	Modular Plug
CE Compliant	Yes
Nominal Cable Outside Diameter (In.)	0.19
Nominal Cable Outside Diameter (mm)	4.7
UL5A Listed	No
Application	Shielded
Cable Length (ft.)	14.76
Cable Length (m)	4.5
Cable Type	F/UTP
Conductor Material	Copper

Maximum Installation Temperature (°C)	70
Maximum Installation Temperature (°F)	158
Minimum Installation Temperature (°C)	70
Minimum Installation Temperature (°F)	-40
RoHS Compliancy Status	Compliant
Min. Order Qty.	1
Measurement System	Meters (Rest of World)

Packaging Detail


UPC	07498300270
Std. Pkg. Qty.	1
Std. Pkg. Volume (cf)	0.0269
Std. Ctn. Qty.	10
Std. Ctn. Volume (cf)	0.2694

Resources

Part Drawings	Category 6A Shielded 28AWG Copper Patch Cords	US English	 View PDF (264.49KB)	 Download PDF	 Share PDF
Technical References	Patch Cord Wiring Guide: TR103	US English	 View PDF (262.81KB)	 Download PDF	 Share PDF
Installation Documents	Panduit 28 AWG Patch Cords Installation Guideline	US English	 View PDF (198.34KB)	 Download PDF	 Share PDF
Selection Guides	28 AWG Selection Guide - Category 6A, 6, & 5e (NA, LA): COSG10--WW-ENG	US English	 View PDF (631.55KB)	 Download PDF	 Share PDF
Selection Guides	Patch Cord Selection Guide (All Regions): COSG11--WW-ENG	US English	 View PDF (292.58KB)	 Download PDF	 Share PDF
Specification Sheets	TX6A-28 Category 6A Performance 28 AWG Shielded Patch Cords	US English	 View PDF (147.97KB)	 Download PDF	 Share PDF




Related Products

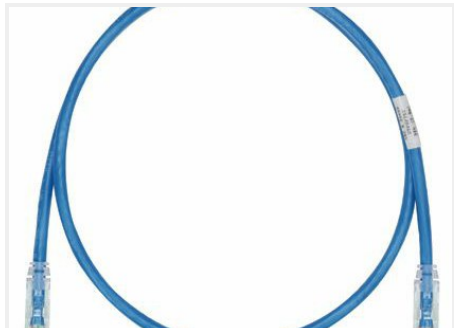


UTPSP7BUY

Category 6, UTP patch cord with TX6™ PLUS Modular Plugs on each end. Blue, 7 ft.

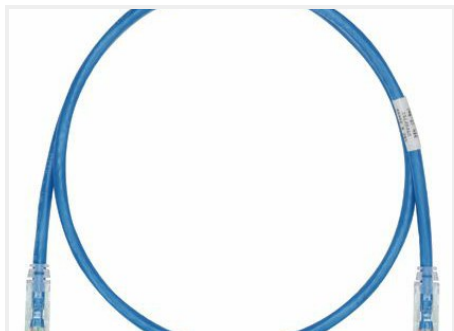

UTPSP2MBUY

 Category 6, UTP patch cord with TX6™ PLUS Modular Plugs on each end. Blue, 2 meters.



UTPSP5BUY

Category 6, UTP patch cord with TX6™ PLUS Modular Plugs on each end. Blue, 5 ft.



Email Support

Email support available 24/7



800-777-3300

Monday through Thursday 7:00 am-6:30 pm CST
Friday 7:00 am-6:00 pm CST



Where to Buy

Find a Panduit Distributor or Partner

[About Us](#)

[Research and Development](#)

[Awards](#)

[Partner Ecosystem](#)

[World Headquarters](#)

[Company Profile](#)

[Media Resources](#)

[Case Studies](#)

[Panduit Code of Conduct](#)

[Careers at Panduit](#)

[The Hub – Partner Portal](#)

[Product Registration](#)

[Panduit Connections Blog](#)



Get Our Catalog



Download the PDF or request a copy be mailed to you.

Which catalog would you like

Download

