


CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



Please be informed that the data shown in this PDF document is generated from our Online Catalog. Please find the complete data in the user documentation. Our General Terms of Use for Downloads are valid.

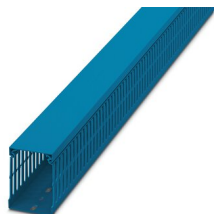

Cable duct for installation and mounting in control cabinets, blue, halogen-free, comprising upper part and mounting base, width: 60 mm, height: 80 mm, length: 2000 mm

Commercial Data

Item number	3240596
Packing unit	1 pc
Minimum order quantity	10 pc
Sales Key	BE74
Product Key	BE7442
Catalog Page	Page 579 (C-3-2019)
GTIN	4046356630146
Weight per Piece (including packing)	986 g
Weight per Piece (excluding packing)	986 g
Customs tariff number	39259020
Country of origin	DE

CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



Technical Data

Product properties

Product type	Wiring duct
--------------	-------------

Connection data

Nominal cross section	3243 mm ²
-----------------------	----------------------

Dimensions

Dimensional drawing	
Width	60 mm
Height	80 mm
Length	2000 mm

Material specifications

Color	blue
Material	PC/ABS
Flammability rating according to UL 94	V0
Components	halogen-free

Cable/line

Halogen-free	yes
Halogen-free	yes

Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-40 °C ... 90 °C

CD-HF 60X80 BU - Cable duct


3240596

<https://www.phoenixcontact.com/us/products/3240596>



Drawings

Dimensional drawing

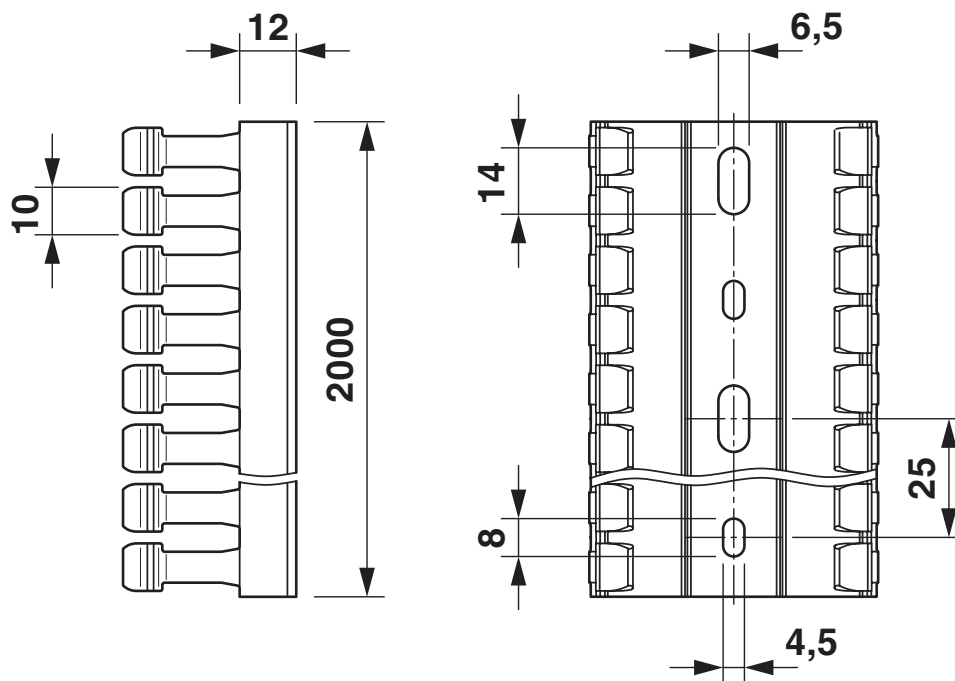

Base perforation according to DIN EN 50085

CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



Approvals



CSA

Approval ID: 248269



VDE Zeichengenehmigung

Approval ID: 40028972



EAC

Approval ID: RU C-DE.PB68.W.00513



UL Recognized

Approval ID: FILE E 328576

CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



Classifications

ECLASS

ECLASS-9.0	27400703
ECLASS-10.0.1	27400703
ECLASS-11.0	27400703

ETIM

ETIM 8.0	EC000012
----------	----------

UNSPSC

UNSPSC 21.0	39131700
-------------	----------

CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



Environmental Product Compliance

China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



Accessories

RVT-PA 4 - Fastening clip

3240498

<https://www.phoenixcontact.com/us/products/3240498>



Plastic body-bound rivet, for hole diameter of 4 mm and a material thickness of 1.5 ... 6 mm

RVT-PA 6 - Fastening clip

3240499

<https://www.phoenixcontact.com/us/products/3240499>



Plastic body-bound rivet, for hole diameter of 6 mm and a material thickness of 1.5 ... 6 mm

CD-HF 60X80 BU - Cable duct

3240596

<https://www.phoenixcontact.com/us/products/3240596>



UNIFOX-RVT P 4 - Tool

1212478

<https://www.phoenixcontact.com/us/products/1212478>

Rivet setting tool, for use with RVT-PA 4 plastic body-bound rivets



UNIFOX-RVT P 6 - Tool

1212509

<https://www.phoenixcontact.com/us/products/1212509>

Rivet setting tool, for use with RVT-PA 6 plastic body-bound rivets



Phoenix Contact 2023 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com