


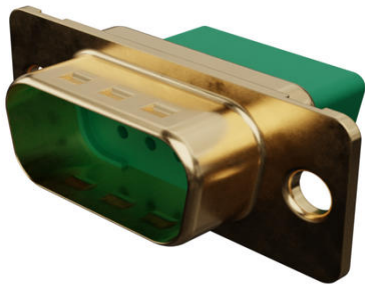

Part Number : [1731091980](#)
Product Description : FCT Standard-Density D-Sub Crimp Housing, Male, Gold Plated Shell without Dimples, 9 Circuits, Green Front and Rear Insulator, Crimp Contacts Included
Series Number : 173109
Status : Active
Product Category : D-Sub Connectors
Engineering Number : FU09P7-1437



Documents & Resources

Drawings

- [1731091980_sd.pdf](#)
- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	D-Sub Connectors
Series	173109
Description	FCT Standard-Density D-Sub Crimp Housing, Male, Gold Plated Shell without Dimples, 9 Circuits, Green Front and Rear Insulator, Crimp Contacts Included
IP Rating	IP20
Magnetic	Yes
Product Name	FCT Products
Type	Standard Density
UPC	191130544455

Electrical

Current - Maximum per Contact	5.0A
Shielded	Yes

Physical

Circuits (Loaded)	0
Circuits (maximum)	9
Color - Resin	Green
Durability (mating cycles min)	500
Gender	Male
Material - Contact	Copper Alloy

Material - Resin	PBT
Material - Shell	Brass
Net Weight	8.000/g
Number of Rows	2
Orientation	Straight
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
PCB Locator	No
PCB Retention	None
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Contact	Gold over Nickel
Plating - Shell	Gold
Polarized to Mating Part	Yes
Polarized to PCB	No
Ports	1
Temperature Range - Operating	-55° to +125°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size (AWG)	18, 20, 22, 24, 26, 28

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mates With	FCT Standard-Density D-Sub, Size 1, 9 Position, Socket

This document was generated on Sep 10, 2025