




PRESENTATION

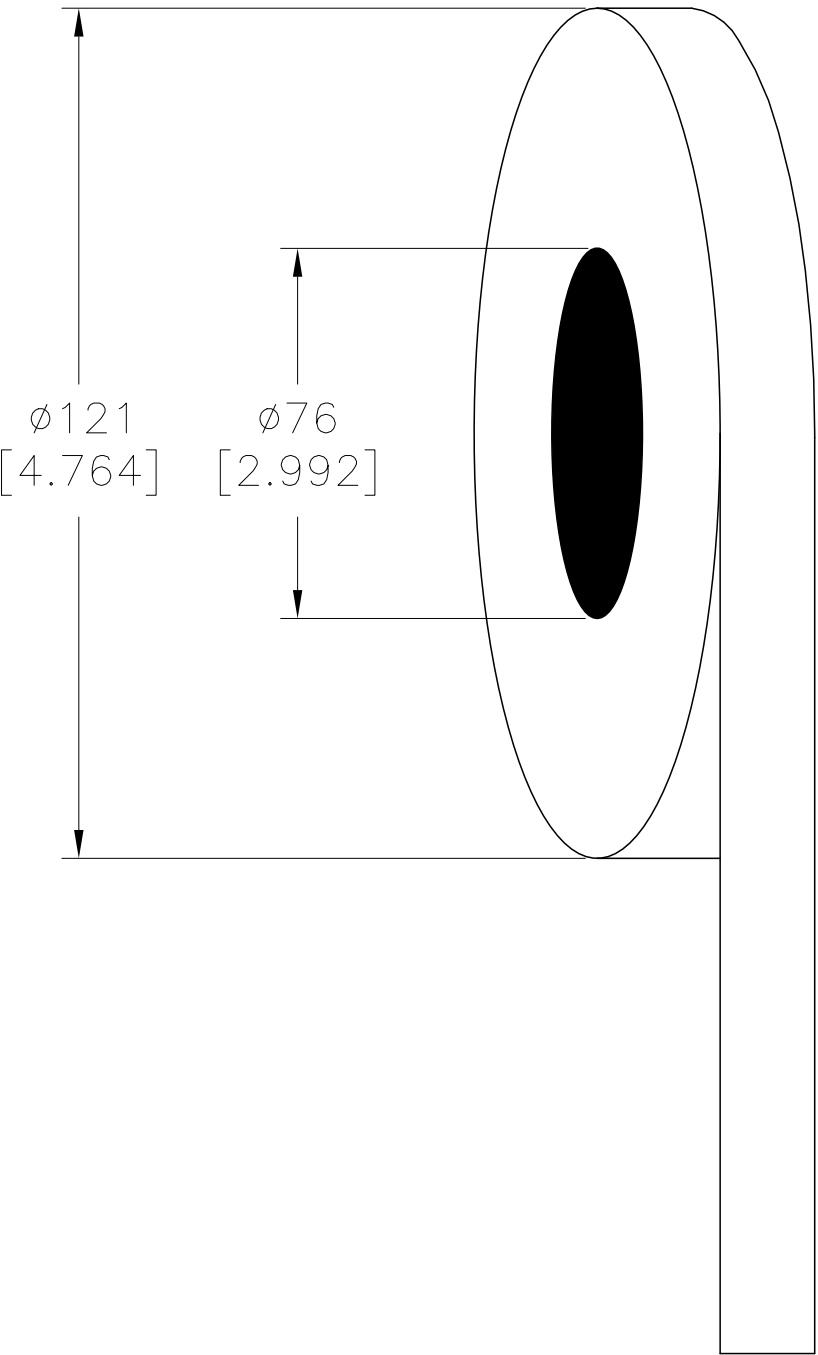

OUTSIDE WOUND
LABEL ACROSS: 1
PER ROLL QTY: 30.48m / 100 feet

MATERIAL	POLYVINYL FLUORIDE (TEDLAR®)
ADHESIVE TYPE	PERMANENT ACRYLIC
LINEAR	BROWN KRAFT

TOLERANCES mm [INCH]		THIS DRAWING IS A CONTROLLED DOCUMENT.		DWN GOPALAKRISHNA HV 31SEP2020		 TE Connectivity	
LABEL HEIGHT: ±0.3 [0.12]		D.BURGAT 31SEP2020		CHK			
LABEL WIDTH: ±0.3 [0.12]		APVD D.BURGAT 31SEP2020		NAME		TEDLAR® LABEL – YELLOW – CONTINUOUS	
WEB WIDTH: ±0.8 [0.31]		PRODUCT SPEC		TTDS-004		12.7mm x 30.4m (0.5inch x 100ft)	
VERTICAL REPEAT: ±0.8 [0.31]*		TOLERANCES UNLESS OTHERWISE SPECIFIED:		APPLICATION SPEC		-	
HORIZONTAL REPEAT: ±0.8 [0.31]*				-		SIZE	
PRINT POSITIONING: ±0.8 [0.31]*		0 PLC ± - 1 PLC ± - 2 PLC ± - 3 PLC ± - 4 PLC ± - ANGLES ± -		-		CAGE CODE	
LEFT MARGIN: ±0.4 [0.16]		MATERIAL		WEIGHT		DRAWING NO	
QUANTITY: -0 % +2 %		FINISH		53 g		FB1U7	
*NON ACCUMULATING		SEE TABLE		GLOSS		C-NPVF050YW-100	
				CUSTOMER DRAWING		RESTRICTED TO	
						SCALE	
						NTS	
						SHEET	
						1 of 1	
						REV	
						A1	