

[Labels](#) / [Labels by Industrial Printer](#) / [i7100 Labels](#) /

3" Core Series UltraTemp 1-Mil Matte Polyimide Labels

3" Core Series UltraTemp 1-Mil Matte Polyimide Labels



Product Highlights:

Label/Tape Size:

0.25 in H x 0.75 in W

Material:

Polyimide

For Use with Printer:

BBP®81 Label Printer, BRADY IP® Series Label Printer, BradyPrinter i5100, BradyPrinter i7100, BRADYPRINTER PR Plus Series Label Printer, THT 3" Core Printer

Material Number:

B-719

Part Number:

THT-1-719-10

ADD TO CART

1



Add To Favorites

People Also Viewed



3" Core Series
UltraTemp 1-Mil Gloss
Polyimide Labels



3" Core Series
WorkHorse Glossy
Polyester Labels



3" Core Series
UltraTemp 1-Mil
Matte Polyimide
Labels



3" Core Series
UltraTemp 1-Mil Gloss
Polyimide Labels



3" Core Series
WorkHorse Glossy
Polyester Labels



3" Core Series
UltraTemp 1-Mil
Matte Polyimide
Labels



3" Core Series
UltraTemp 1-Mil Gloss
Polyimide Labels



3" Core Series
WorkHorse Glossy
Polyester Labels



3" Core Series
UltraTemp 1-Mil
Matte Polyimide
Labels

Need a different size? Customize it!



Overview

Static Dissipative Polyimide (B-719) withstands wave solder environments and multiple harsh washes for printed circuit board and electronic component preprocess labeling.

- Low profile, high temperature, matte white polyimide material features a static dissipative adhesive and static dissipative release liner
- Surface resistivity values in the recommended range for Dissipative ESD packaging materials as defined by ANSI/ESD S541-2008
- RoHS compliant to 2011/65/EU; UL Approved; Meets requirements of MIL-STD-202G, Method 215K
- Service temperature of -94 to 212° F (-70 to 100° C)

Specifications

Material Number	B-719
California Prop 65	WARNING: Cancer - www.p65warnings.ca.gov
Catalog Page #	175
Dimensions	0.25 in H x 0.75 in W
UOM	Roll of 10000 Labels
Finish	Matte
Label/Tape Size	0.25 in H x 0.75 in W
Maximum Service Temperature °F	572 °F
Meta Description	Brady THT-1-719-10 is a High-Temperature ESD Industrial Polyimide Barcode Label that is 0.250" X 0.750" (6.350 mm X 19.050 mm). Shop online!
Meta Title	BRADY THT-1-719-10 ESD BARCODE LABEL
Minimum Service Temperature °F	-94 °F
Product Number	134303
UPC	754473924850
Quantity per Roll	10000
Quantity per Row	4
Thickness	0.0033 in
Trade Name	UltraTemp®
Unit Price	/Label
Adhesive Type	Acrylic
Applications	Circuit Board ID - After Process, Circuit Board ID - Surface Mount, Circuit Board ID - Through Hole Bottom, Circuit Board ID - Through Hole Top, Circuit Board Marking
Color	White

For Use with Printer	BBP®81 Label Printer, BRADY IP® Series Label Printer, BradyPrinter i5100, BradyPrinter i7100, BRADYPRINTER PR Plus Series Label Printer, THT 3" Core Printer
Label/Media Format	Roll
Label Properties	Heat Resistant Labels, Permanent Adhesive Labels
Material	Polyimide
Material Properties	Low Profile, Static-dissipative
Patent Number(s)	5958537
Patent Valid in (Countries)	USA
Print Technology	Thermal Transfer
Shape	Rectangle
Suggested Ribbon Series	R4700, R6000

Solutions

[Floor Marking Guide](#)
[GHS Label Compliance](#)
[Lockout Tagout Compliance](#)
[Arc Flash Labeling Requirements](#)
[Cable and Wire Label Options](#)
[Product and Barcode Labeling](#)
[Brand Protection Solutions](#)

Services

[Lockout Tagout Services](#)
[Arc Flash Services](#)
[Confined Space Services](#)
[Software Programming & Integration](#)
[Label Template & File Conversion](#)
[Printer Use & Training](#)
[Printer Preventative Maintenance](#)
[Toll and Custom Coating](#)
[Authentication & Tracking Services](#)

Help

[Contact Us](#)
[Website Feedback](#)
[Knowledge Center](#)
[Printer Drivers & Firmware](#)
[Brady Software Updates](#)
[Safety Data Sheets](#)
[Technical Data Sheets](#)
[WEEE-RoHS Compliance](#)
[Product Certification](#)
[Printer Registration](#)

Resources

[Find a Distributor](#)
[Design Custom Safety Signs](#)
[Create Custom THT Labels](#)
[Printer Selection Tool](#)
[Label Selection Tool](#)
[Digital Catalog](#)
[Request a Catalog](#)
[Interactive Facility Map](#)
[EPA e-Manifest Update](#)

Corporate


[About](#)
[Careers](#)
[Investors](#)
[Privacy Policy](#)
[Terms and Conditions](#)
[Terms of Use](#)
[ISO](#)
[Certificates](#)

Other BradyContact Sites

[Distributor Portal](#)
[International Sites](#)
[Safety Services & Software](#)
[Smart ID Brand Protection Solutions](#)

6555 W. Good Hope Rd. Milwaukee, WI 53223
Phone: 888-250-3082
Hours: 7am-6pm CT Monday - Thursday; Friday 7am-5pm CT

Brady (NYSE:BRC) is a manufacturer of complete solutions that identify and protect people, products and places. Brady's products help customers increase safety, security, productivity and performance and include high-performance labels, signs, safety devices, printing systems and software.

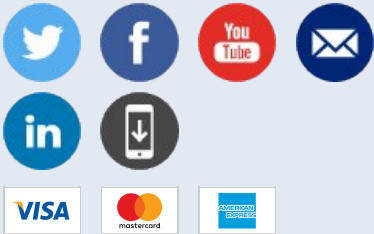

2018 © Brady Worldwide, Inc.

