


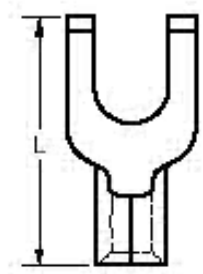

Part Number : [191180090](#)
Product Description : Krimptite Flanged Spade
Tongue Terminal for 12-10 AWG Wire, Stud Size 10
(M5), Length 19.56mm, Mylar Tape Carrier
Series Number : 19118
Status : Active
Product Category : Ring and Spade Terminals
Engineering Part Number : C-117-10T



Documents and Resources

Drawings

[191180090 sd.pdf](#)

3D Models and Design Files

[STEP AP242](#)

[SOLIDWORKS](#)

[Creo](#)

Specifications

[PS-19902-015-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Ring and Spade Terminals
Series	19118
Description	Krimptite Flanged Spade Tongue Terminal for 12-10 AWG Wire, Stud Size 10 (M5), Length 19.56mm, Mylar Tape Carrier
Keyword	Spade Terminal, Spade Terminals
Product Name	Krimptite
Style	Spade
Type	Spade Connector, Metric Spade Connector
UPC	800753093881

Agency

CSA	LR18689
UL	E32244

Physical

Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	2.232/g
Packaging Type	Adhesive Tape on Reel

Stud Size	10 (M5)
Wire Size (AWG)	10, 12
Wire Size mm ²	4.00-6.00

Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

Application Tooling

Global

Description	Part Number
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>190270088</u>
Mini-Mac Applicator	<u>638851000</u>

This document was generated on Dec 30, 2025