



Drawings

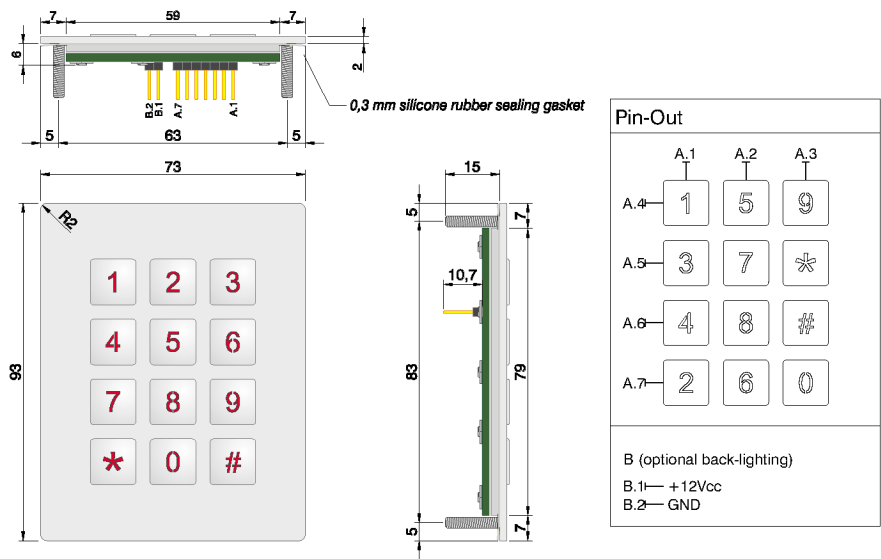

Suggested Cut-out

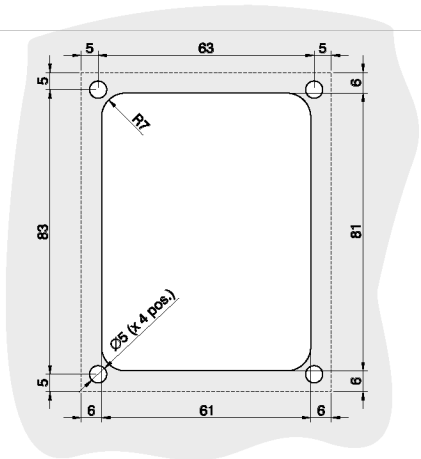

IP	65
IK	08
Cycles	3.000.000
Operating temp.	-10° to +70°C (0° to +50°C with TI)
Storage temp.	-25° to +85°C (-25° to +55°C with TI)

Marking
Backlight



Tolerances:			Date	Name	YME IP 12 H				
			04/12	dr					
IP rating	05/19	dr	knitter-switch			30 26 27			Page
Rename	02/14	dr							1/1
Rename	11/13	dr							
Modifications	Date	Name							