


<https://www.wago.com/806-912>

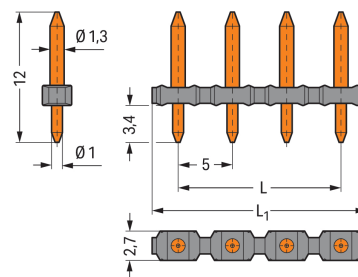

Similar to illustration


$$L = (\text{pole no.} - 1) \times \text{pin spacing} \quad L = (\text{pole no.} - 1) \times \text{pin spacing} + 4.8 \text{ mm}$$

Number of levels	1	Connection 1
		Pole number 12

Pin spacing	5 mm / 0.197 inches
Width	59.8 mm / 2.354 inches
Height	12 mm / 0.472 inches
Depth	2.7 mm / 0.106 inches
Solder pin length	3.4 mm
Solder pin diameter	1 mm
Drilled hole diameter	1.3 (+0.05) mm

Suitable Pin spacing: 5 mm / 0.197 inch

Contact type (pluggable connector)	Male connector/plug
Connector (connection type)	for PCB
Mating direction to the PCB	90 °

PCB contact	
PCB contact	THT

Material data	
Note (material data)	Information on material specifications can be found here
Color	black
Insulation material (main housing)	Polyamide (PA46)
Flammability class per UL94	V2
Fire load	0 MJ
Weight	1.7 g

Commercial data	
Product Group	4 (Printed Circuit Connectors)
PU (SPU)	100 pcs
Packaging type	Box
Country of origin	DE
GTIN	4044918429252
Customs tariff number	85366930000

Product Classification	
UNSPSC	39121409
eCl@ss 10.0	27-14-11-92
eCl@ss 9.0	27-14-11-92
ETIM 9.0	EC002848
ETIM 10.0	EC002848
ECCN	NO US CLASSIFICATION

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance

Compliance Search

Environmental Product Compliance 806-912

↓

Documentation			
Additional Information			
Technical Section	03.04.2019	pdf 2027.26 KB	↓



CAD/CAE-Data	
CAD data	CAE data
2D/3D Models 806-912	EPLAN Data Portal 806-912
	

PCB Design	
Symbol and Footprint via SamacSys 806-912	
Symbol and Footprint via Ultra Librarian 806-912	