

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Conductor marker carrier, transparent, unlabeled, mounting type: slide-on, cable diameter range: 6 ... 10 mm, lettering field size: 15 x 4 mm

Your advantages

- The corresponding UC-WMT ..., US-WMT ..., and EMT ... insert labels are used for marking
- These conductor marking systems consist of marker carriers and insert labels
- The PATG ... collar is a captive marker carrier
- Can be used to mark conductors with a diameter of 0.6 mm ... 50 mm

Commercial data

Item number	1013054
Packing unit	500 pc
Minimum order quantity	500 pc
Sales key	BG12
Product key	BG221A
Catalog page	Page 248 (C-3-2019)
GTIN	4017918013479
Weight per piece (including packing)	0.562 g
Weight per piece (excluding packing)	0.54 g
Customs tariff number	39269097
Country of origin	DE

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

Technical data

Product properties

Product type	Marker carrier cable
Type	Profile

Dimensions

Width	7.5 mm
Text field width	15.00 mm
Text field height	4.00 mm
Length	15 mm

External dimensions

Outside diameter	6 mm ... 10 mm
External diameter min.	6 mm
External diameter max.	10 mm

Material specifications

RoHS compliant	yes
Color	transparent
Material	PVC
Flammability rating according to UL 94	V0
Components	Silicone-free

Cable/line

External cable diameter	6 mm ... 10 mm
-------------------------	----------------

Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

Ambient conditions

Ambient temperature (operation)	-50 °C ... 80 °C
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %

Mounting

Mounting type	slide-on
---------------	----------

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

Classifications

ECLASS

ECLASS-11.0	27281105
ECLASS-12.0	27281105
ECLASS-13.0	27281105

ETIM

ETIM 9.0	EC001530
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

Accessories

UCT-WMT (15X4) - Conductor marker

0801446

<https://www.phoenixcontact.com/us/products/0801446>




Conductor marker, Sheet, white, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

UCT-WMT (15X4) BU - Conductor marker

0801452

<https://www.phoenixcontact.com/us/products/0801452>

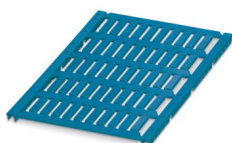

Conductor marker, Sheet, blue, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

PATG 4/15 - Conductor marker carrier




1013054

<https://www.phoenixcontact.com/us/products/1013054>

UCT-WMT (15X4) GN - Conductor marker

0801450

<https://www.phoenixcontact.com/us/products/0801450>

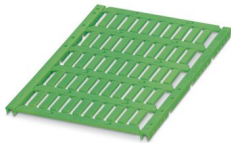


Conductor marker, Sheet, green, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

UCT-WMT (15X4) OG - Conductor marker

0801449

<https://www.phoenixcontact.com/us/products/0801449>

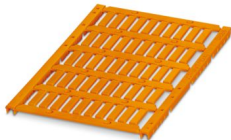

Conductor marker, Sheet, orange, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

UCT-WMT (15X4) RD - Conductor marker

0801448

<https://www.phoenixcontact.com/us/products/0801448>




Conductor marker, Sheet, red, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

UCT-WMT (15X4) YE - Conductor marker

0801447

<https://www.phoenixcontact.com/us/products/0801447>

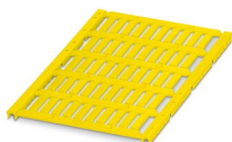

Conductor marker, Sheet, yellow, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

UC-WMT (15X4) - Conductor marker

0819398

<https://www.phoenixcontact.com/us/products/0819398>




Conductor marker, Sheet, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 46 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

UC-WMT (15X4) BU - Conductor marker

0821030

<https://www.phoenixcontact.com/us/products/0821030>

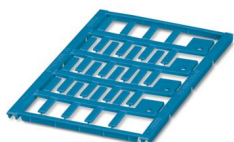

Conductor marker, Sheet, blue, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 46 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

UC-WMT (15X4) GN - Conductor marker

0824040

<https://www.phoenixcontact.com/us/products/0824040>



Conductor marker, Sheet, green, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 46 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

UC-WMT (15X4) OG - Conductor marker

0824037

<https://www.phoenixcontact.com/us/products/0824037>



Conductor marker, Sheet, orange, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 46 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

UC-WMT (15X4) RD - Conductor marker

0821043

<https://www.phoenixcontact.com/us/products/0821043>




Conductor marker, Sheet, red, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 46 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

UC-WMT (15X4) YE - Conductor marker

0819408

<https://www.phoenixcontact.com/us/products/0819408>

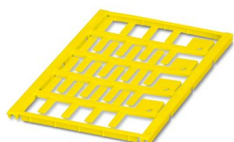

Conductor marker, Sheet, yellow, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 46 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

US-WMT (15X4) - Cable marker

0828767

<https://www.phoenixcontact.com/us/products/0828767>




Cable marker, Card, white, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

US-WMT (15X4) BU - Cable marker

0829291

<https://www.phoenixcontact.com/us/products/0829291>

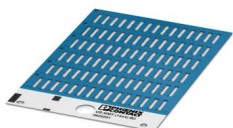

Cable marker, Card, blue, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

PATG 4/15 - Conductor marker carrier




1013054

<https://www.phoenixcontact.com/us/products/1013054>

US-WMT (15X4) GN - Cable marker

0829292

<https://www.phoenixcontact.com/us/products/0829292>

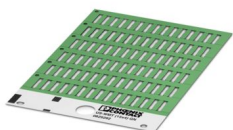

Cable marker, Card, green, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

US-WMT (15X4) OG - Cable marker

0829288

<https://www.phoenixcontact.com/us/products/0829288>



Cable marker, Card, orange, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

US-WMT (15X4) RD - Cable marker

0829287

<https://www.phoenixcontact.com/us/products/0829287>



Cable marker, Card, red, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

US-WMT (15X4) VT - Cable marker

0829290

<https://www.phoenixcontact.com/us/products/0829290>



Cable marker, Card, violet, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

US-WMT (15X4) YE - Cable marker

0828954

<https://www.phoenixcontact.com/us/products/0828954>



Cable marker, Card, yellow, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: slide-on, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 84

EMT (15X4)R - Insert label

0817329

<https://www.phoenixcontact.com/us/products/0817329>



Insert label, Roll, white, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMaster 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 7500

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

EMT (15X4)R BU - Insert label

0817332

<https://www.phoenixcontact.com/us/products/0817332>



Insert label, Roll, blue, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 7500

EMT (15X4)R RD - Insert label

0816249

<https://www.phoenixcontact.com/us/products/0816249>



Insert label, Roll, red, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 7500

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

EMT (15X4)R YE - Insert label

0817358

<https://www.phoenixcontact.com/us/products/0817358>



Insert label, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMaster 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 7500

WMTW (15X4)R - Cable marker

0831002

<https://www.phoenixcontact.com/us/products/0831002>



Cable marker, Roll, white, unlabeled, can be labeled with: THERMOMARK E.300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMaster 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 3000

PATG 4/15 - Conductor marker carrier

1013054

<https://www.phoenixcontact.com/us/products/1013054>



WMTW (15X4)R YE - Cable marker

0831003

<https://www.phoenixcontact.com/us/products/0831003>



Cable marker, Roll, yellow, unlabeled, can be labeled with: THERMOMARK E. 300 (D)/600 (D), THERMOMARK ROLL 2.0, THERMOMARK ROLL, THERMOMARK ROLL X1, THERMOMARK ROLLMASTER 300/600, THERMOMARK X1.2, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 3000

PABL 15X4 - Insert strip

0808260

<https://www.phoenixcontact.com/us/products/0808260>



Insert strip, Sheet, white, unlabeled, can be labeled with: Office printing systems, CMS-P1-PLOTTER, perforated, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 360

PATG 4/15 - Conductor marker carrier

1013054

<https://www.phoenixcontact.com/us/products/1013054>



UCT-WMT (15X4) VT - Conductor marker

0801451

<https://www.phoenixcontact.com/us/products/0801451>



Conductor marker, Sheet, violet, unlabeled, can be labeled with: TOPMARK NEO, TOPMARK LASER, BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, THERMOMARK PRIME, THERMOMARK CARD 2.0, THERMOMARK CARD, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 50

UC-WMT (15X4) BN - Cable marker

0829475

<https://www.phoenixcontact.com/us/products/0829475>



Cable marker, Sheet, brown, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

PATG 4/15 - Conductor marker carrier



1013054

<https://www.phoenixcontact.com/us/products/1013054>

UC-WMT (15X4) VT - Cable marker

0825361

<https://www.phoenixcontact.com/us/products/0825361>



Cable marker, Sheet, violet, unlabeled, can be labeled with: BLUEMARK ID COLOR, BLUEMARK ID, BLUEMARK CLED, PLOTMARK, CMS-P1-PLOTTER, mounting type: insert, cable diameter range: 0.6 ... 50 mm, lettering field size: 15 x 4 mm, Number of individual labels: 32

Phoenix Contact 2024 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com