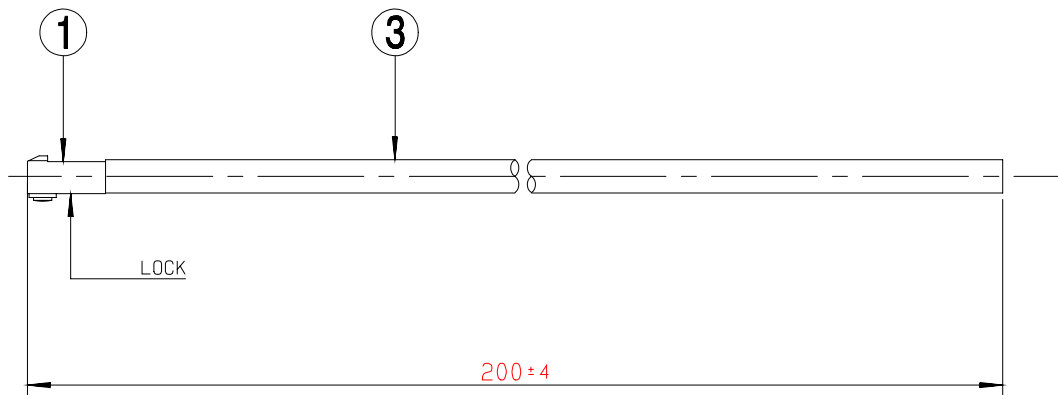


PIGTAIL MALE UMP**R285.020.302****CABLE 2/75 S-BR LENGHT: 20 CM****Series : CORD-STD*** 1 * Connector A : **R107.101.200**

* 2 * Connector B :

* 3 * Cable : **C291.180.072**

Type :

ELECTRICAL CHARACTERISTICS

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+90 ° C
VSWR	NA + 0.000 x F(GHz) Maxi
Insertion loss	NA $\sqrt{F}$(GHz) dB Maxi
Voltage rating	100 Veff Maxi
Dielectric withstanding voltage	350 Veff mini
Insulation resistance	1000 MΩ mini

SPECIFICATION

Weight	1.650 g
Cable retention	NA N mini
Others :	

**Edition : 0144 B**

Design changes may be in order to improve the product.