




+ CONNECTORS

SFP/SFP+/ZSFP+

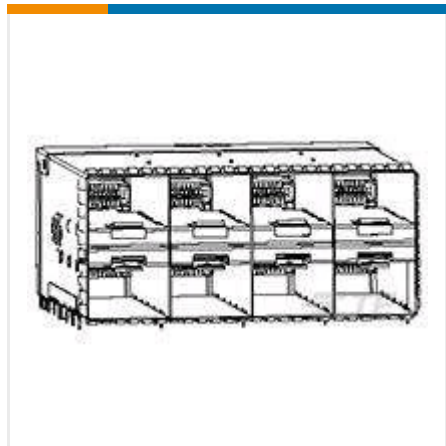

✓ Active

↓ **PRODUCT DRAWING**
English

TE CONNECTIVITY (TE)

zSFP+ STACKED 2X4 RECEPTACLE ASSEMBLY

zSFP+/SFP28 | zSFP+

1-2180324-9

TE Internal Number: 1-2180324-9

Always EU RoHS/ELV Compliant

Form Factor **zSFP+**

Product Type **Cage Assembly with Integrated Connector**

Data Rate (Max) (Gb/s) **32**

EMI Containment **External Springs**

Cage Type **Stacked**

Product Drawings

[RECEPTACLE ASSEMBLY, 2X4, STACKED, ZSFP+](#)

PDF
English

Product Specifications

Product Specification

[ZSFP+ Stacked Connector And Cage Assemblies](#)

PDF
English

Application Specification

[Stacked Small Form-Factor Pluggable ZSFP+ Connector And Cage Assembly](#)

PDF
English

Instruction Sheets

Instruction Sheet (U.S.)

[Small Form-Factor Pluggable \(SFP\)+ ZSFP+ Extraction Tool Kits 2063048-\[\] And 2161405-1 For Stacked PT Connector And Cage Assemblies](#)

PDF
English

[Small Form-Factor Pluggable \(ZSFP+\) Seating Tool Kits 2215000-\[\] For Stacked PT Connector And Cage Assemblies](#)

PDF
English

Please review product documents or [contact us](#) for the latest agency approval information. Please Note: Use the Product Drawing for all design activity.

Product Type Features

Form Factor

zSFP+

Product Type

Cage Assembly with Integrated Connector



	Included Heat Sink	No
	Included Lightpipe	Yes
	Integrated Lightpipes	Yes
Configuration Features	EMI Containment	External Springs
	Port Configuration	2x4
	Lightpipe Configuration	Three
	Lightpipe Style	Standard
	Number of Ports	8
Signal Characteristics	Data Rate (Max) (Gb/s)	32
Contact Features	Contact Mating Area Plating Material	Gold or Gold Flash over Palladium Nickel
	Tail Plating Material	Tin
	Contact Mating Area Plating Thickness	.76 µm [29.92 µin]
Termination Features	Termination Method to PC Board	Through Hole - Press-Fit
Mechanical Attachment	PCB Mounting Style	Single-Sided
	Mounting Style	Standard
Housing Features	Cage Type	Stacked
	Cage Material	Nickel Silver Alloy
Dimensions	PCB Thickness (Recommended)	1.5 mm [.059 in]
	Tail Length	1.8 mm [.07 in]
Operation/Application	Heat Sink Compatible	No
	For Use With	zSFP+ SMT Connector
Industry Standards	UL Flammability Rating	UL 94V-0
Packaging Features	Packaging Method	Tray
Product Compliance	Statement of Compliance PDF	
	VIEW ALL PRODUCT COMPLIANCE	

