
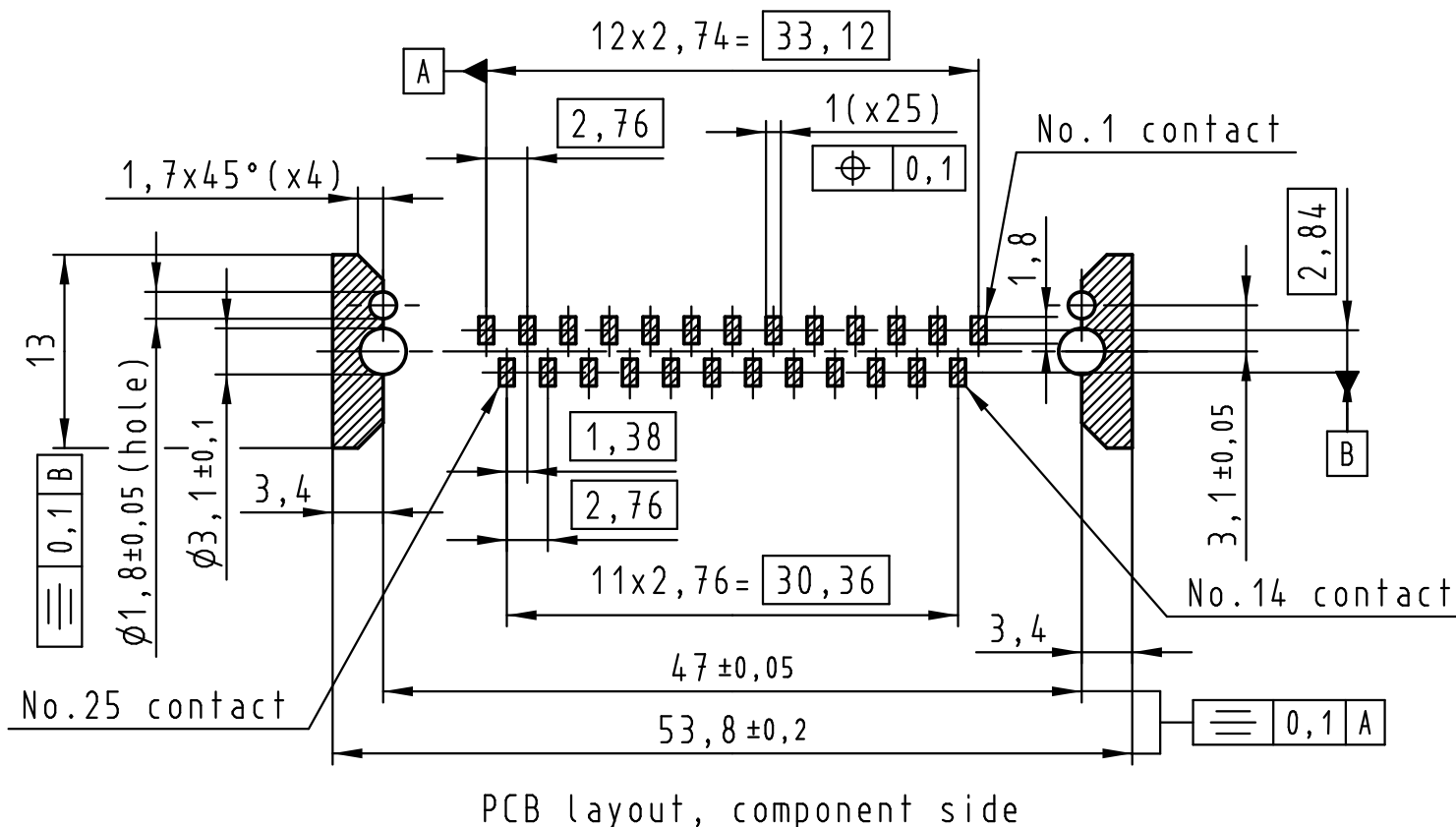
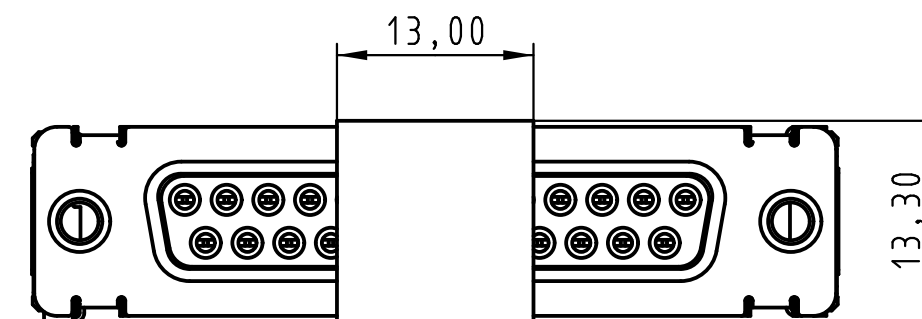
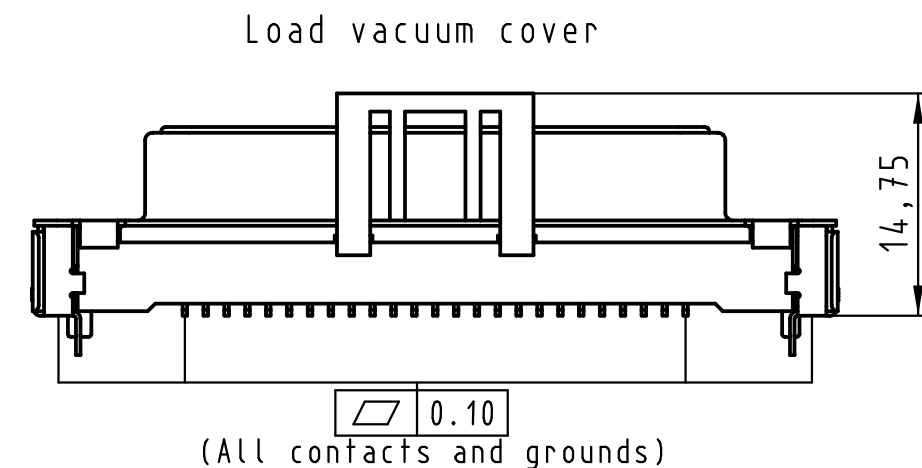
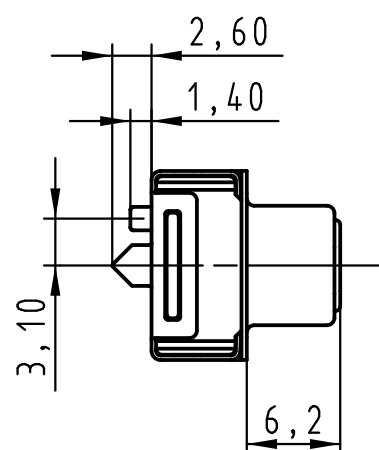
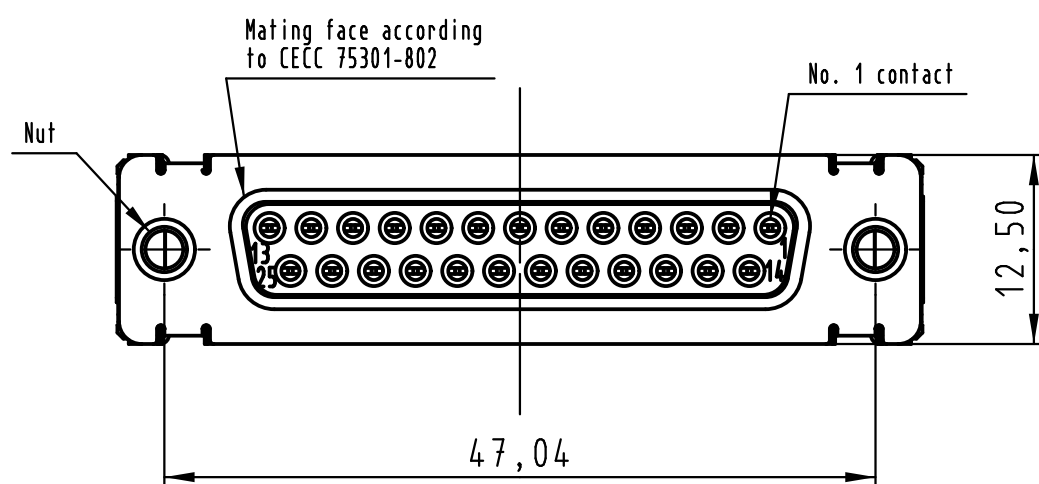


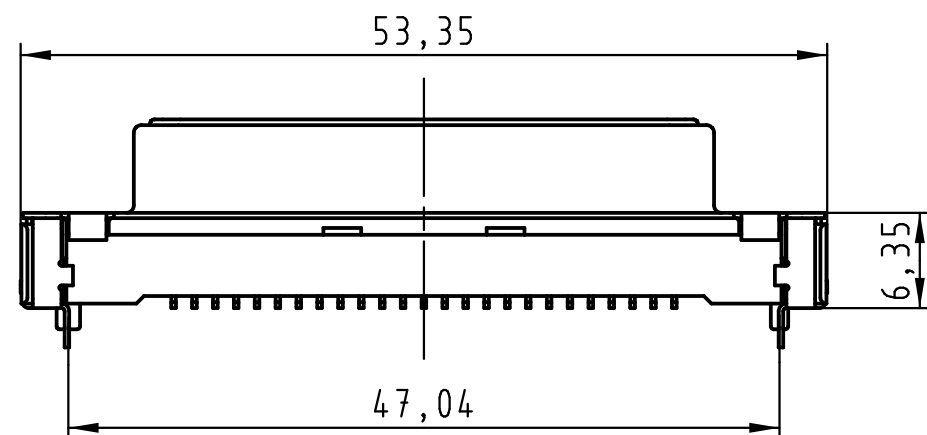

Max. Temperature: 260° during 10 seconds.

0955 355 3611 741	1	M3	Black insulator	Reel Packaging: 140 connectors (See details on page2/2)		
0955 355 3612 741	1	4-40 UNC				
0955 355 6611 741	2	M3				
0955 355 6612 741	2	4-40 UNC				
0955 355 7611 741	3	M3				
0955 355 7612 741	3	4-40 UNC				
Part number	PL	Nut	Index designation			
All Dimensions in mm Original Size DIN A 3			Techn. Character.		Free size tolerances	
						D-Sub SMT, 25 poles Female, Straight with nuts and ground pins
			Detail.	25-Oct-11	Johnson.S	
			Insp.	17-Nov-11	Steven.W	
			Stand.	17-Nov-11	Steven.W	
			Zhuhai HARTING Limited			TB 09 55 355 x61x
EC04070	17-Nov-11	Johnson.S				
Mod.	Dat.	Name	Sub.			Page 1 / 2

0955 355 3611 741	1	M3	Black insulator	Reel Packaging: 140 connectors
0955 355 3612 741	1	4-40 UNC		
0955 355 6611 741	2	M3		
0955 355 6612 741	2	4-40 UNC		
0955 355 7611 741	3	M3		
0955 355 7612 741	3	4-40 UNC		
Part number	PL	Nut	Index designation	

 All Dimensions in mm Original Size DIN A 3			Techn. Character.				Free size tolerances		
				Dat.	Name	Scale	D-Sub SMT, 25 poles Female, Straight with nuts and ground pins		
			Detail.	25-Oct-11	Johnson.S				
			Insp.	17-Nov-11	Steven.W				
			Stand.	17-Nov-11	Steven.W				
			Zhuhai HARTING Limited 				TB 09 55 355 x61x		Page 2/2
EC04070	17-Nov-11	Johnson.S					Sub.		
Mod.	Dat.	Name							