




Part Number : [349590384](#)
Product Description : Mini50 Unsealed Receptacle,
UL 94 HB, 3 Rows, with CPA, 38 Circuits, Polarization
Option B, Gray
Series Number : 34959
Status : Active
Product Category : Connector Housings

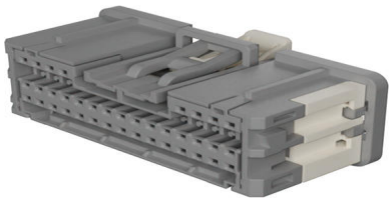

Documents and Resources

Drawings

- [349590384 sd.pdf](#)
- [PK-31301-898-000.pdf](#)
- [PK-31301-538-001.pdf](#)
- [PK-31301-898-001.pdf](#)

3D Models and Design Files

- [STEP AP242](#)
- [SOLIDWORKS](#)
- [Creo](#)

Specifications

- [349590001-AS-CH-000.pdf](#)
- [AS-34959-001-001.pdf](#)
- [PS-34959-001-001.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Compliant
China RoHS	 per SJ/T 11365-2006
EU ELV	Compliant per 2000/53/EC
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)7771-DC (04 Feb 2026)

EU RoHS	Compliant per EU 2015/863
---------	---------------------------

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

Part Details

General

Status	Active
Category	Connector Housings
Series	34959
Description	Mini50 Unsealed Receptacle, UL 94 HB, 3 Rows, with CPA, 38 Circuits, Polarization Option B, Gray
Application	Automotive, Wire-to-Board
Product Name	Mini50
UPC	191128829694

Physical

Circuits (maximum)	38
Color - Resin	Gray
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes

Material - Resin	Nylon
Net Weight	5.800/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarization	B
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Mates With / Use With

Mates with Part(s)

Description	Part Number
Mini50 Unsealed Vertical Hybrid Header, UL 94 HB, 3 Rows, 38 Circuits, Polarization Option B, Gray, Tray	<u>349580384</u>
Mini50 Unsealed Right-Angle Header, UL 94 HB, 38 Circuits, Polarization B, Gray, Tray	<u>349610387</u>
Mini50 Unsealed Right-Angle Header, UL 94 HB, 38 Circuits, Polarization B, Gray, Tube	<u>349617387</u>
Mini50 Unsealed Right-Angle Header, UL 94 HB, 38 Circuits, Polarization B, Gray, Tape and Reel	<u>349618387</u>
Mini50 Unsealed Right-Angle Headers	<u>213355</u>

Use with Part(s)

Description	Part Number
CTX50 Unsealed Receptacle Terminals	<u>560023</u>

This document was generated on May 21, 2026